

Weidmüller Tool Chest

Optimized organization of tools and work materials

With the process of wiring control cabinets being extremely time-consuming, having quick access to organized tools makes all the difference. The Weidmuller tool chest allows you to organize your tools how you want them. With its foam inserts that are tailored to the drawers and its trisection design, you can create custom tool layouts that are personalized to your needs. Not sure which tool goes where? Our foam layouts have labels for each tool, so you can quickly pack up your tools. Each tool layout has a specific QR code that leads to our online catalog with technical specs and application videos.

Tool Chest Features:

- **Optimal load capacities:**
40kg (88lbs) per drawer, 400kg (881lbs) housing capacity
- **Ideal space conditions:**
Six drawers with 600x447mm (23.6x17.6in) usable internal dimensions
(Height: 2x75mm / 2x100mm / 1x150mm / 1x200mm)
(Height: 0.08x2.9in/ 0.08x3.9in/ 0.04x5.9in/ 0.04x7.9in)
- **Maximum utilization:**
Full extension of drawers and optimal drawer height
- **Perfect work safety:**
Central locking and increased safety against unintentional opening while mobile
- **Flexible adjustment possibilities:**
Perforated sidewalls and rear wall for the admission of accessories and tool hook
- **Highest ease of use:**
Sturdy ergonomic sliding bar made of anodized aluminum
- **Full mobility:**
Two smooth running, fixed and two swivel wheels made of solid rubber
- **Additional storage and working surface:**
Non-slip plastic cover with small parts compartment
- **Additional safety:**
Edge protection made of ABS plastic as shock absorber

Interchangeable Inlays



Custom fit foam inlays keep your tools organized and in place, guaranteeing you always know where your tools will be.

Maximum Flexibility



Three part foam inserts allow you to tailor your workstation, resulting in a more efficient and organized work process.

Clearly Labeled



Clearly visible markers with name and article number reveal which tool belongs where.

Quick Identification



A QR code leads to the online catalog for further information about the tool.

Weidmuller – Your partner in Industrial Connectivity

As experienced experts we support our customers and partners around the world with products, solutions and services in the industrial environment of power, signal and data. We are at home in their industries and markets and know the technological challenges of tomorrow. We are therefore continuously developing innovative, sustainable and useful solutions for their individual needs. Together we set standards in Industrial Connectivity.

Weidmüller Tool Box — Complete Solution

One stop shop for any professional workshop or panel builder



Weidmuller, Inc
821 Southlake Blvd.
Richmond, Virginia 23236
Telephone: (800) 849-9343
Facsimile: (804) 379-2593
Email: info@weidmuller.com
Website: www.weidmuller.com

Personal support can be found on our website: www.weidmuller.com/contact



Complete Solution — Entire Shop in One Box

All contents at a glance

Tool Case
Multi-drawer locking case




Easy locking cart that can hold all the tools and shelves for larger tools.

Crimping tools
Wire ferrule tools for stranded cables



Crimping tools for multiple shapes and ferrule sizes.

THM MultiMark Printer
Simple Printing Solutions

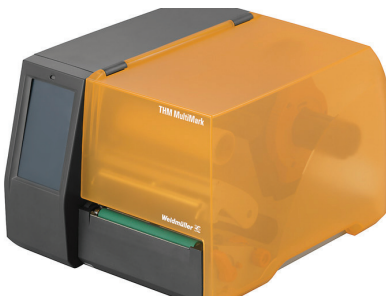

Endless reels for marking any tags on Terminal Blocks, Devices, and wire/cables.

Full Assortment of screwdrivers
Insulated & Non-insulated




Insulated and non-insulated screwdrivers. Assortment of torque bits and automatic screwdriver bits.

Wire & Cable Cutters
Ergonomic cutters to avoid hand fatigue



Cut through multi-stranded cables and insulated pliers for precision and safe handling of materials.

DIN Rail Cutter
Cut and punch TS35 DIN rail

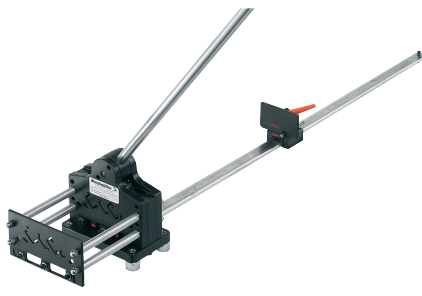

Cut TS35 DIN rail with ease and punch up to a M5 slot all in the same tool.

Stripax
Wire Strippers



Industry leading, ergonomic wire strippers for mulitple cable sizes and jacket materials.

Cable Sheath Strippers
Quickly and easily remove the outer jacket



Strip off the outer jacket from data cables without damaging the inner cable insulation.

Easily Identifiable Space Slots
Increase reaction time and productivity



Organized and labelled draw inserts for quick re-ordering.

Detailed Contents



* Tool chest accessories not included

Large Universal Inlay

Part Number	Description	Part Number	Description
1323880000	SD TO 0.6X3.0	9918160000	SLICER 1K
9006060000	SWIFTY SET	9202750000	BIT E6,3 4,4X2,5X70
9046380000	FRZ S 200	9024020000	SCREWDRIVER, BIT E6.3
9002650000	KT 8 CABLE CUTTER	9024040000	SCREWDRIVER, BIT E6.3
9005000000	STRIPAX	9024100000	SCREWDRIVER, BIT E6.3
1444050000	PZ 6 ROTO L	9024110000	SCREWDRIVER, BIT E6.3
9006120000	CTI 6	1318350000	BIT E6,3 T15
9205150000	SUPER CUT ELEC.DIAG.CUT.PLIERS	1318370000	BIT E6,3 T20
9204190000	AM 16	1318380000	BIT E6,3 T40

Small Inlay 1


Part Number	Description
9005610000	STRIPAX 16
9012600000	PZ 16
9030500000	CST
9002650000	KT 8 CABLE CUTTER
9032010000	CASSETTE CST BRAUN
9032040000	CASSETTE CST ROT

Small Inlay 2

Part Number	Description
9046290000	KBZ 180MM LONG INSULATED PLIERS
9046320000	SE HD 160
9046370000	FRZ S 160 LONG NOSE PLIERS
9008850000	SK WSD-S 1,5-10 ALLEN SET 9PC

Complete Solution

Part	Box Configuration
7940108784	Shop in One Box includes: - Tool Chest with inlays - Multimark Printer - TLSD 5 Rail Cutter
7940108783	Tool Chest with Tools (Does not include printer or rail cutter)

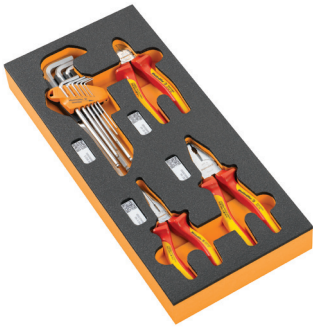


Small Inlay 3

Part Number	Description
1157830000	KT 22 CABLE CUTTER 22MM DIA
9006450000	PZ 50
9001540000	AM 25
9001080000	AM 35



Small Inlay 4

Part Number	Description	Part Numbers	Description
9918390000	DMSI MANUAL 0.5-1.7(INSULATED)	2506070000	WB I SK 4
2433160000	WB SI SL 0.4x2.5	2506080000	WB I SK 5
2433170000	WB SI SL 0.5x3.0	2433210000	WB IK SL PH1
2433180000	WB SI SL 0.6X3.5	2433220000	WB IK SL PH2
2433190000	WB SI SL 0,8x4,0	2506000000	WB I T10
2433200000	WB SI SL 1,0x5,5	2506010000	WB I T15
2433230000	WB IK SL PZ1	2506020000	WB I T20
2433240000	WB IK SL PZ2	2506030000	WB I VK 1
2506050000	WB I SK 2,5	2506040000	WB I VK 2
2506060000	WB I SK 3	1274750000	SDIS SL 3.5-6.5/PH/1/2

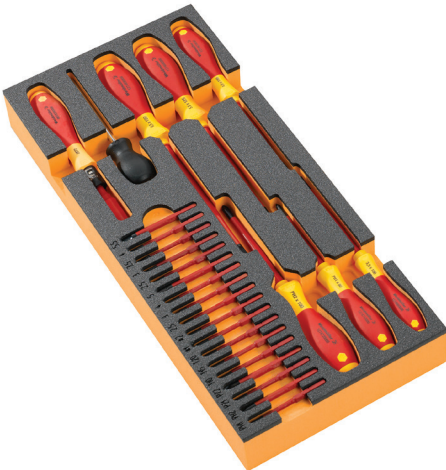

Small Inlay 6

Part Number	Description
1910000000	Screwty Set
9015900000	FLECAFIX 11/24
9015980000	FLECAFIX 24/36



Small Inlay 7

Part Number	Description
2436680000	VT M
2436670000	VT LCL
9918870000	VT DIGI PRO

