

Detectable Markers by Weidmüller

Food safety at the highest level



Benefits

Support

The food and beverage industry places the highest demands on quality, hygiene, and safety. With our detectable marking solutions, we support our customers in ensuring that the high standards required within the HACCP concept are met.

Process security within the HACCP-concept

Due to a metallic filler, our detectable MultiCards are identified reliably by metal and X-ray detectors. Identification minimizes the risk of contamination during the food production process. MultiCards provide maximal safety because of properties like corrosion resistance and ageing resistance against UV radiation and heat. We regularly check and confirm the safety properties in our accredited laboratory.

Your special advantages:

- Detectable by metal and X-ray detectors
- Visually recognisable by blue colour
- Corrosion resistant metallic filler
- Clear and resistant print image
- Available in different versions for a wide variety of marking requirements




Weidmüller 

Technical data

Detectable SFX Markers - MultiCard

Material	Color	Fire class acc. to UL 94	Temperature range
PA 6.6	Blue	HB	-40°C...100°C

Type	Width	Height	Qty.	Order no.
SFX-DT 9/24 MC NE BL	15 mm	24 mm	160	2602720000
SFX-DT 11/60 MC NE BL	11 mm	60 mm	60	2602730000
SFX-DT 10/60 S MC NE BL	10 mm	60 mm	50	2602740000

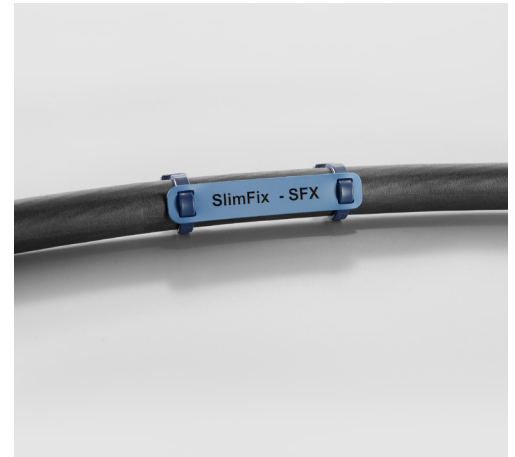

PrintJet ADVANCED ink jet printer

Type	Qty.	Order no.
PrintJet ADVANCED 120 V	1	1338700000



Detectable SFX Markers - MultiMark

Material	Tempature range	Fire class acc. to UL 94	Type	Order no.
Polyethylene	-30...65°C	HB	RIBBON MMHS 60/300 SW	2448880000

Type	Color	Height/Width	Labeling Field	Qty.	Order no.
SFX-DT 9/24 MM BL	Blue	26/15 mm	23.9 x 9 mm	1000	2621490000
SFX-DT 11/60 MM BL	Blue	60/13 mm	10.5 x 44 mm	1000	2621480000

THM MultiMark thermal transfer printer

Type	Qty.	Order no.
THM MultiMark	1	2599430000



Detectable cable ties

Material	Color	Fire class acc. to UL 94	Temperature range
PA 6.6	Blue	HB	-25°C....100°C



Type	Width	Length	Qty.	Order no.
CB-DT 100/2.5 BL	2.5 mm	100 mm	100	2602750000
CB-DT 140/3.5 BL	3.5 mm	140 mm	100	2602760000
CB-DT 200/4.5 BL	4.5 mm	200 mm	100	2602770000
CB-DT 280/4.5 BL	4.5 mm	280 mm	100	2602780000
CB-DT 380/4.5 BL	4.5 mm	380 mm	100	2602790000
CB-DT 360/7.5 BL	7.5 mm	360 mm	100	2602800000

Weidmüller, Inc

821 Southlake Blvd.
 Richmond, Virginia 23236
 Telephone: (800) 849-9343
 Facsimile: (804) 379-2593
 Email: info@weidmuller.com
 Website: www.weidmuller.com



Weidmüller