

Klippon® K - Aluminium enclosures

Robust enclosures for industrial applications

Robust, light and safe


Klippon® K - aluminium enclosures are characterised by a wide range of modular sizes, low weight, and a wide variety of applications. The robust enclosures are suitable for industrial applications and applications in harsh environments. A perfect protection of terminals, switches, power supplies, control and display elements, or electronic components is provided. That is what our Klippon® K range is made for.

22 different sizes and two different surfaces – powder coated and natural – offer maximum flexibility. We manufacture and deliver the enclosures fully assembled with terminals and cable glands – exactly customised, according to your requirements.



Your special advantages:

- Almost indestructible
- Highest IP protection up to IP66/IP67/IP68
- Extreme temperature resistance from -60°C to +135°C
- Closed moulded seals ensure increased impermeability of each enclosure
- Prepunched mounting holes enable direct mounting of the enclosures
- Higher safety due to standardised Torx screw heads
- Worldwide approvals according to the latest international standards

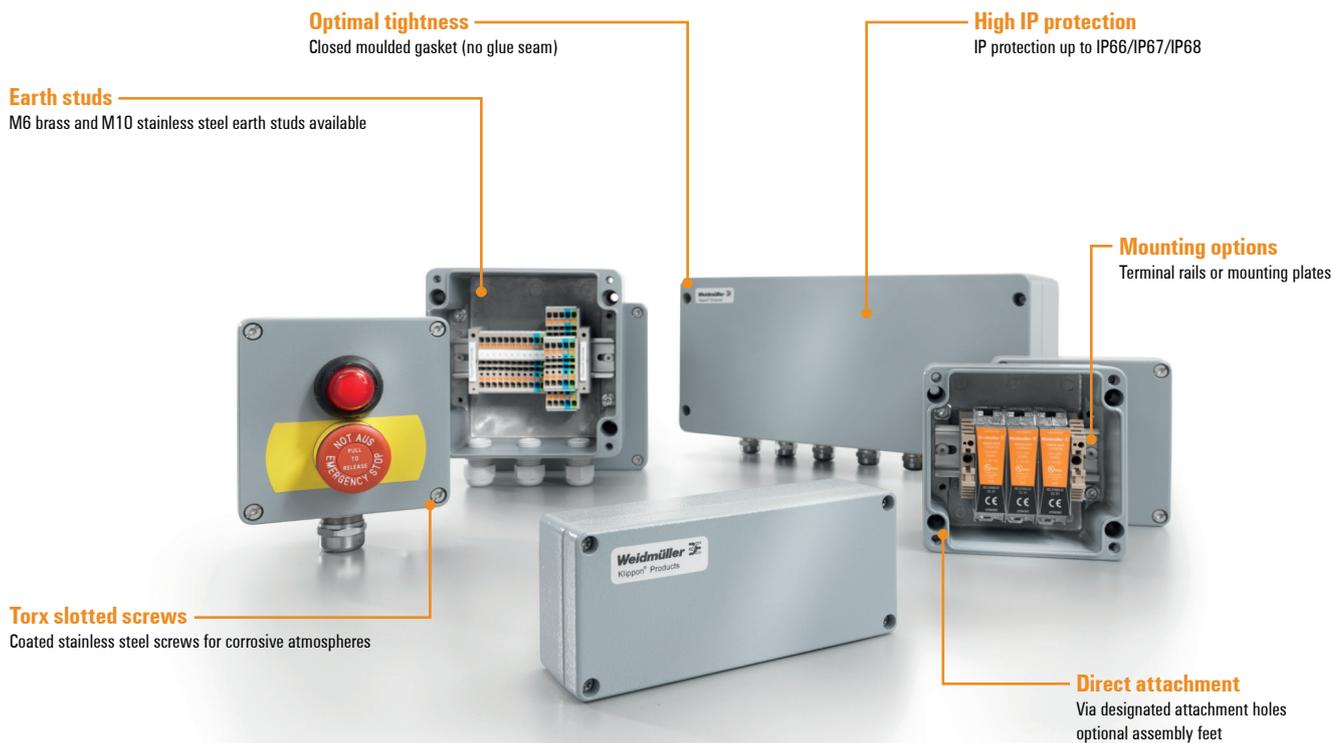

Product Overview

Description	Height x width x depth in mm	Powder-coated (RAL7001)*			Unpainted		
		Standard		Ex enclosure	Standard		Ex enclosure
		CR moulded seal	Silicone moulded sea	Silicon moulded seal	CR moulded seal	Silicone moulded seal	Silicon moulded seal
Klippon® K 0	45 x 50 x 30	9529090000	1937920000		0573200000	1939760000	
Klippon® K 01	64 x 58 x 34	9529100000	1937850000		1565240000	1939540000	
Klippon® K 02	64 x 98 x 34	9529110000	1937840000		1565250000	1939550000	
Klippon® K 1	70 x 70 x 45	9529120000	1937630000	1329630000	0342000000	1939560000	9526840000
Klippon® K 11	80 x 75 x 57	9529130000	1937910000	1329640000	0573300000	1939570000	9526850000
Klippon® K 2	70 x 100 x 45	9529140000	1937930000	1329650000	0342100000	1939580000	9526860000
Klippon® K 21	80 x 125 x 57	9529150000	1937830000	1328120000	0573400000	1939590000	9526870000
Klippon® K 3	70 x 165 x 45	9529160000	1937900000	1329670000	0342200000	1939600000	9526880000
Klippon® K 31	80 x 175 x 57	9529170000	1937820000	1329680000	0573500000	1939610000	9526890000
Klippon® K 32	80 x 250 x 55	9529180000	1937810000	1329690000	1565260000	1939620000	9526900000
Klippon® K 4	82 x 130 x 72	9529190000	1937890000	1329700000	0342300000	1939630000	9526910000
Klippon® K 41	120 x 122 x 81	9529200000	1937800000	1329710000	1565270000	1939640000	9526920000
Klippon® K 42	140 x 140 x 91	2934110000	2934120000		2934130000	2934140000	
Klippon® K 5	130 x 170 x 90	9529210000	1937860000	1329720000	0342400000	1939650000	9526930000
Klippon® K 51	120 x 220 x 81	9529220000	1937750000	1328130000	1565280000	1939660000	9526940000
Klippon® K 52	160 x 160 x 91	9529230000	1937740000	1329730000	1565290000	1939670000	9526950000
Klippon® K 6	160 x 200 x 100	9529240000	1937870000	1329740000	0342500000	1939690000	9526960000
Klippon® K 61	160 x 260 x 91	9529250000	1937730000	1328140000	0573600000	1939700000	9526970000
Klippon® K 7	160 x 350 x 100	9529260000	1937880000	1329750000	0342600000	1939710000	9526980000
Klippon® K 71	230 x 280 x 111	9529270000	1937720000	1329700000	0573700000	1939730000	9526990000
Klippon® K 75	230 x 330 x 180	2934170000	2934180000		2934190000	2934200000	
Klippon® K 79	310 x 400 x 180	2934230000	2934240000		2934250000	2934260000	

Note *Colour variations may occur under certain circumstances



For a more detailed overview of the products, you can open the online catalogue at catalogue.weidmueller.com or scan the QR code.



You can find this product family in our Weidmüller Configurator: www.weidmueller.com/wmc