

Klippon® K - Aluminium enclosures

Robust protection for demanding applications

Robust, lightweight and secure

The Klippon® K aluminium enclosure series provides reliable protection for electrical and electronic components – even under the most demanding conditions. Thanks to their exceptional durability, these enclosures are ideally suited for industrial applications as well as use in harsh and hazardous environments.


Whether used for terminal blocks, switches, power supplies, control and display elements, or electronic assemblies, Klippon® K enclosures ensure long-lasting and dependable protection for your components.

A comprehensive portfolio of 22 different sizes, available with either a powder-coated or natural finish, offers maximum flexibility for a wide range of applications. Upon request, we can deliver your enclosures fully assembled and precisely tailored to your specific requirements.



Your special advantages:

- Almost indestructible
- Highest IP protection up to IP66/IP67/IP68
- Extreme temperature resistance from -60°C to +135°C
- Closed moulded seals for optimal impermeability
- Prepunched mounting holes for easy mounting
- Higher safety due to standardised Torx screw heads
- Worldwide approvals according to the latest international standards
- Individual processing and assembly

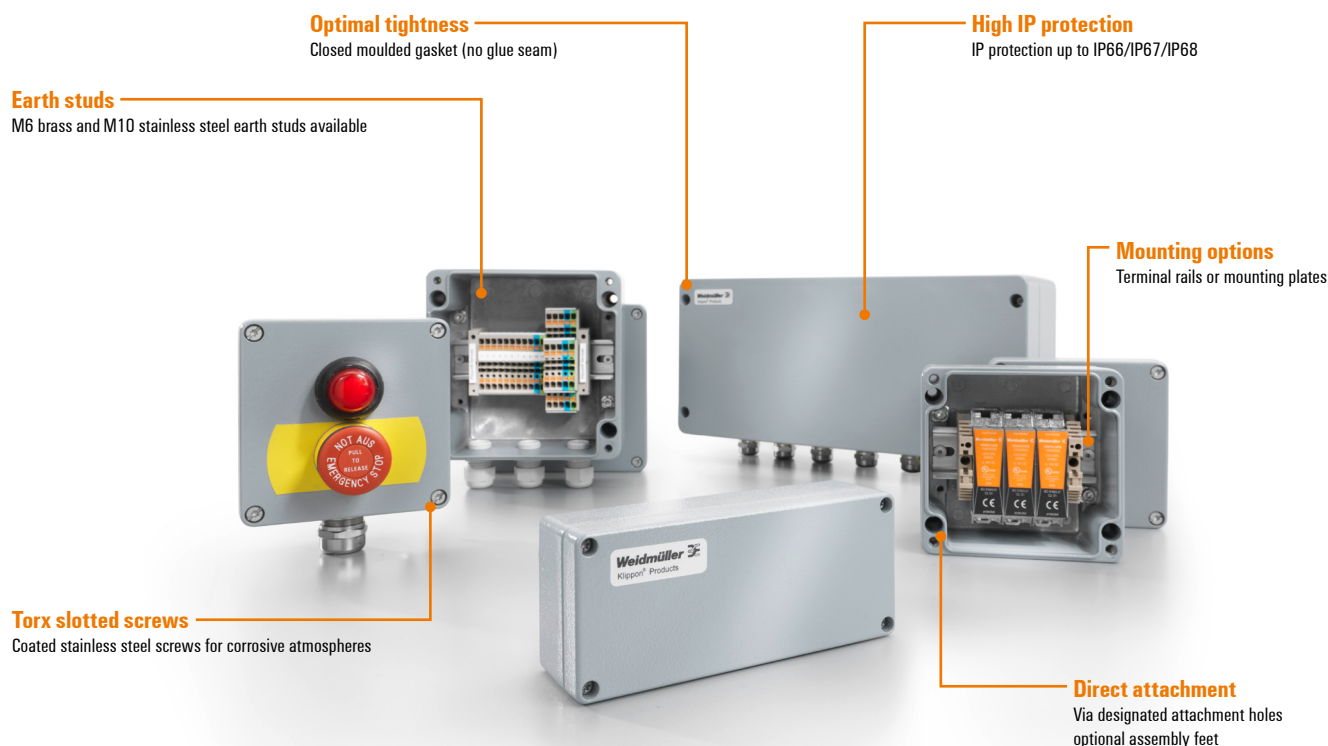

Product Overview

Description	Height x width x depth in mm	Powder-coated (RAL7001)			Unpainted		
		Standard		Ex enclosure	Standard		Ex enclosure
		CR moulded seal	Silicone moulded sea	Silicon moulded seal	CR moulded seal	Silicone moulded seal	Silicon moulded seal
Klippon® K 0	45 x 50 x 30	9529090000	1937920000		0573200000	1939760000	
Klippon® K 01	64 x 58 x 34	9529100000	1937850000		1565240000	1939540000	
Klippon® K 02	64 x 98 x 34	9529110000	1937840000		1565250000	1939550000	
Klippon® K 1	70 x 70 x 45	9529120000	1937630000	1329630000	0342000000	1939560000	9526840000
Klippon® K 11	80 x 75 x 57	9529130000	1937910000	1329640000	0573300000	1939570000	9526850000
Klippon® K 2	70 x 100 x 45	9529140000	1937930000	1329650000	0342100000	1939580000	9526860000
Klippon® K 21	80 x 125 x 57	9529150000	1937830000	1328120000	0573400000	1939590000	9526870000
Klippon® K 3	70 x 165 x 45	9529160000	1937900000	1329670000	0342200000	1939600000	9526880000
Klippon® K 31	80 x 175 x 57	9529170000	1937820000	1329680000	0573500000	1939610000	9526890000
Klippon® K 32	80 x 250 x 55	9529180000	1937810000	1329690000	1565260000	1939620000	9526900000
Klippon® K 4	82 x 130 x 72	9529190000	1937890000	1329700000	0342300000	1939630000	9526910000
Klippon® K 41	120 x 122 x 81	9529200000	1937800000	1329710000	1565270000	1939640000	9526920000
Klippon® K 42	140 x 140 x 91	2934110000	2934120000		2934130000	2934140000	
Klippon® K 5	130 x 170 x 90	9529210000	1937860000	1329720000	0342400000	1939650000	9526930000
Klippon® K 51	120 x 220 x 81	9529220000	1937750000	1328130000	1565280000	1939660000	9526940000
Klippon® K 52	160 x 160 x 91	9529230000	1937740000	1329730000	1565290000	1939670000	9526950000
Klippon® K 6	160 x 200 x 100	9529240000	1937870000	1329740000	0342500000	1939690000	9526960000
Klippon® K 61	160 x 260 x 91	9529250000	1937730000	1328140000	0573600000	1939700000	9526970000
Klippon® K 7	160 x 350 x 100	9529260000	1937880000	1329750000	0342600000	1939710000	9526980000
Klippon® K 71	230 x 280 x 111	9529270000	1937720000	1329770000	0573700000	1939730000	9526990000
Klippon® K 75	230 x 330 x 180	2934170000	2934180000		2934190000	2934200000	
Klippon® K 79	310 x 400 x 180	2934230000	2934240000		2934250000	2934260000	



For a detailed overview of the products, visit
www.weidmueller.com/klipponk
 or scan the QR code.



You can find this product family
 in our Weidmüller Configurator:
www.weidmueller.com/wmc