
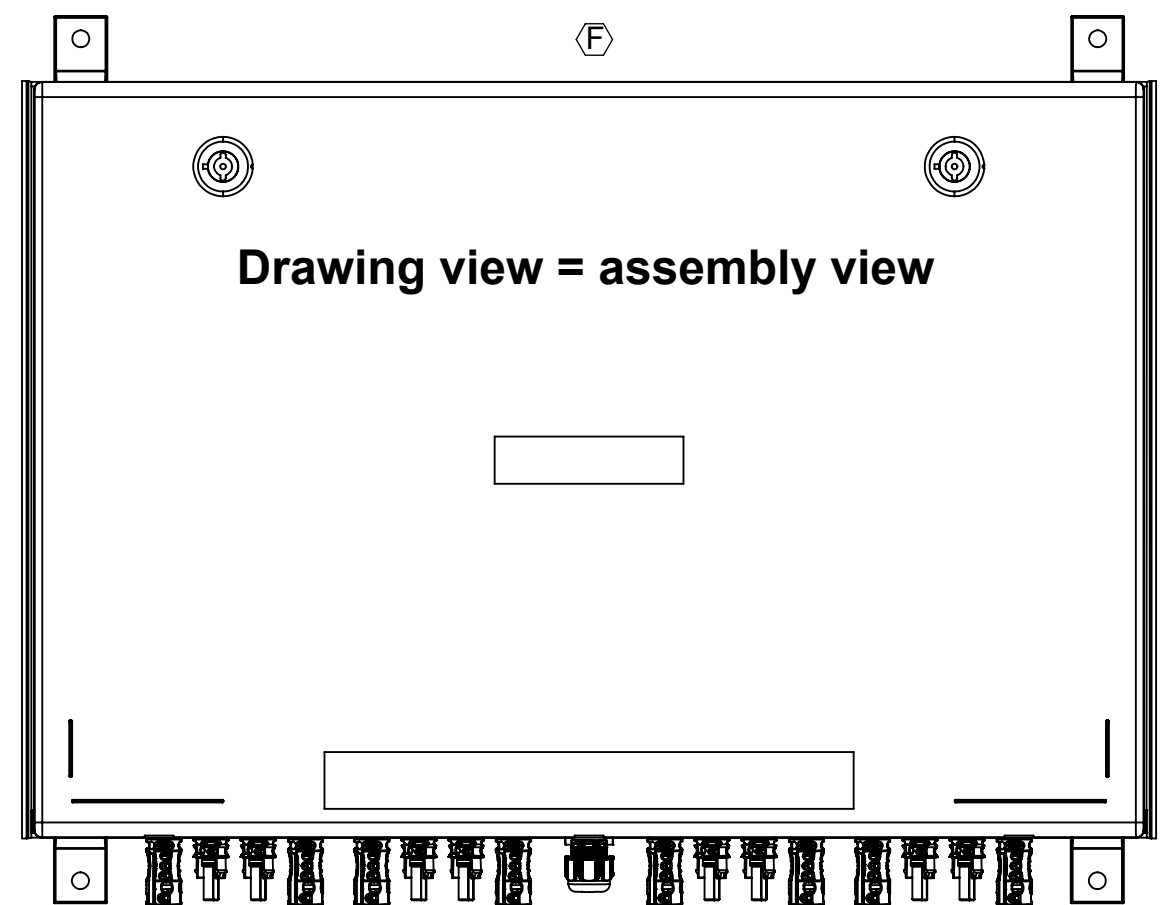
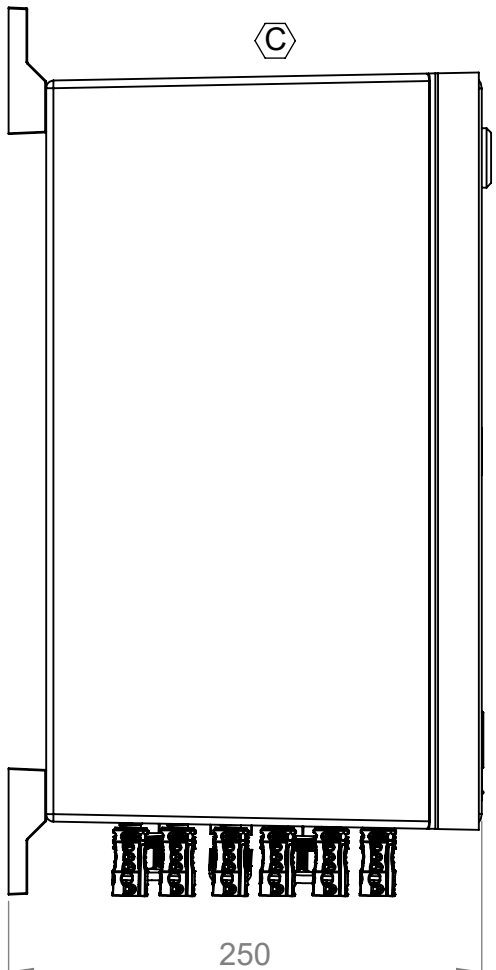
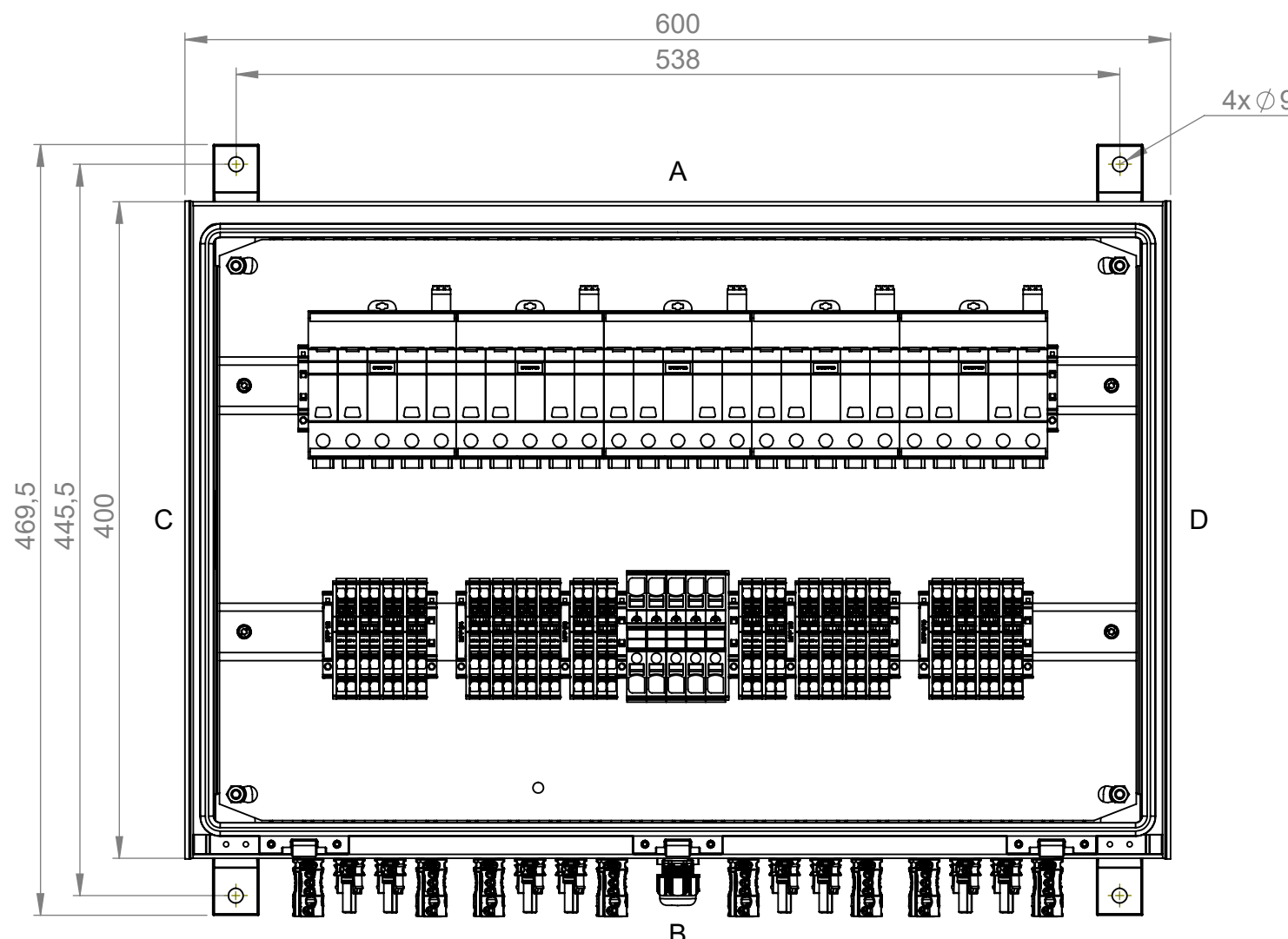
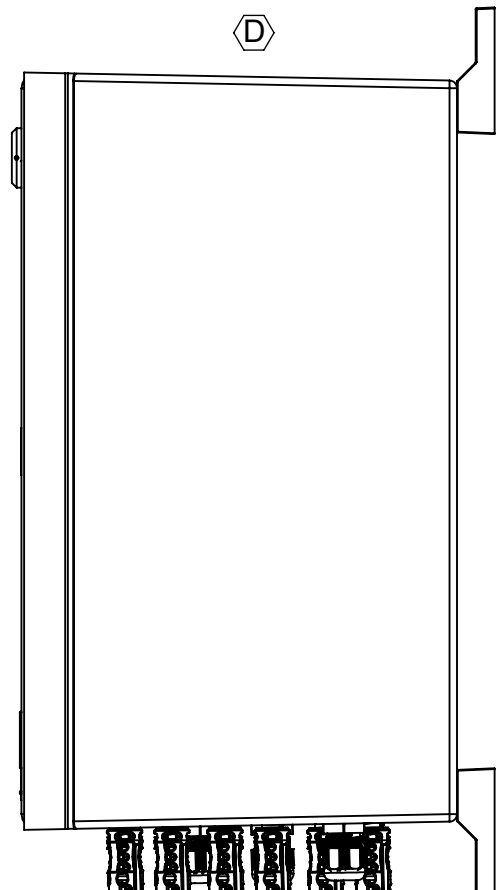
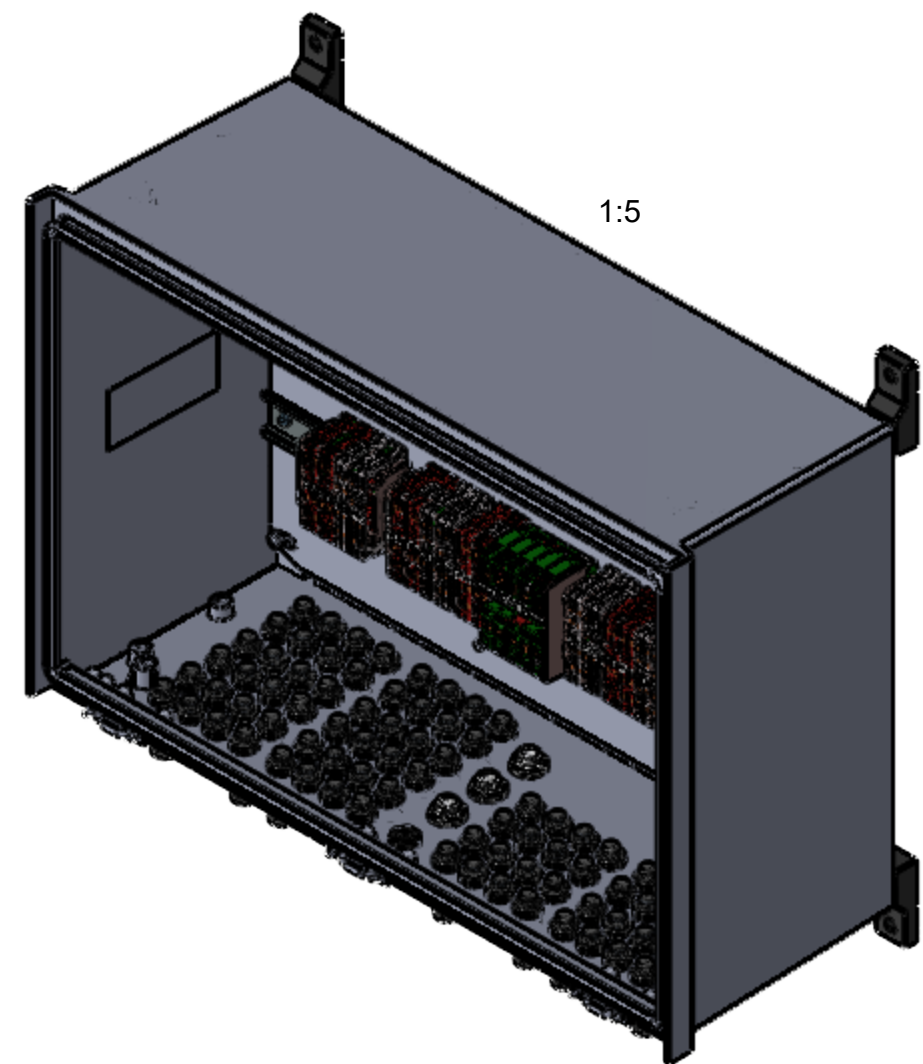


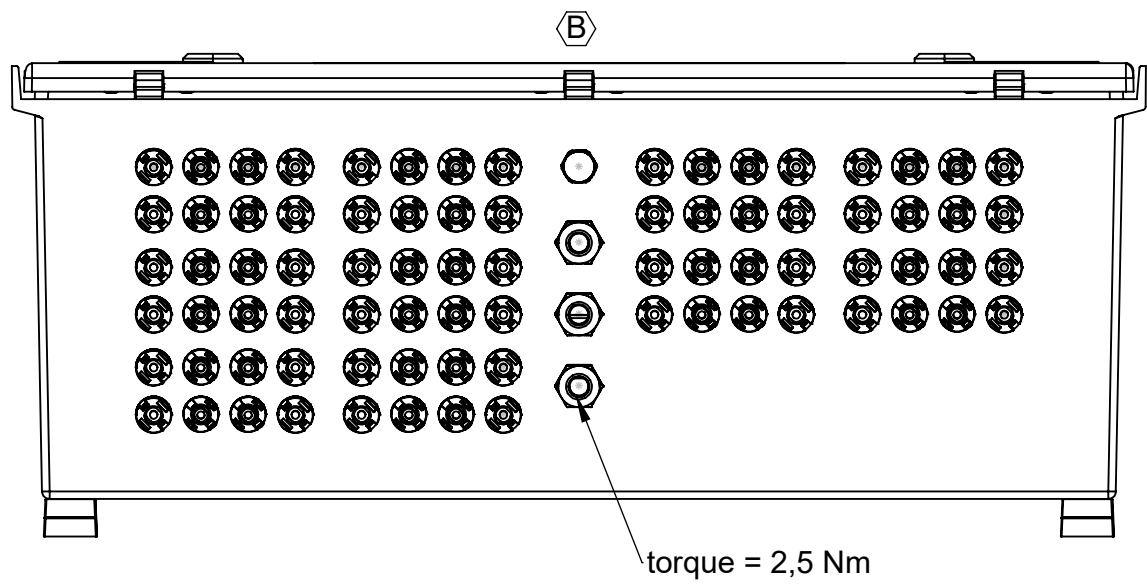

technical details:
Up to 10 MPPT (Maximum Power Point Tracking)
2x DC Input per MPPT
2x DC Output per MPPT

Connection type:
Plug-MC4-EVO2

Surge voltage arrester
PV system voltage max.: 1100V DC
Requirements class: Type I+II
with remote contact

Rated DC voltage (Un): 1100 V
Rated DC current per input (Inc): 32 A
Rated short-time withstand current per input: 1.25 x Inc
Rated total DC current per MPPT (I out max.): 32 A
Operation ambient temperature: -20°C to +50°C
Degree of Protection: IP65, no direct sunlight

Additional Product Documents				1.	Tolerances: ISO 2768-mK			
-	-	-	-	2.				
-	-	-	-	Drawn	Date	Name	Weidmüller 	
-	-	-	-	Checked	08.02.2023	wm00674		
-	-	-	-	14.02.2023	W007064	Criterion for print		Description:
-	-	-	-	1:4	A2	PVC DC 2I 2O 10MPP SPD1R EVO 11		
-	-	-	-	Customer:		Drawing-No / Material-No:		drw Index
-	-	-	-	Customer-No:		8000107559		Sheet
1	Index		Brief Description	Date	Name	Customer Description: -		0 1 / 1