


Klippon® Relay

Simple and time-saving installation of relay modules

Advantages and overview of the complete modules

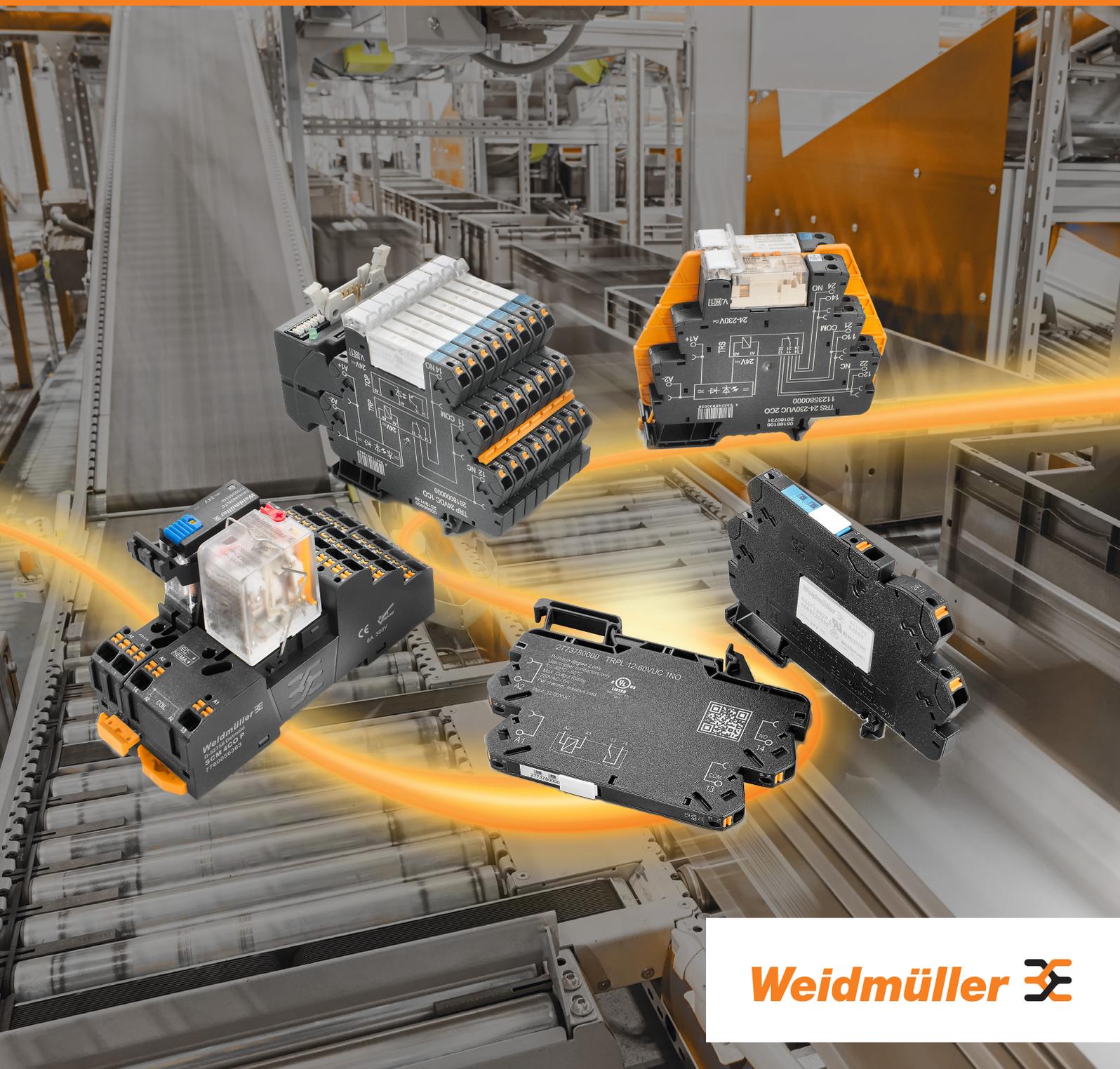



Switch to **efficient** - with Klippon® Relay
Innovative relay solutions for fast and easy wiring

Klippon® Relay products are easy, fast, and convenient to install. The PUSH IN technology shortens wiring times. And our fully assembled and tested relay KITS save time during installation and commissioning.



Complete modules

Pre-assembled and 100 % function tested KITS

Relay KITS consisting of relays with status indicator and socket with retaining clip provide greater convenience. The KITS are delivered completely assembled as well as function and insulation tested. This saves time and reduces the number of material numbers because the sets are under one article number and reduce the number of stock places.

- KIT consisting of relay, socket and retaining clip
- 100 % function tested
- 100 % check of the dielectric strength between input - output

Your advantages
Simple and time-saving installation, fast availability and reduced warehousing!

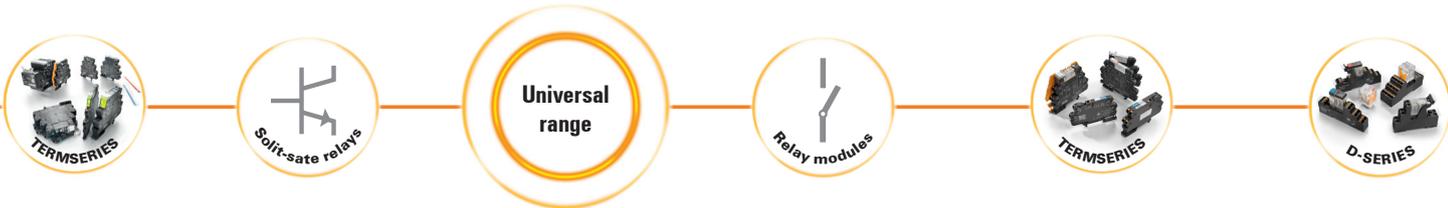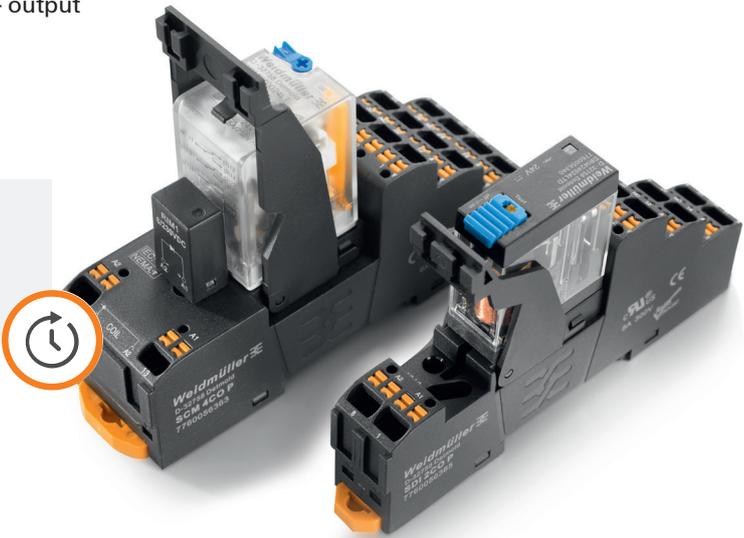

Visit our website for more information
www.weidmueller.com/klipponrelay

D-SERIES

Highly reliable industrial relays

Approvals KITs



Additional approvals of the individual parts



D-SERIES - DRI



PUSH IN KITs - 1 CO contact - 10 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRIKITP 24VDC 1CO LD/PB	24 V DC	●	●	●	10	2576210000
DRIKITP 24VDC 1CO LD	24 V DC	●	●		10	2576220000
DRIKITP 24VAC 1CO LD/PB	24 V AC	●		●	10	2576250000
DRIKITP 24VAC 1CO LD	24 V AC	●			10	2576260000
DRIKITP 115VAC 1CO LD/PB	115 V AC	●		●	10	2576180000
DRIKITP 115VAC 1CO LD	115 V AC	●			10	2575980000
DRIKITP 230VAC 1CO LD/PB	230 V AC	●		●	10	2576160000
DRIKITP 230VAC 1CO LD	230 V AC	●			10	2576280000



Screw KITs - 1 CO contact - 10 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRIKIT 24VDC 1CO LD/PB	24 V DC	●	●	●	10	2476750000
DRIKIT 24VDC 1CO LD	24 V DC	●	●		10	2476680000
DRIKIT 24VAC 1CO LD/PB	24 V AC	●		●	10	2476780000
DRIKIT 24VAC 1CO LD	24 V AC	●			10	2476710000
DRIKIT 115VAC 1CO LD/PB	115 V AC	●		●	10	2476790000
DRIKIT 115VAC 1CO LD	115 V AC	●			10	2476720000
DRIKIT 230VAC 1CO LD/PB	230 V AC	●		●	10	2476800000
DRIKIT 230VAC 1CO LD	230 V AC	●			10	2476730000

D-SERIES - DRM



PUSH IN KITs - 2 CO contact - 10 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRMKITP 24VDC 2CO LD/PB	24 V DC	●	●	●	10	2576120000
DRMKITP 24VDC 2CO LD	24 V DC	●	●		10	2576110000
DRMKITP 24VAC 2CO LD/PB	24 V AC	●		●	10	2576080000
DRMKITP 24VAC 2CO LD	24 V AC	●			10	2576070000
DRMKITP 115VAC 2CO LD/PB	115 V AC	●		●	10	2576000000
DRMKITP 115VAC 2CO LD	115 V AC	●			10	2575990000
DRMKITP 230VAC 2CO LD/PB	230 V AC	●		●	10	2576040000
DRMKITP 230VAC 2CO LD	230 V AC	●			10	2576030000



Screw KITs - 2 CO contact - 10 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRMKIT 24VDC 2CO LD/PB	24 V DC	●	●	●	10	1542460000
DRMKIT 24VDC 2CO LD	24 V DC	●	●		10	1542360000
DRMKIT 24VAC 2CO LD	24 V AC	●		●	10	1542380000
DRMKIT 24VAC 2CO LD/PB	24 V AC	●			10	1542480000
DRMKIT 230VAC 2CO LD/PB	230 V AC	●		●	10	1542490000
DRMKIT 230VAC 2CO LD	230 V AC	●			10	1542390000



PUSH IN KITs - 2 CO contact - 5 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRIKITP 24VDC 2CO LD/PB	24 V DC	●	●	●	10	2576190000
DRIKITP 24VDC 2CO LD	24 V DC	●	●		10	2576200000
DRIKITP 24VAC 2CO LD/PB	24 V AC	●		●	10	2576230000
DRIKITP 24VAC 2CO LD	24 V AC	●			10	2576240000
DRIKITP 115VAC 2CO LD/PB	115 V AC	●		●	10	2576170000
DRIKITP 115VAC 2CO LD	115 V AC	●			10	2576290000
DRIKITP 230VAC 2CO LD/PB	230 V AC	●		●	10	2576150000
DRIKITP 230VAC 2CO LD	230 V AC	●			10	2576270000



Screw KITs - 2 CO contact - 5 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRIKIT 24VDC 2CO LD/PB	24 V DC	●	●	●	10	2476890000
DRIKIT 24VDC 2CO LD	24 V DC	●	●		10	2476820000
DRIKIT 24VAC 2CO LD/PB	24 V AC	●		●	10	2476920000
DRIKIT 24VAC 2CO LD	24 V AC	●			10	2476850000
DRIKIT 115VAC 2CO LD/PB	115 V AC	●		●	10	2476930000
DRIKIT 115VAC 2CO LD	115 V AC	●			10	2476860000
DRIKIT 230VAC 2CO LD/PB	230 V AC	●		●	10	2476940000
DRIKIT 230VAC 2CO LD	230 V AC	●			10	2476870000



PUSH IN KITs - 4 CO contact - 5 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRMKITP 24VDC 4CO LD/PB	24 V DC	●	●	●	10	2576140000
DRMKITP 24VDC 4CO LD	24 V DC	●	●		10	2576130000
DRMKITP 24VAC 4CO LD/PB	24 V AC	●		●	10	2576100000
DRMKITP 24VAC 4CO LD	24 V AC	●			10	2576090000
DRMKITP 115VAC 4CO LD/PB	115 V AC	●		●	10	2576020000
DRMKITP 115VAC 4CO LD	115 V AC	●			10	2576010000
DRMKITP 230VAC 4CO LD/PB	230 V AC	●		●	10	2576060000
DRMKITP 230VAC 4CO LD	230 V AC	●			10	2576050000



Screw KITs - 4 CO contact - 5 A

Type	Rated control voltage	LED	Diode	Test button	Qty	Order No.
DRMKIT 24VDC 4CO LD	24 V DC	●	●	●	10	1542410000
DRMKIT 24VDC 4CO LD/PB	24 V DC	●	●		10	1542510000
DRMKIT 24VAC 4CO LD	24 V AC	●		●	10	1542430000
DRMKIT 24VAC 4CO LD/PB	24 V AC	●			10	1542530000
DRMKIT 230VAC 4CO LD	230 V AC	●		●	10	1542450000
DRMKIT 230VAC 4CO LD/PB	230 V AC	●			10	1542540000



Exemplary product selection

You can find more products in the online catalogue

TERMSERIES-compact

Universally usable relays for industrial applications

Approvals KITs



PUSH IN - 1 CO - 6 A

Type	Rated control voltage	contact material	Qty	Order No.
TRPL 5VDC 1CO	5 V DC	AgNi	10	2774030000
TRPL 24VDC 1CO	24 V DC	AgNi	10	2773890000
TRPL 24VUC 1CO	24 V UC	AgNi	10	2773970000
TRPL 12-60VUC 1CO	12-60 V UC	AgNi	10	2773770000
TRPL 24-230VUC 1CO	24-230 V UC	AgNi	10	2773860000
TRPL 120VAC 1CO	120 V AC	AgNi	10	2773800000
TRPL 230VAC 1CO	230 V AC	AgNi	10	2773830000



PUSH IN - 1 NO - 6 A

Type	Rated control voltage	contact material	Qty	Order No.
TRPL 5VDC 1NO	5 V DC	AgNi	10	2774040000
TRPL 24VDC 1NO	24 V UC	AgNi	10	2773920000
TRPL 24VUC 1NO	24 V UC	AgNi	10	2773980000
TRPL 12-60VUC 1NO	12-60 V UC	AgNi	10	2773780000
TRPL 24-230VUC 1NO	24-230 V UC	AgNi	10	2773870000
TRPL 120VAC 1NO	120 V AC	AgNi	10	2773810000
TRPL 230VAC 1NO	230 V AC	AgNi	10	2773840000



PUSH IN - 1 NO with FUSE - 6 A

Type	Rated control voltage	contact material	Qty	Order No.
TRPL 24VDC 1NO F	24 V DC	AgNi	10	2773930000

TERMSERIES-compact

TERMSERIES-compact FUSE



Exemplary product selection

You can find more products in the online catalogue

TERMSERIES

The slim all-rounder



PUSH IN KITS – 1 CO contact – 6 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRP 24VDC 1CO	24 V DC	AgNi	10	2618000000
TRP 24VUC 1CO	24 V UC	AgNi	10	2618220000
TRP 120VUC 1CO	120 V UC	AgNi	10	2618150000
TRP 230VUC 1CO	230 V UC	AgNi	10	2618200000
TRP 24-230VUC 1CO ED2	24-230 V UC	AgNi	10	2663010000
TRP 24VDC 1CO AU	24 V DC	AgNi Au	10	2618110000
TRP 24VUC 1CO AU	24 V UC	AgNi Au	10	2618160000
TRP 120VAC RC 1CO AU	120 V AC	AgNi Au	10	2618030000
TRP 230VAC RC 1CO AU	230 V AC	AgNi Au	10	2617950000
TRP 24-230VUC 1CO AU ED2	24-230 V UC	AgNi Au	10	2663020000
TRP 24VDC 1CO AGSNO	24 V DC	AgSnO	10	2618020000
TRP 24VUC 1CO AGSNO	24 V UC	AgSnO	10	2617880000
TRP 120VAC RC 1CO AGSNO	120 V AC	AgSnO	10	2617840000
TRP 230VAC RC 1CO AGSNO	230 V AC	AgSnO	10	2617850000
TRP 24-230VUC 1CO AGSNO ED2	24-230 V UC	AgSnO	10	2663160000

PUSH IN KITS – 1 CO contact with test button – 6 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRP 24VDC 1CO AGSNO PB	24 V DC	AgSnO	10	2855800000
TRP 24VUC 1CO AGSNO PB	24 V UC	AgSnO	10	2855810000
TRP 24-230VUC 1CO AGSNO ED2 PB	24-230 V UC	AgSnO	10	2855910000
TRP 24VDC 1CO AGSNO AU PB	24 V DC	AgSnO Au	10	2855830000
TRP 24VUC 1CO AGSNO AU PB	24 V UC	AgSnO Au	10	2855820000
TRP 24-230VUC 1CO AGSNO AU ED2 PB	24-230 V UC	AgSnO Au	10	2855900000

PUSH IN KITS – 1 CO contact – 16 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRP 24VDC 1CO 16A	24 V DC	AgNi	10	2618100000
TRP 24VUC 1CO 16A	24 V UC	AgNi	10	2617910000
TRP 120VAC RC 1CO 16A	120 V AC	AgNi	10	2618270000
TRP 230VAC RC 1CO 16A	230 V AC	AgNi	10	2618190000
TRP 24-230VUC 1CO 16A ED2	24-230 V UC	AgNi	10	2663160000

PUSH IN KITS – 2 CO contact – 8 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRP 24VDC 2CO	24 V DC	AgNi	10	2618400000
TRP 24VUC 2CO	24 V UC	AgNi	10	2618320000
TRP 120VAC RC 2CO	120 V AC	AgNi	10	2618470000
TRP 230VAC RC 2CO	230 V AC	AgNi	10	2618330000
TRP 24-230VUC 2CO ED2	24-230 V UC	AgNi	10	2663040000
TRP 24VDC 2CO AU	24 V DC	AgNi Au	10	2618530000
TRP 24VUC 2CO AU	24 V UC	AgNi Au	10	2618540000
TRP 120VAC RC 2CO AU	120 V AC	AgNi Au	10	2618490000
TRP 230VAC RC 2CO AU	230 V AC	AgNi Au	10	2618500000
TRP 24-230VUC 2CO AU ED2	24-230 V UC	AgNi Au	10	2663050000



Screw KITS – 1 CO contact – 6 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRS 24VDC 1CO	24 V DC	AgNi	10	1122770000
TRS 24VUC 1CO	24 V UC	AgNi	10	1122780000
TRS 120VUC 1CO	120 V UC	AgNi	10	1122830000
TRS 230VUC 1CO	230 V UC	AgNi	10	1122840000
TRS 24-230VUC 1CO ED2	24-230 V UC	AgNi	10	2662850000
TRS 24VDC 1CO AU	24 V DC	AgNi Au	10	1123000000
TRS 24VUC 1CO AU	24 V UC	AgNi Au	10	1123010000
TRS 120VAC RC 1CO AU	120 V AC	AgNi Au	10	1123070000
TRS 230VAC RC 1CO AU	230 V AC	AgNi Au	10	1123080000
TRS 24-230VUC 1CO AU ED2	24-230 V UC	AgNi Au	10	2662860000
TRS 24VDC 1CO AGSNO	24 V DC	AgSnO	10	1984540000
TRS 24VUC 1CO AGSNO	24 V UC	AgSnO	10	2152940000
TRS 120VAC RC 1CO AGSNO	120 V AC	AgSnO	10	2152900000
TRS 230VAC RC 1CO AGSNO	230 V AC	AgSnO	10	2152920000
TRS 24-230VUC 1CO AGSNO ED2	24-230 V UC	AgSnO	10	2663000000

Screw KITS – 1 CO contact with test button – 6 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRS 24VDC 1CO AGSNO PB	24 V DC	AgSnO	10	2855870000
TRS 24VUC 1CO AGSNO PB	24 V UC	AgSnO	10	2855890000
TRS 24-230VUC 1CO AGSNO ED2 PB	24-230 V UC	AgSnO	10	2855930000
TRS 24VDC 1CO AGSNO AU PB	24 V DC	AgSnO Au	10	2855860000
TRS 24VUC 1CO AGSNO AU PB	24 V UC	AgSnO Au	10	2855880000
TRS 24-230VUC 1CO AGSNO AU ED2 PB	24-230 V UC	AgSnO Au	10	2855920000

Screw KITS – 1 CO contact – 16 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRS 24VDC 1CO 16A	24 V DC	AgNi	10	1479680000
TRS 24VUC 1CO 16A	24 V UC	AgNi	10	1479690000
TRS 120VAC RC 1CO 16A	120 V AC	AgNi	10	1479750000
TRS 230VAC RC 1CO 16A	230 V AC	AgNi	10	1479760000
TRS 24-230VUC 1CO AU ED2	24-230 V UC	AgNi	10	2662960000

Screw KITS – 2 CO contact – 8 A

Type	Rated control voltage	Contact material	Qty	Order No.
TRS 24VDC 2CO	24 V DC	AgNi	10	1123490000
TRS 24VUC 2CO	24 V UC	AgNi	10	1123500000
TRS 120VAC RC 2CO	120 V AC	AgNi	10	1123550000
TRS 230VAC RC 2CO	230 V AC	AgNi	10	1123570000
TRS 24-230VUC 2CO ED2	24-230 V UC	AgNi	10	2662880000
TRS 24VDC 2CO AU	24 V DC	AgNi Au	10	1123730000
TRS 24VUC 2CO AU	24 V UC	AgNi Au	10	1123740000
TRS 120VAC RC 2CO AU	120 V AC	AgNi Au	10	1123800000
TRS 230VAC RC 2CO AU	230 V AC	AgNi Au	10	1123810000
TRS 24-230VUC 2CO AU ED2	24-230 V UC	AgNi Au	10	2662890000

TERMSERIES - electromechanical relays 6.4 mm

TERMSERIES - electromechanical relays 12.8 mm



Exemplary product selection

You can find more products in the online catalogue

Approvals



PUSH IN KITS - 1 NO bipolar transistor



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOP 24VDC 48VDC0.1A	24 V DC	0,1 A	3..48 V DC	10	2618790000
TOP 24VUC 48VDC0.1A	24 V UC	0,1 A	3..48 V DC	10	2618640000
TOP 120VAC RC 48VDC0.1A	120 V AC	0,1 A	3..48 V DC	10	2618650000
TOP 230VAC RC 48VDC0.1A	230 V AC	0,1 A	3..48 V DC	10	2618620000
TOP 24-230VUC 48VDC0.1A ED2	24-230 V UC	0,1 A	3..48 V DC	10	2663070000

PUSH IN KITS - 1 NO MOS-FET



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOP 24VDC 24VDC2A	24 V DC	2 A	3..33 V DC	10	2618720000
TOP 24VUC 24VDC2A	24 V UC	2 A	3..33 V DC	10	2618730000
TOP 120VAC RC 24VDC2A	120 V AC	2 A	3..33 V DC	10	2618660000
TOP 230VAC RC 24VDC2A	230 V AC	2 A	3..33 V DC	10	2618670000
TOP 24-230VUC 24VDC2A ED2	24-230 V UC	2 A	3..33 V DC	10	2663080000

PUSH IN KITS - 1 NO Triac (Zero-voltage switching)



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOP 24VDC 230VAC1A	24 V DC	1 A	24..240 V AC	10	2618420000
TOP 24VUC 230VAC1A	24 V UC	1 A	24..240 V AC	10	2618350000
TOP 120VAC RC 230VAC1A	120 V AC	1 A	24..240 V AC	10	2618390000
TOP 230VAC RC 230VAC1A	230 V AC	1 A	24..240 V AC	10	2618430000
TOP 24-230VUC 230VAC1A ED2	24-230 V UC	1 A	24..240 V AC	10	2663090000

PUSH IN KITS - 1 NO MOS-FET



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOP 24VDC 24VDC3.5A	24 V DC	3,5 A	3..33 V DC	10	2618700000
TOP 24-230VUC 24VDC3.5A ED2	24-230 V UC	3,5 A	3..33 V DC	10	2663100000

PUSH IN KITS - 1 NO MOS-FET



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOP 24VDC 24VDC5A	24 V DC	5 A	3..33 V DC	10	2618840000
TOP 24-230VUC 24VDC5A ED2	24-230 V UC	5 A	3..33 V DC	10	2663150000

Screw KITS - 1 NO bipolar transistor



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOS 24VDC 48VDC0.1A	24 V DC	0,1 A	3..48 V DC	10	1126940000
TOS 24VUC 48VDC0.1A	24 V UC	0,1 A	3..48 V DC	10	1126950000
TOS 120VAC RC 48VDC0.1A	120 V AC	0,1 A	3..48 V DC	10	1127000000
TOS 230VAC RC 48VDC0.1A	230 V AC	0,1 A	3..48 V DC	10	1127010000
TOS 24-230VUC 48VDC0.1A ED2	24-230 V UC	0,1 A	3..48 V DC	10	2662910000

Screw KITS - 1 NO MOS-FET



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOS 24VDC 24VDC2A	24 V DC	2 A	3..33 V DC	10	1127170000
TOS 24VUC 24VDC2A	24 V UC	2 A	3..33 V DC	10	1127180000
TOS 120VAC RC 24VDC2A	120 V AC	2 A	3..33 V DC	10	1127230000
TOS 230VAC RC 24VDC2A	230 V AC	2 A	3..33 V DC	10	1127240000
TOS 24-230VUC 24VDC2A ED2	24-230 V UC	2 A	3..33 V DC	10	2662920000

Screw KITS - 1 NO Triac (Zero-voltage switching)



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOS 24VDC 230VAC1A	24 V DC	1 A	24..240 V AC	10	1127410000
TOS 24VUC 230VAC1A	24 V UC	1 A	24..240 V AC	10	1127420000
TOS 120VAC RC 230VAC1A	120 V AC	1 A	24..240 V AC	10	1127480000
TOS 230VAC RC 230VAC1A	230 V AC	1 A	24..240 V AC	10	1127490000
TOS 24-230VUC 230VAC1A ED2	24-230 V UC	1 A	24..240 V AC	10	2662930000

Screw KITS - 1 NO MOS-FET



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOS 24VDC 24VDC3.5A	24 V DC	3,5 A	3..33 V DC	10	1127630000
TOS 24-230VUC 24VDC3.5A ED2	24-230 V UC	3,5 A	3..33 V DC	10	2662940000

Screw KITS - 1 NO MOS-FET



Type	Rated control voltage	Continuous current	Rated switching voltage	Qty	Order No.
TOS 24VDC 24VDC5A	24 V DC	5 A	3..33 V DC	10	1990960000
TOS 24-230VUC 24VDC5A ED2	24-230 V UC	5 A	3..33 V DC	10	2662990000



Exemplary product selection

You can find more products in the online catalogue

Weidmüller – Your partner in Smart Industrial Connectivity

As experienced experts we support our customers and partners around the world with products, solutions and services in the industrial environment of power, signal and data. We are at home in their industries and markets and know the technological challenges of tomorrow. We are therefore continuously developing innovative, sustainable and useful solutions for their individual needs. Together we set standards in Industrial Connectivity.

We cannot guarantee that there are no mistakes in the publications or software provided by us to the customer for the purpose of making orders. We try our best to quickly correct errors in our printed media.

All orders are based on our general terms of delivery, which can be reviewed on the websites of our group companies where you place your order. On demand we can also send the general terms of delivery to you.