
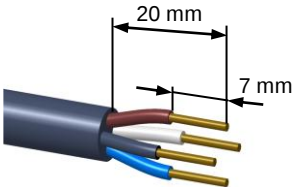


Zugfederanschluss / Tension clamp connection

Montagehinweis / Mounting information / Référence de montage / Indicaciones de montaje /
 Infomazioni per il montaggio

1

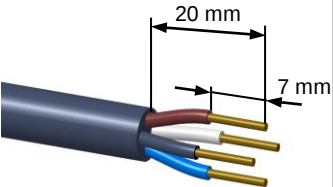

1a	Gerade / Straight	1a	Gewinkelt / Angled
			

2



9025750000 (0,34 mm²) 9011460000 - PZ 6/5

Aderquerschnitte / Connection cross-section: 0.14 ... 0.75mm² Empfohlen / Recommended: 0.34 mm²	
---	--

2a



3



3a



In der Lieferung enthalten
 Included in the delivery

4



4a 4b

4a	Anzugsdrehmoment Kopf - Gehäuse Tightening torque head - housing	
	Kunststoffgehäuse / plastic housing Metallgehäuse / metal housing	0,8 Nm 0,6 - 0,8 Nm
4b	Anzugsdrehmoment Kabelverschraubung Tightening torque cable gland	
	4 – 5 mm Kabel / cable Ø 5 – 6 mm Kabel / cable Ø 6 – 7 mm Kabel / cable Ø 7 – 8 mm Kabel / cable Ø 8 – 12 mm Kabel / cable Ø	0,8 - 1 Nm 0,8 - 1 Nm 0,8 - 1 Nm 0,8 - 1 Nm 1 - 1,4 Nm