


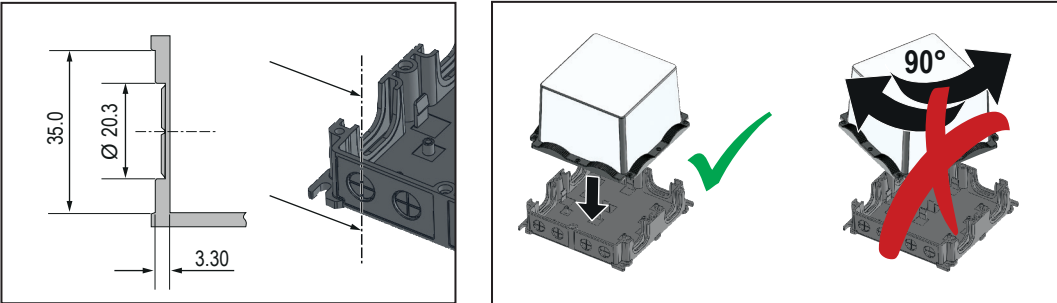
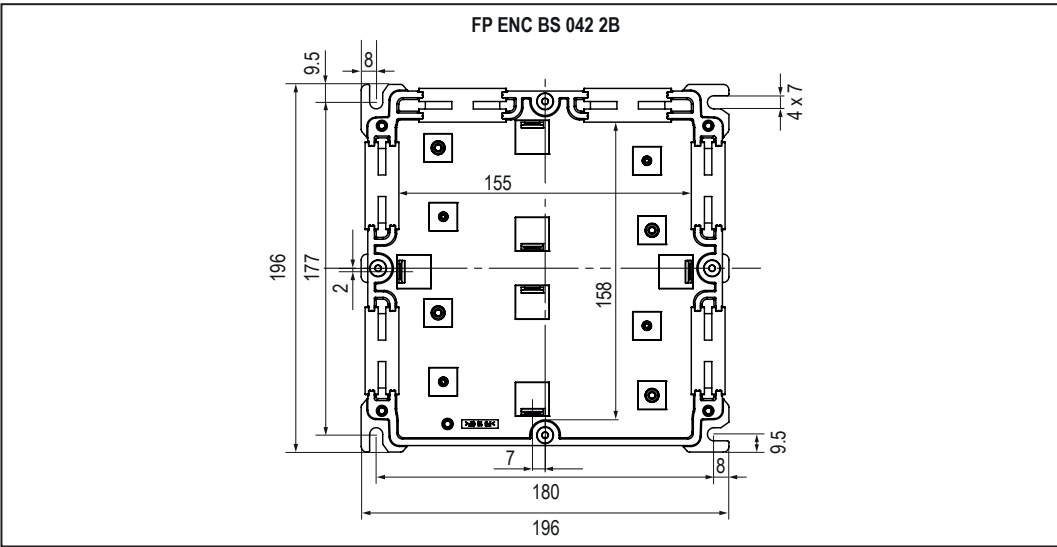
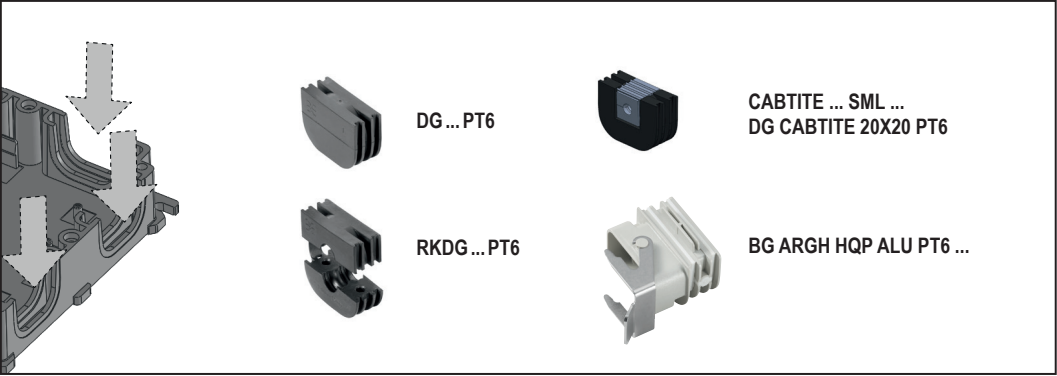
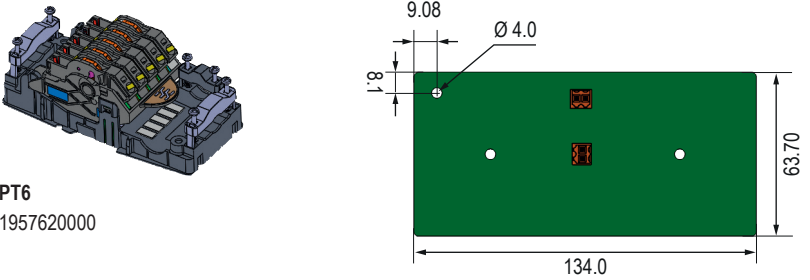
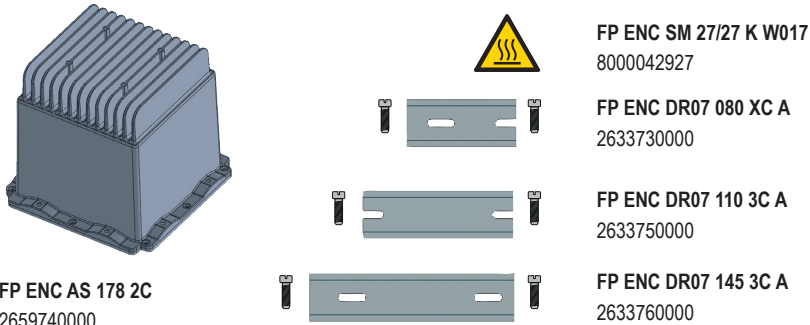
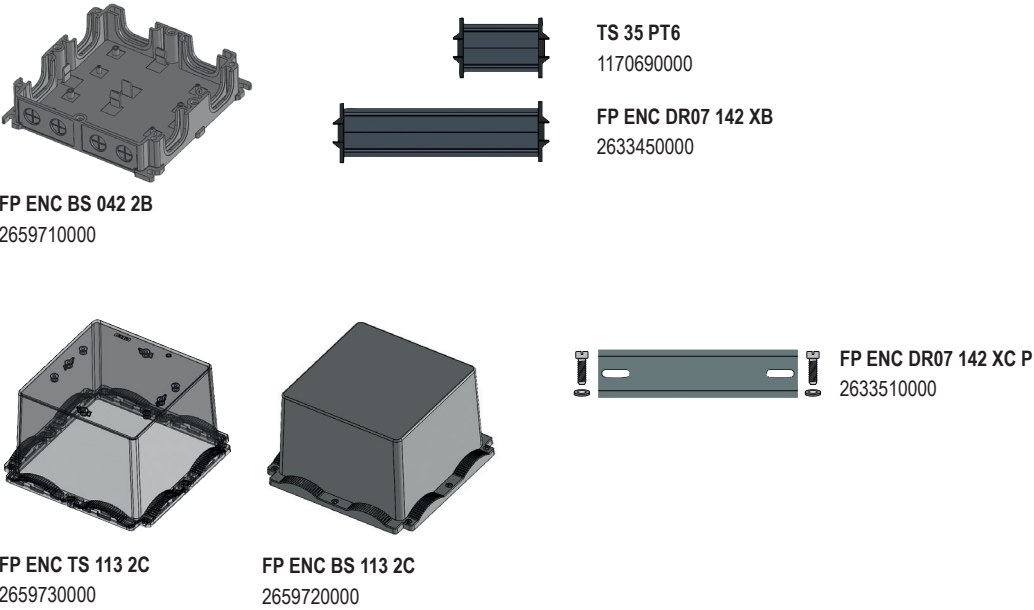
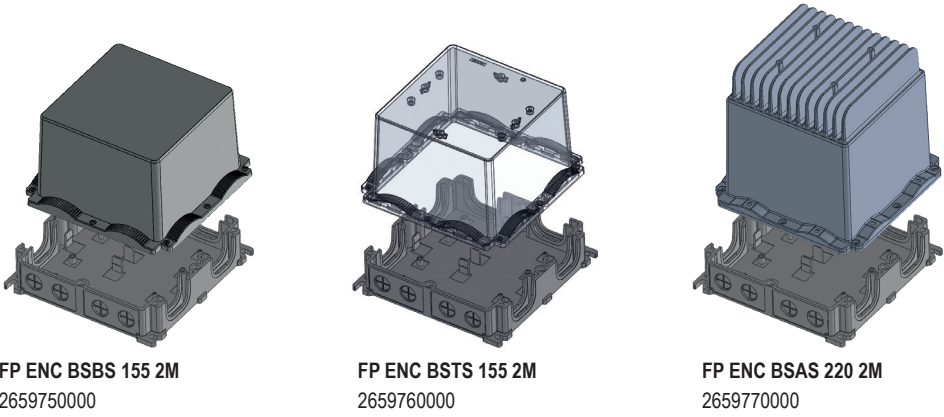
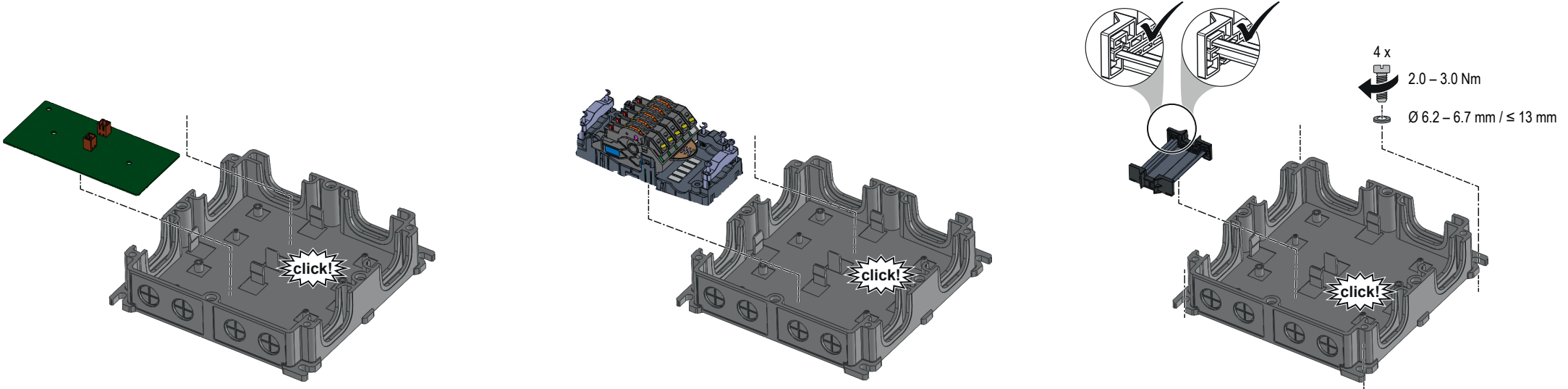
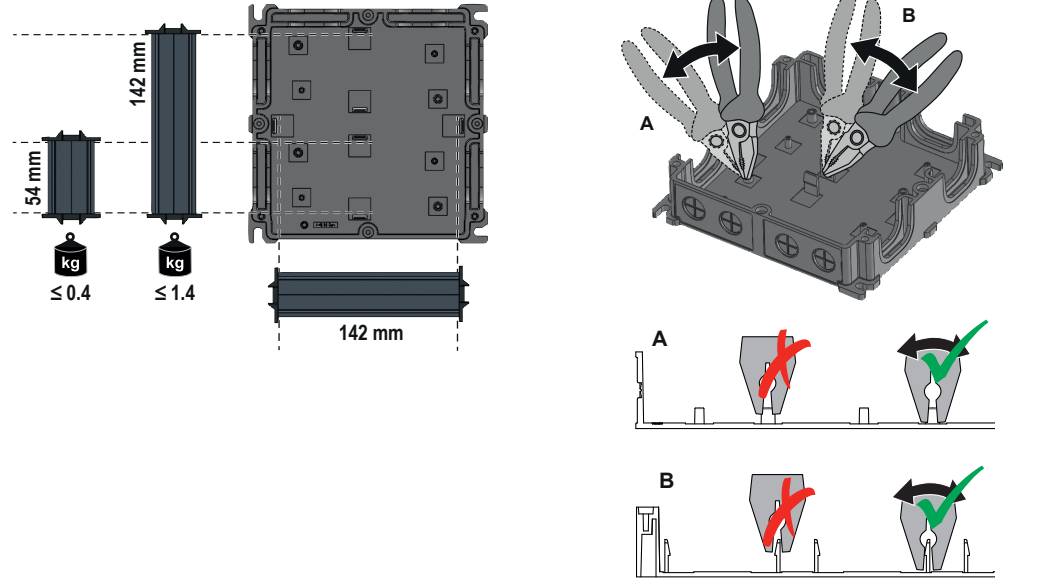
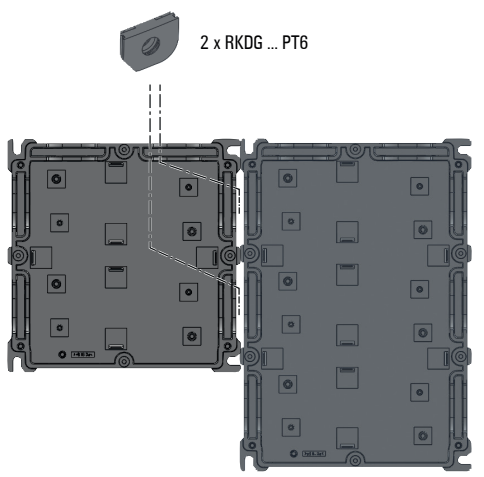
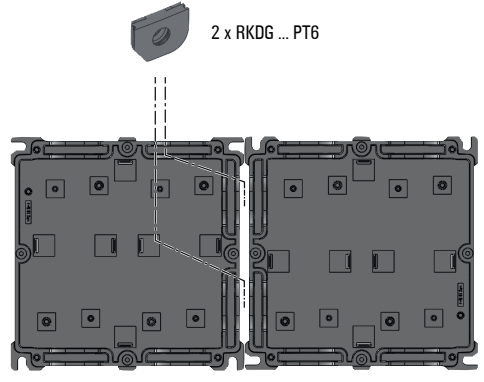
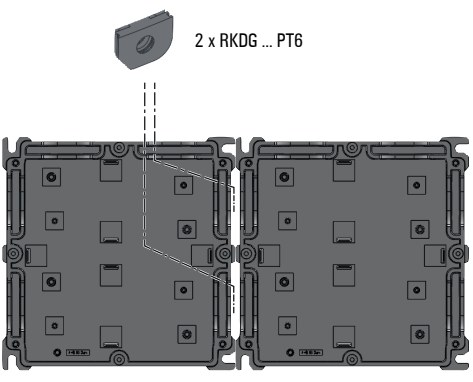
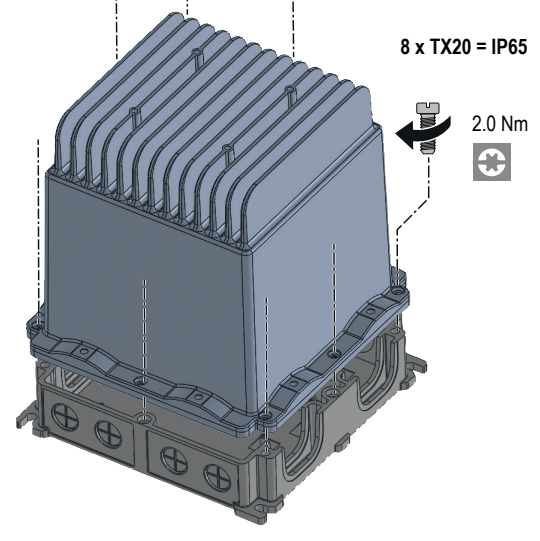
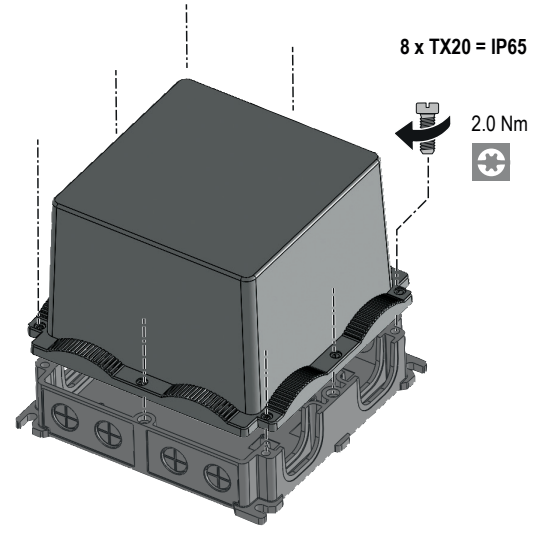
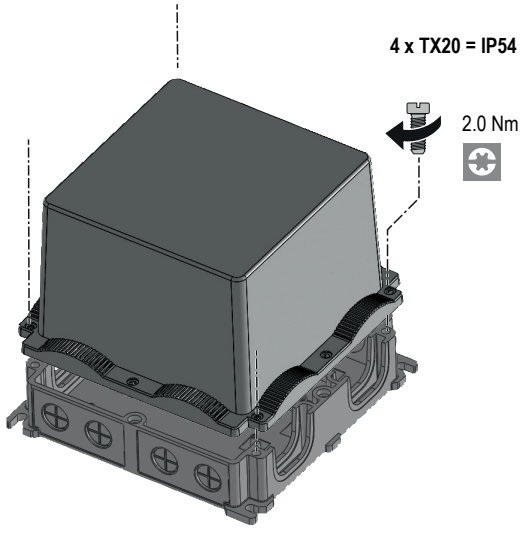
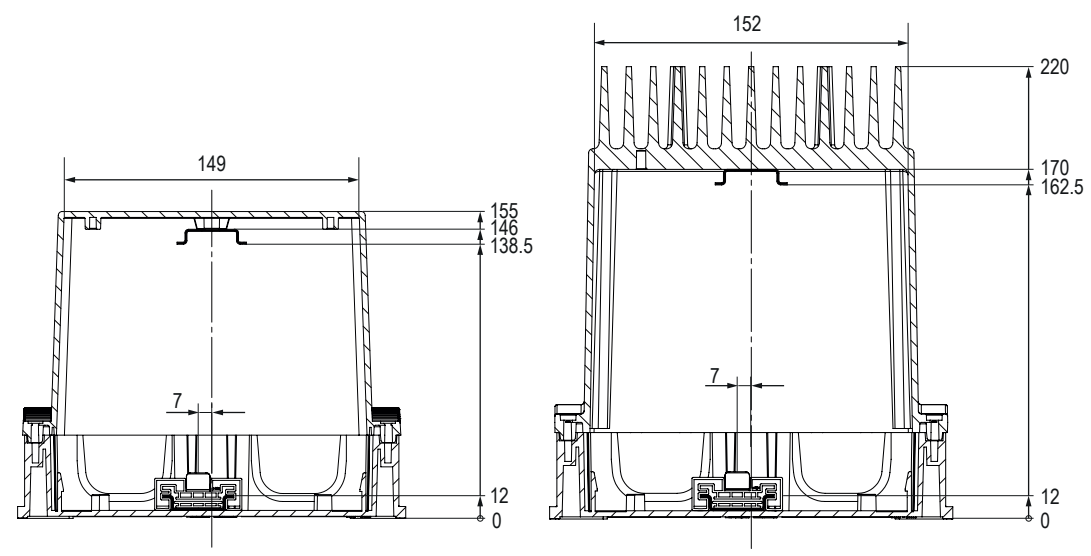


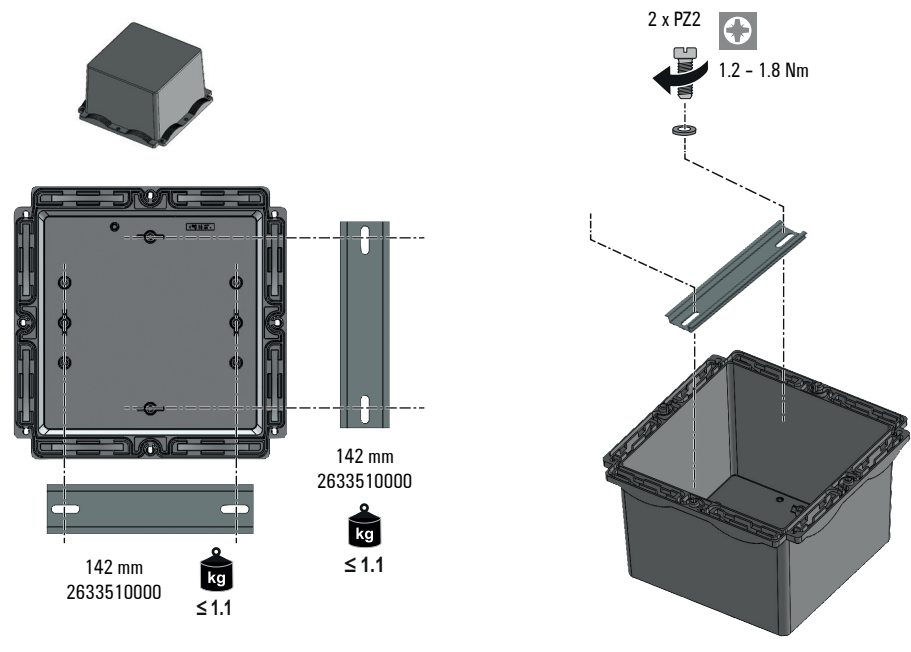

Technische Daten / Technical data			
Schutzart	Protection class	IP65	
Umgebungstemperatur	Ambient temperature	-40 °C ... +85 °C	
Material	Material	Polycarbonate / Aluminium	
Dichtungsmaterial	Seal material	EPDM	
Rüttelsicher gemäß	Resistant to vibrations according to	IEC 61373 category 1b 	
Maße (L / B / H)	Dimensions (L / W / H)	FP ENC BSBS 155 2M	196 / 196 / 155 mm
		FP ENC BSTS 155 2M	196 / 196 / 155 mm
		FP ENC BSAS 220 3M	196 / 196 / 220 mm
		FP ENC BS 042 2B	196 / 196 / 42 mm
		FP ENC TS 113 2C	191 / 191 / 113 mm
		FP ENC BS 113 2C	191 / 191 / 113 mm
		FP ENC AS 178 2C	191 / 191 / 178 mm

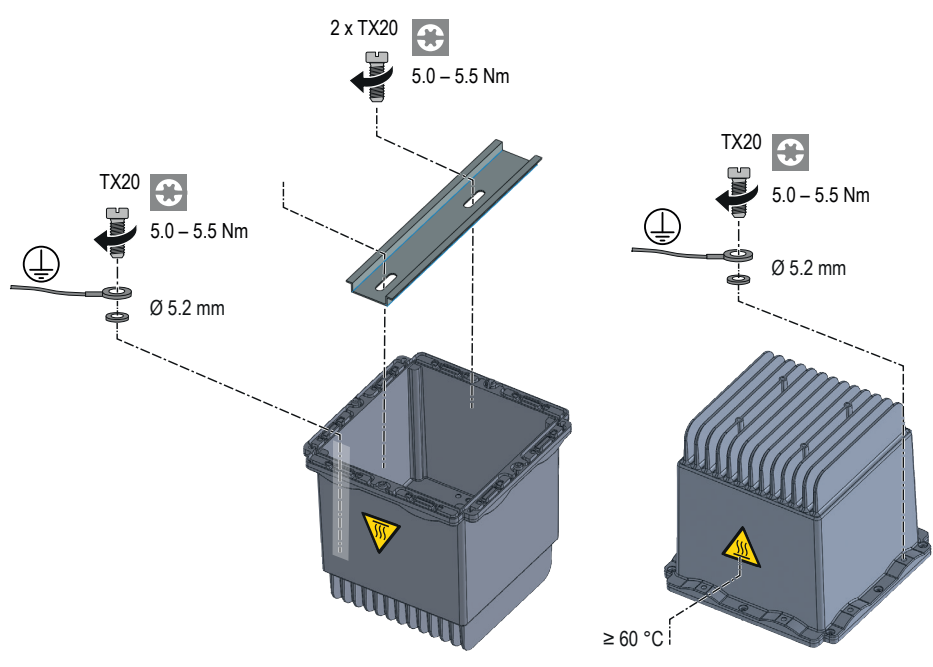

FieldPower® Enclosure Size 2

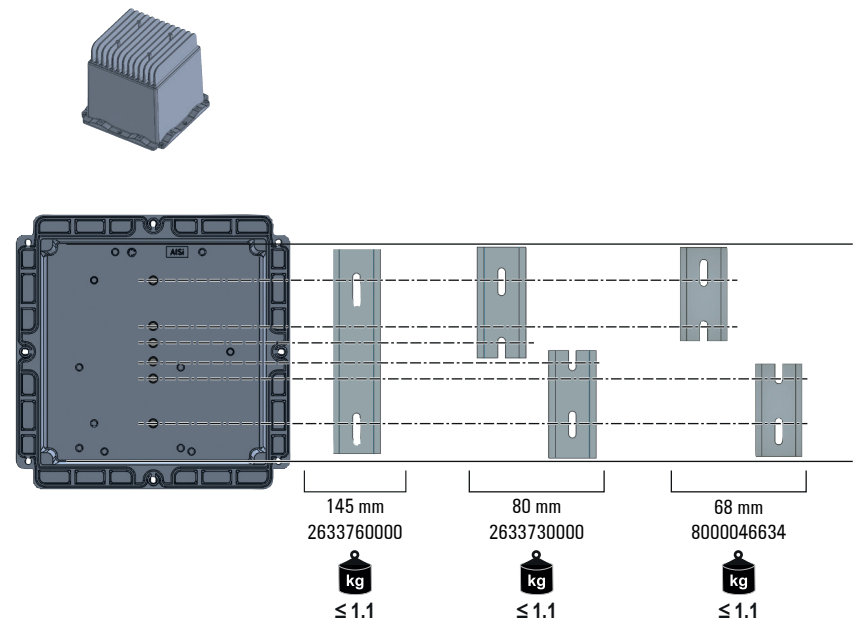

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
32758 Detmold, Germany
T +49 5231 14-0
F +49 5231 14-292083
www.weidmueller.com
2674490000/04/11.2024