

Cabtite Cable Entry Plates for space-saving installation

Simply insert plugless cables into control cabinets and enclosures

If multiple hoses or cables are to be fed into control cabinets or enclosures, cable entry plates are the best choice. They seal, minimise tensile stress, save space, and are an economical alternative to conventional cable glands.


Cabtite cable entry plates only require a small rectangular wall cut-out in the enclosure. Plugless cables, hoses, or optical fibres can be inserted effortlessly. Installation time is reduced by up to 40 % compared to cable glands. Cabtite cable entry plates comply with IP54 or IP66 and are tested according to DIN EN 60529. They are made of UL94 V-0 certified TPE material and are suitable for temperature ranges between -40°C and +90°C.




Your special advantages:

- Simple and quick solution for inserting plugless cables, hoses, and conductors
- Extremely low space requirement with high packing density
- Flexible and safe solution for laying a wide range of cable types
- Up to 40 % time savings compared to installation with cable glands

IP54 - Version

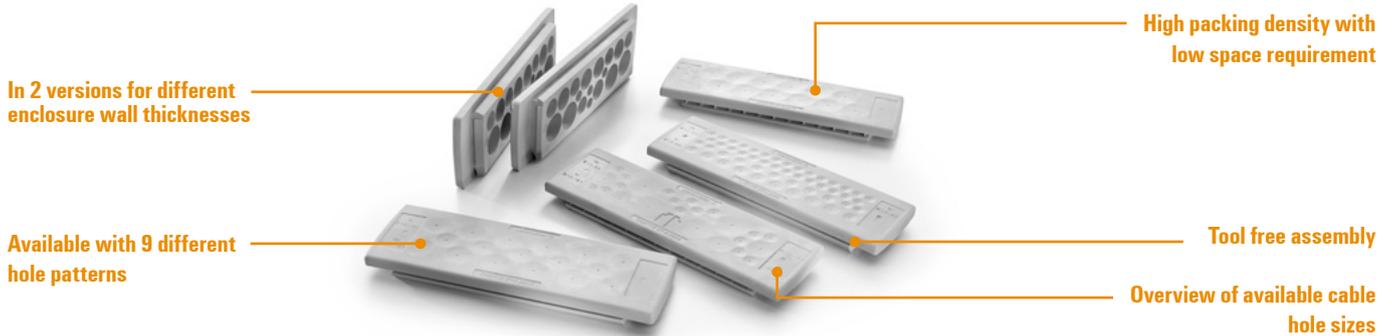

IP66 - Version

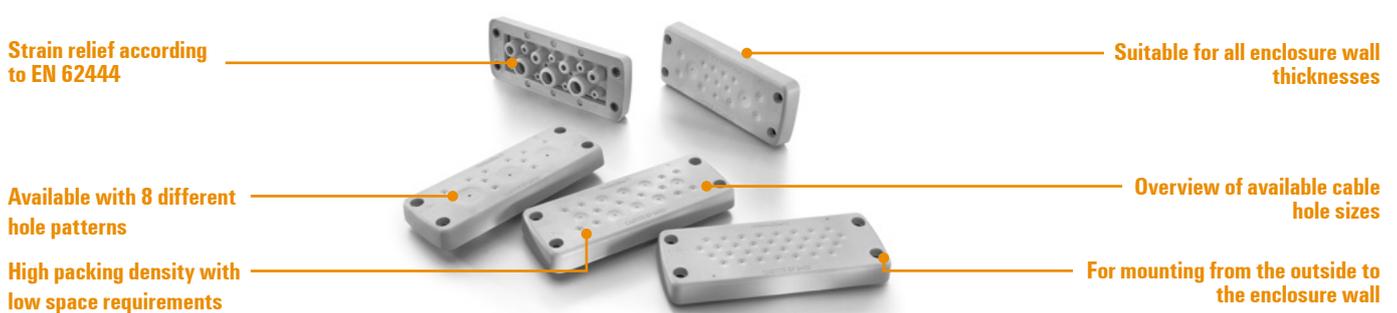

Product Overview

Pos.	Description	Wall thickness	IP Class	Version	Number of cable	Order No.
1	CABTITE EP A24/12 GY	1.5 - 2.5 mm	IP54	Snap version	12	2743540000
2	CABTITE EP A24/14 GY	1.5 - 2.5 mm	IP54	Snap version	14	2743550000
3	CABTITE EP A24/17 GY	1.5 - 2.5 mm	IP54	Snap version	17	2743560000
4	CABTITE EP A24/18 GY	1.5 - 2.5 mm	IP54	Snap version	18	2743570000
5	CABTITE EP A24/19 GY	1.5 - 2.5 mm	IP54	Snap version	19	2743580000
6	CABTITE EP A24/26 GY	1.5 - 2.5 mm	IP54	Snap version	26	2743590000
7	CABTITE EP A24/42 GY	1.5 - 2.5 mm	IP54	Snap version	42	2743600000
8	CABTITE EP A24/48 GY	1.5 - 2.5 mm	IP54	Snap version	48	2743610000
9	CABTITE EP A24/50 GY	1.5 - 2.5 mm	IP54	Snap version	50	2743620000
10	CABTITE EP B24/12 GY	2.5 - 4 mm	IP54	Snap version	12	2743630000
11	CABTITE EP B24/14 GY	2.5 - 4 mm	IP54	Snap version	14	2743640000
12	CABTITE EP B24/17 GY	2.5 - 4 mm	IP54	Snap version	17	2743650000
13	CABTITE EP B24/18 GY	2.5 - 4 mm	IP54	Snap version	18	2743660000
14	CABTITE EP B24/19 GY	2.5 - 4 mm	IP54	Snap version	19	2743670000
15	CABTITE EP B24/26 GY	2.5 - 4 mm	IP54	Snap version	26	2743680000
16	CABTITE EP B24/42 GY	2.5 - 4 mm	IP54	Snap version	42	2743690000
17	CABTITE EP B24/48 GY	2.5 - 4 mm	IP54	Snap version	48	2743700000
18	CABTITE EP B24/50 GY	2.5 - 4 mm	IP54	Snap version	50	2743710000
19	CABTITE EP 24/13 GY	universal	IP66	Screw version	13	2779310000
20	CABTITE EP 24/14 GY	universal	IP66	Screw version	14	2779320000
21	CABTITE EP 24/16 GY	universal	IP66	Screw version	16	2779330000
22	CABTITE EP 24/ 16-1 GY	universal	IP66	Screw version	16	2779340000
23	CABTITE EP 24/17 GY	universal	IP66	Screw version	17	2779350000
24	CABTITE EP 24/20 GY	universal	IP66	Screw version	20	2779360000
25	CABTITE EP 24/21 GY	universal	IP66	Screw version	21	2779370000
26	CABTITE EP 24/ 32 GY	universal	IP66	Screw version	32	2779380000

Note For more information see Online Catalog on <https://catalog.weidmueller.com>



You can find this product family in our Weidmüller Configurator:
www.weidmueller.com/wmc