


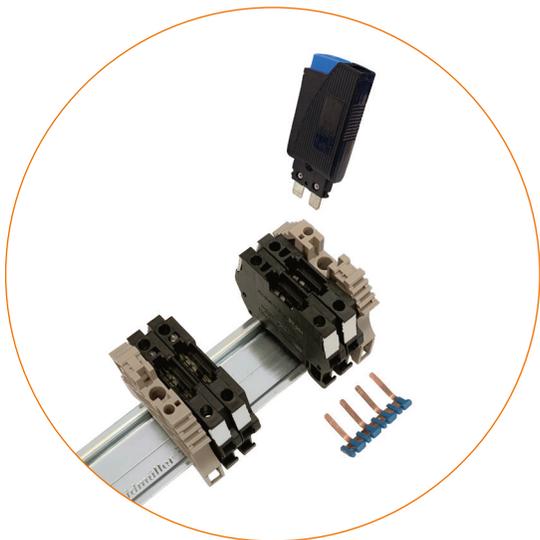

## 1180 Plus Series Circuit Breakers & Terminal Block Bases Supplemental Rated Circuit Breakers (UL1077)

The Weidmüller thermal circuit breaker type 1180 Plus reduces stoppages and downtime. In combination with a modular-style terminal block, the circuit breaker offers individual protection for every circuit.

### Approvals



### Your benefits at a glance

- All amperage available from 0.1A to 10.0A
- Push button resettable breaker
- Terminal block sized breaker base only 9mm wide
- New base design with built-in molded end plate
- Bases available in screw or tension clamp with or without LED indication

**Weidmüller** 

## Thermal Overcurrent Circuit Breaker



### Ordering data

#### Circuit breakers

Type	Order number
1180 01 0.10A	1278840000
1180 01 0.20A	1278850000
1180 01 0.25A	1278860000
1180 01 0.30A	1278870000
1180 01 0.40A	1278880000
1180 01 0.50A	1278910000
1180 01 0.60A	1278920000
1180 01 0.70A	1278930000
1180 01 0.80A	1278940000
1180 01 1.00A	1278950000
1180 01 1.50A	1278960000

Type	Order number
1180 01 2.00A	1278970000
1180 01 2.50A	1278980000
1180 01 3.00A	1278990000
1180 01 3.50A	1279010000
1180 01 4.00A	1279020000
1180 01 5.00A	1279030000
1180 01 6.00A	1279040000
1180 01 7.00A	1279050000
1180 01 8.00A	1279060000
1180 01 10.0A	1279070000



#### Terminal block bases

Description	Type	Order number
Black Terminal Block screw terminal with spacer 3mm	10plus-ST-201	7940108385
Black Terminal Block LED 24VDC screw with spacer 3mm	10plus-ST-202	7940112375
Black Terminal Block LED 12VDC screw with spacer 3mm	10plus-ST-203	7940109767
Black Terminal Block push terminal with spacer 3mm	10plus-XT-201	7940112376
Black Terminal Block LED 24VDC push terminal with spacer 3mm	10plus-XT-202	7940112377
Black Terminal Block LED 12VDC push terminal with spacer 3mm	10plus-XT-203	7940112378
12 pole insulated jumper	X22223202	7940108406



Visit our website to learn more  
about our circuit breakers