


Schraubanschluss / Screw connection

Montagehinweis / Mounting information / Référence de montage / Indicaciones de montaje /
 Infomazioni per il montaggio


1



1a Gerade / Straight

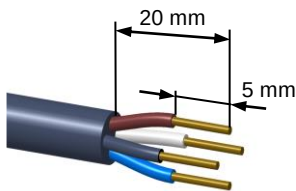

1b Gewinkelt / Angled

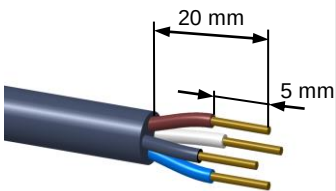

Empfohlen / Recommended: 0,34 mm²

2




9025750000
(0,34 mm²)

9011460000

2a



3

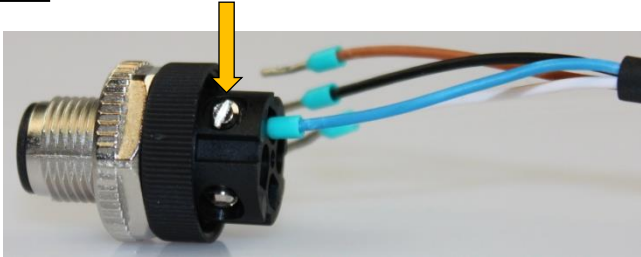

Anzugsdrehmoment Schraubverbindung
 Tightening torque of the screw connection

0,4 Nm (4- and 5-poles)
 0,2 Nm (8-poles)



Schlitzschraubendreher
 Slotted-head screw

4



4a

Anzugsdrehmmment Kopf - Gehäuse
 Tightening torque head - housing

Kunststoffgehäuse / plastic housing 0,8 Nm
 Metallgehäuse / metal housing 0,6 - 0,8 Nm

4b

Anzugsdrehmoment Kabelverschraubung
 Tightening torque cable gland

4 – 5 mm Kabel / cable Ø	0,8 - 1 Nm
5 – 6 mm Kabel / cable Ø	0,8 - 1 Nm
6 – 7 mm Kabel / cable Ø	0,8 - 1 Nm
7 – 8 mm Kabel / cable Ø	0,8 - 1 Nm
8 – 12 mm Kabel / cable Ø	1 - 1,4 Nm