
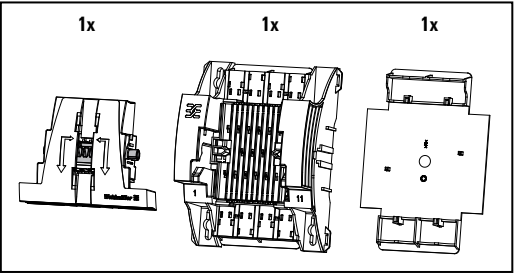


Installation Instructions

FieldPower® Elevator Shaft Wiring Box
FP ESWB

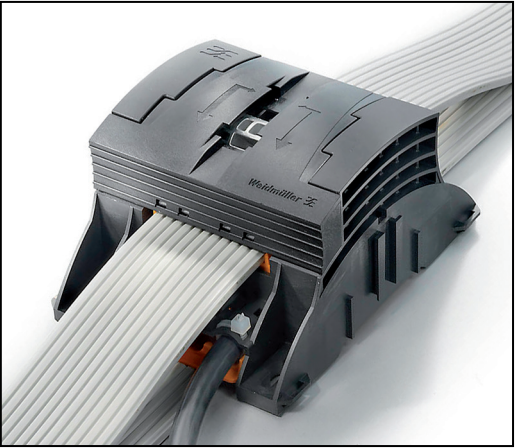



Only use flat cable type 9G1,5 + 2 F from Draka EHC

Recommended tools

		Order No.
	SDS 0.4X2.5X75	9008370000
	SDS 1.2X6.5X150	9009010000
	KSE 160	9046410000

Technical data

Protection class	IP20
Insulation material	Polyamide
Silicone free	Yes
Halogen free	Yes
Ambient temperature	
Installation	+10 °C ... +50 °C
Operation	-5 °C ... +50 °C
Flame resistant	V0
Rated voltage	230 V
Rated current	6 A
Rated impulse withstand voltage	4 kV

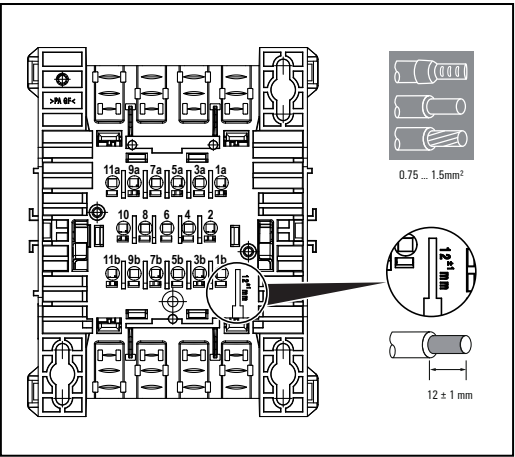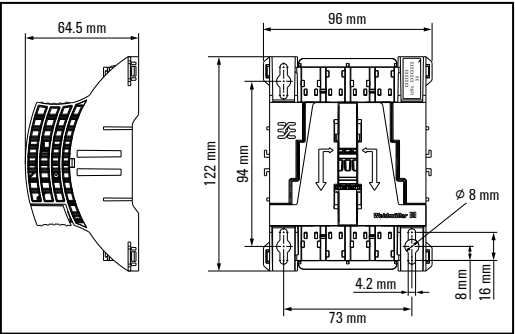

Montage und Wartung nur durch eine Elektrofachkraft!

Installation and maintenance by qualified electricians only!

Le montage et l'entretien ne doivent être réalisés que par un électricien !

Montaggio e manutenzione solo da parte di un elettricista specializzato!

¡El montaje y el mantenimiento solo los debe llevar a cabo un electricista cualificado!




Gefahr durch spannungsführende Teile! Bei Installations- und Wartungsarbeiten ist die Anlage allpolig spannungsfrei zu schalten.

Danger from live parts! All poles of the system must be disconnected from the power supply for installation and maintenance work.

Danger, présence de pièces sous tension ! Pour toute opération d'installation et de maintenance, le dispositif doit être mis hors tension sur tous les pôles.


Attenzione, componenti sotto tensione! Durante eventuali interventi di installazione e manutenzione, togliere la tensione da tutti i poli dell'impianto.

¡Peligro por piezas conductoras de energía! Durante los trabajos de instalación y mantenimiento, toda la instalación debe quedar libre de tensión para todos los polos.

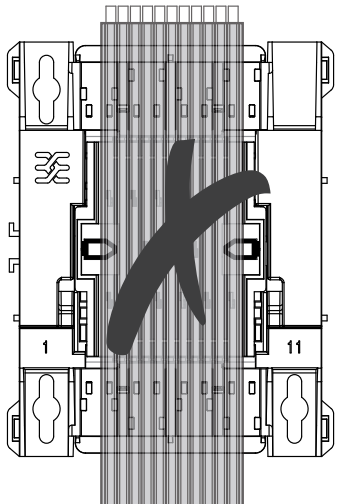




1

Example

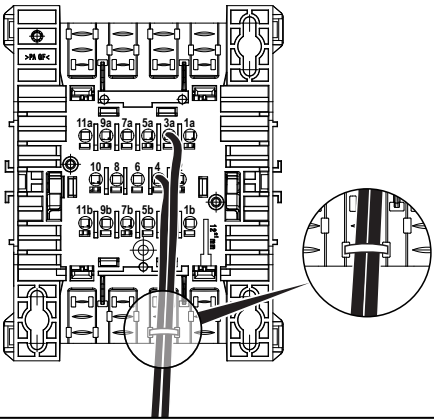





2a

Two safety chains

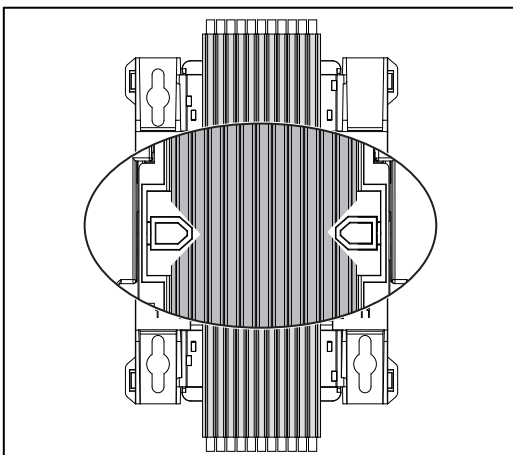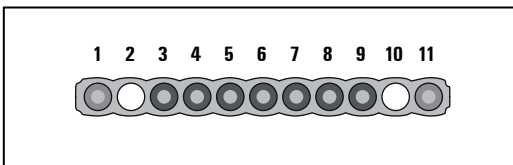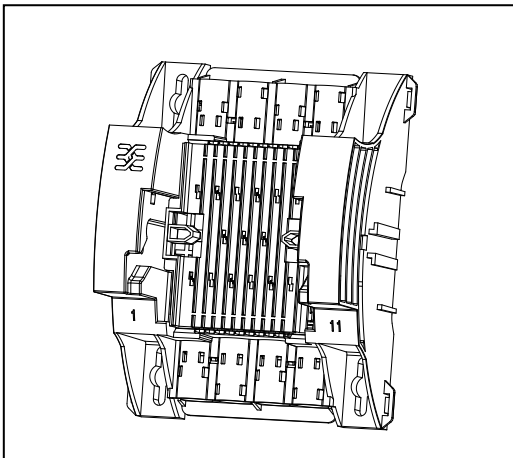





2b

One safety chain

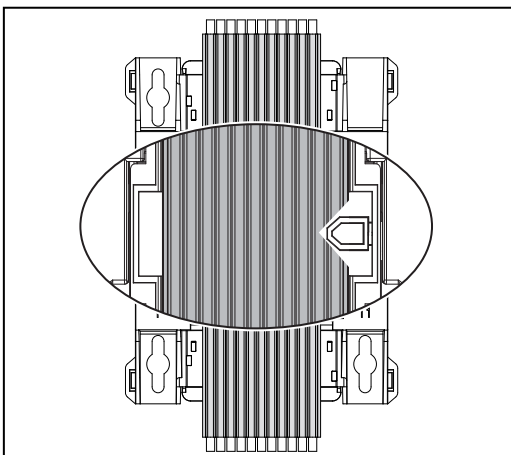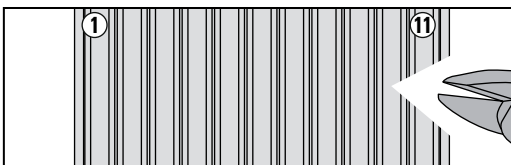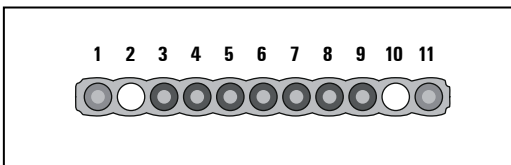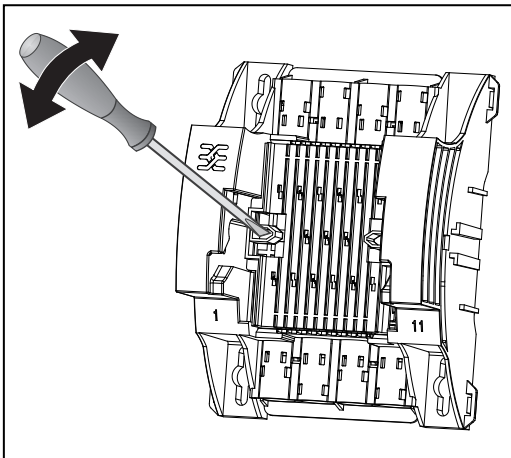


2c

No safety chain

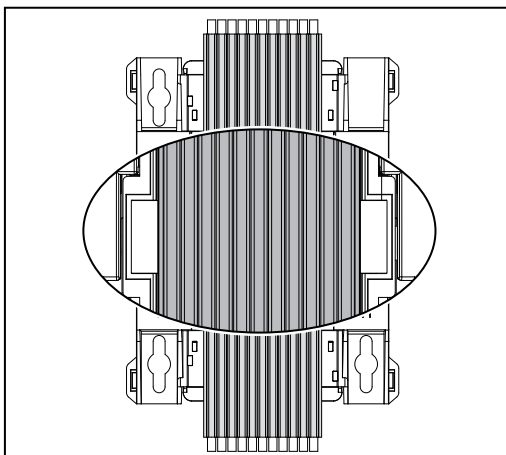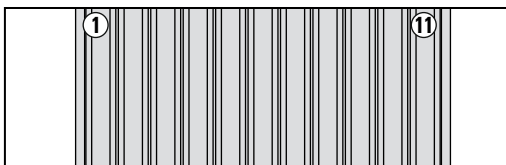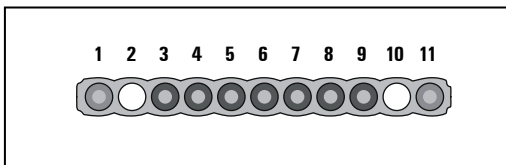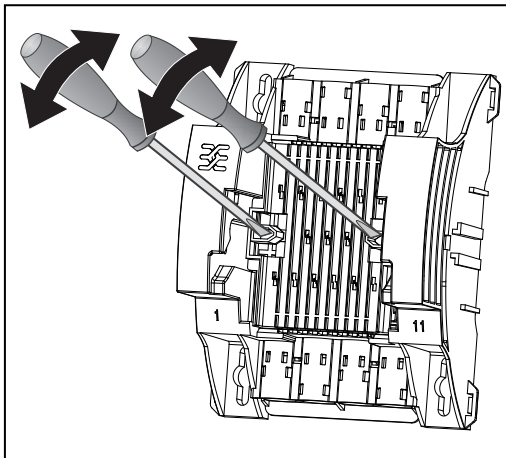

3

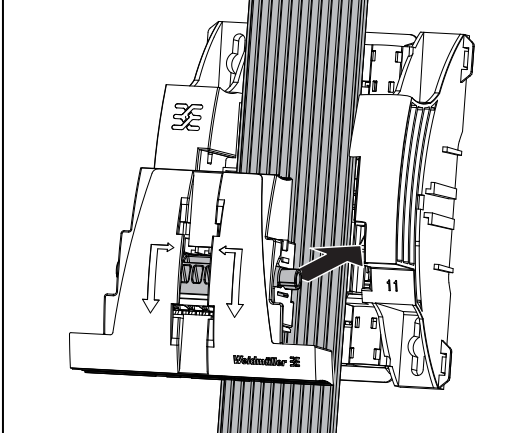

4

