


WZAD

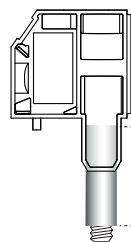


WZAD 50N 1872720000
WZAD 70N 1964830000
WZAD 95N/120N 1859580000

2.5 - 5.0 Nm
 2.5 - 5.0 Nm
 3.0 - 6.0 Nm

VH WZAD50N
VH WZAD70N
VH WZAD 95N/120N

L = 39.2 mm
 L = 41.2 mm
 L = 51.9 mm

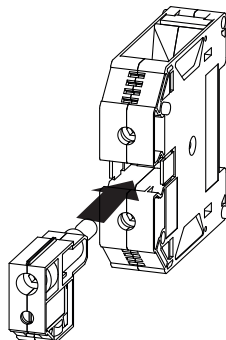

WDU 50N 1820840000
WDU 70N/35 9512190000
WDU 95N/120N 1820550000


Weidmüller

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 32758 Detmold, Germany
 T +49 5231 14-0
 F +49 5231 14-292083
 www.weidmueller.com


4346680000/02/11.2024

WZAD + WQV


1

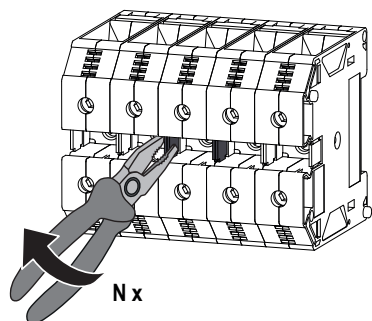


2

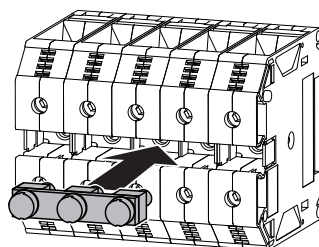

3

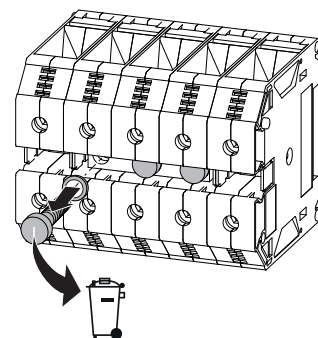


4

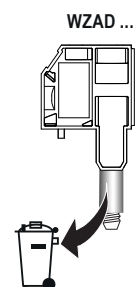


WZAD ...


	Order No.
WZAD 50N	1872720000
WZAD 70N	1964830000
WZAD 95N/120N	1859580000

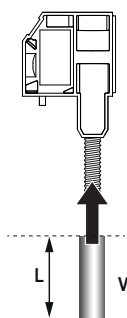

VH ...

 


	Order No.	L [mm]
VH 27.4/8/6.4	1967090000	27.4
VH 27.4/8/6.4	1967110000	25.2
VH 36.1/8/6.4	1967100000	36.1

 

	Order No.	L [mm]
VH 27.4/8/6.4	1967090000	27.4
VH 28.1/8/6.4	3011910000	28.1
-	-	-

5

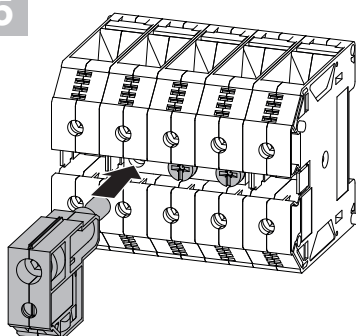

6

