

Licensed Long Distance Ethernet

Ultra-long Range Ethernet for Reliable Connectivity

Utility Grade

Transmits wireless Ethernet 30+ miles with secure and robust two-way communication over licensed frequencies

Selectable Frequencies

Operates in 400MHz or 900MHz up to 5W, licensed wireless transceiver capable of long range and high bandwidth communications

Simple Configuration

Web-based configuration for Access Point/Client and Bridge/Router configuration

Best of Both Worlds

Serves as a Serial Server (RS232/485) and Ethernet data transmission router

Automatic Mesh Connectivity

Spanning Tree (Self Healing) support with deterministic AP to AP mesh network redundancy



Let's connect.

www.weidmuller.com

Weidmüller 

Competitive Comparisons


Company	Weidmüller 	GE	Schneider	Motorola
Distance 50Km/31 Miles	Yes	Yes	Yes	Yes
Repeater/Mesh/Multi Hop (5+)	Yes	No	No	No
RS232/RS485/Ethernet TCP/IP	Yes	No RS232	No (Only one at a time)	No (Only one at a time)
Onboard I/O	Yes	No	No	No
Built-in Broadcast Limitation	Yes	No	No	No

Typical Applications

These licensed wireless Ethernet modems offer powerful, long range communications for difficult-to-reach locations. Flexible options available support 360- to 512-MHz or 950MHz configurations. They offer dynamic network optimization, intelligent routing and operate in an extended temperature range. They provide industry-standard encryption (128-bit AES, 802.11i with CCMP, WEP, WPA2) and compliance, including ATEX/IECEx.

Applications

- Remote Well Head Monitoring
- Pipeline Leak Detection
- SCADA Networks
- Environmental Monitoring
- Water Treatment Facilities
- Mining Operations Infrastructure
- Tank Farm Monitoring

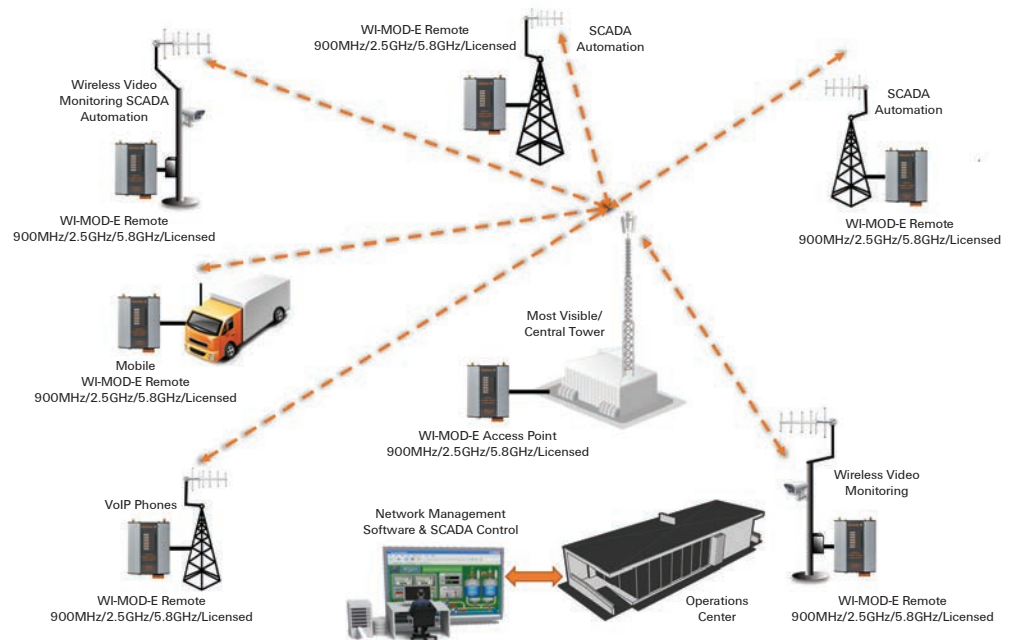

Availability

Type	Description	Temperature Range	Part Number
WI-MOD-450-E-5W	315-512MHz Licensed Ethernet Modem	-30° to +60°C	6720005017
WI-MOD-950-E-5W	928-960MHz Licensed Ethernet Modem	-30° to +60°C	6720005018

Information

Information is available for download on our website: www.weidmuller.com
Printed catalog versions are also available and can be ordered online.

Ref. No.	Description
2001460000	Wireless I/O and Ethernet Connectivity Catalog #12

Weidmüller, Canada

10 Spy Court
Markham, Ontario L3R 5H6
Telephone: (800) 268-4080
Facsimile: (877) 300-5635
Email: info1@weidmuller.ca
Website: www.weidmuller.ca

Weidmüller, Mexico

Bldv. Hermanos Serdán 698,
Col. San Rafael Oriente
Puebla, Puebla, Mexico
C.P. 72029
Telephone: 01 222 2686267
Facsimile: 01 222 2686219
Email: clientes@weidmuller.com.mx
Website: www.weidmuller.com.mx

Weidmüller, United States

821 Southlake Blvd.
Richmond, Virginia 23236
Telephone: (800) 849-9343
Facsimile: (804) 379-2593
Email: info@weidmuller.com
Website: www.weidmuller.com