


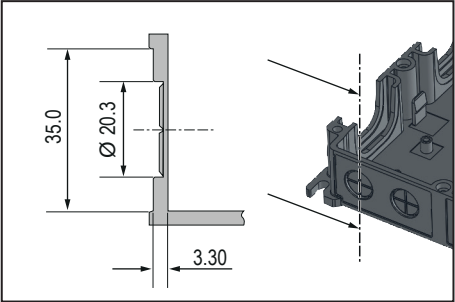
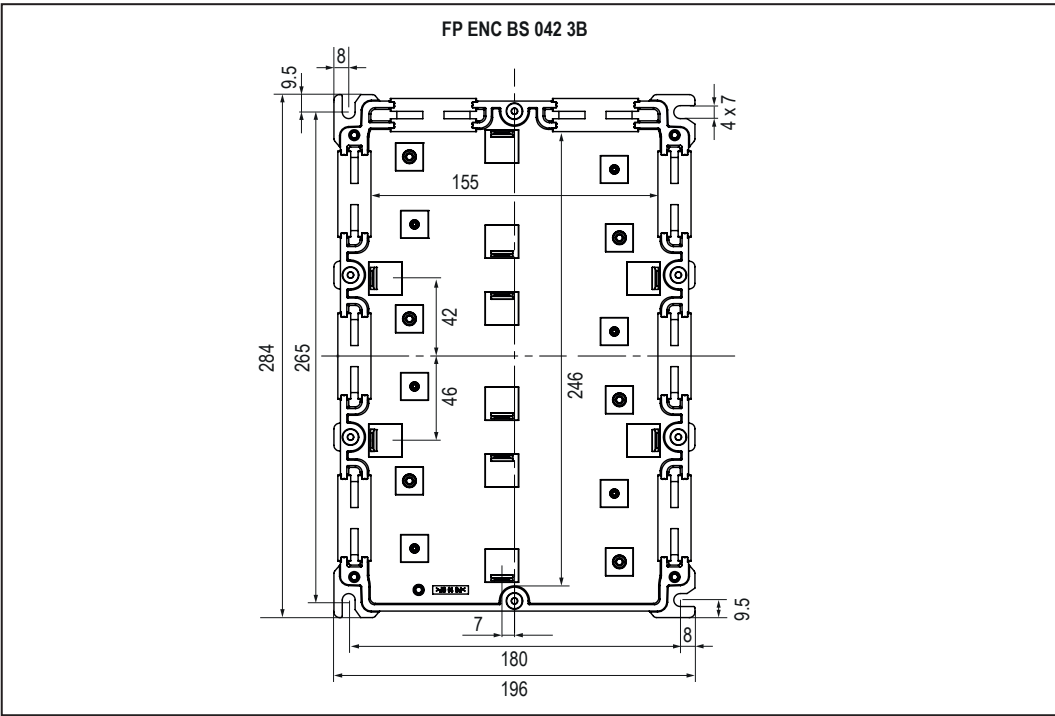
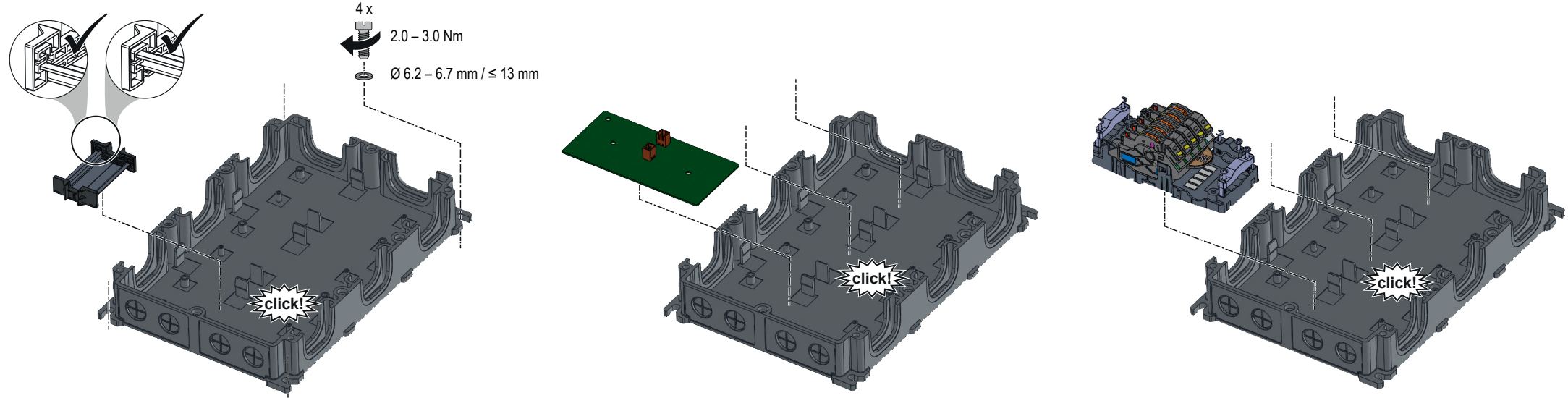
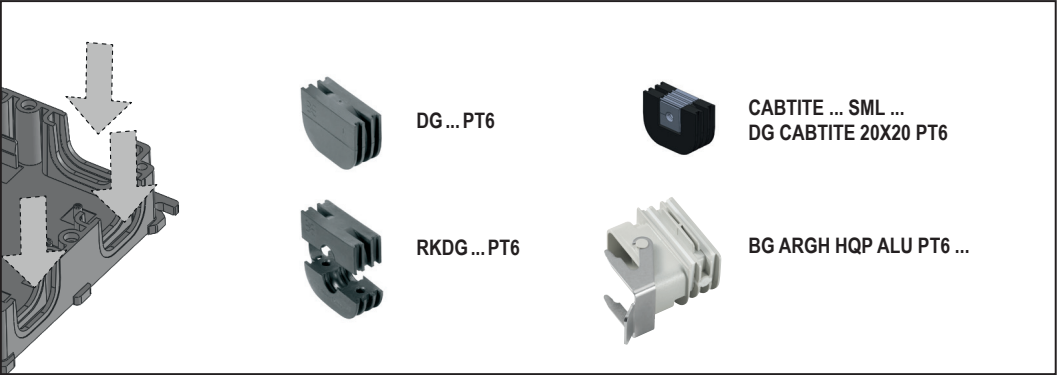
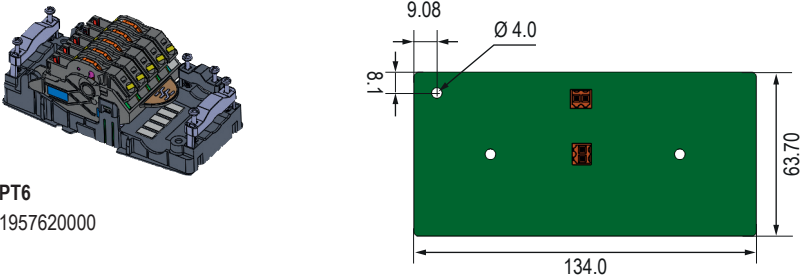
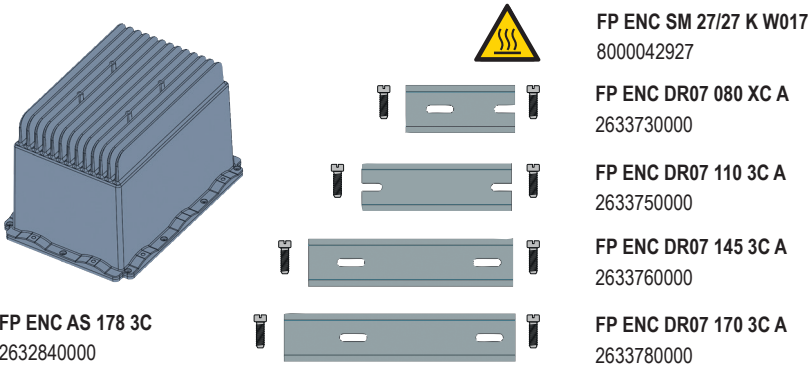
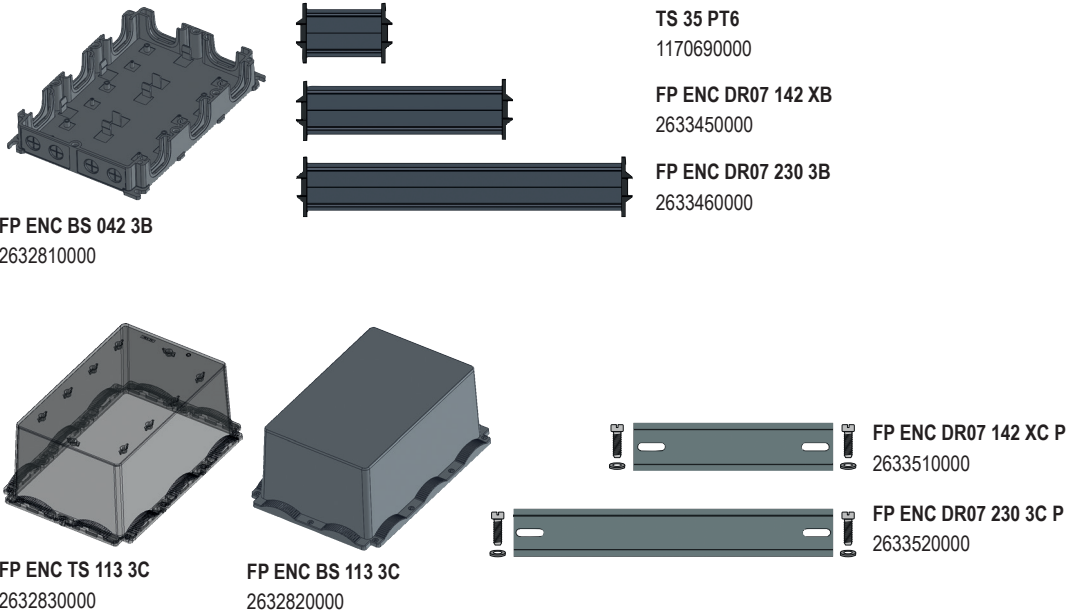
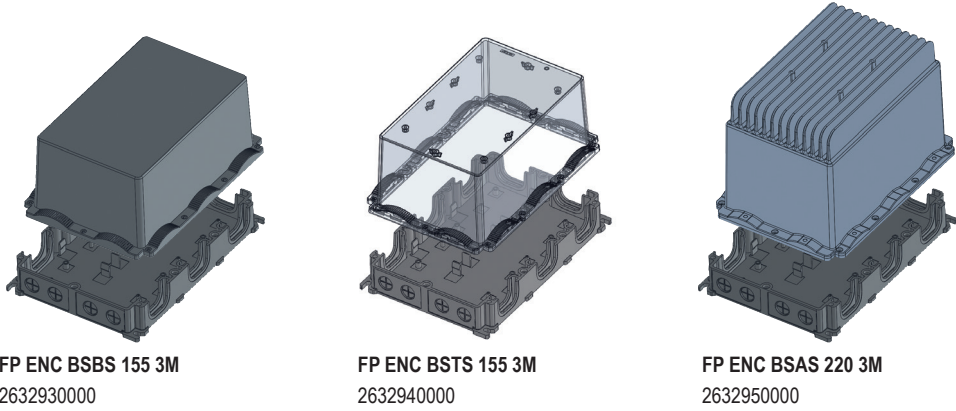
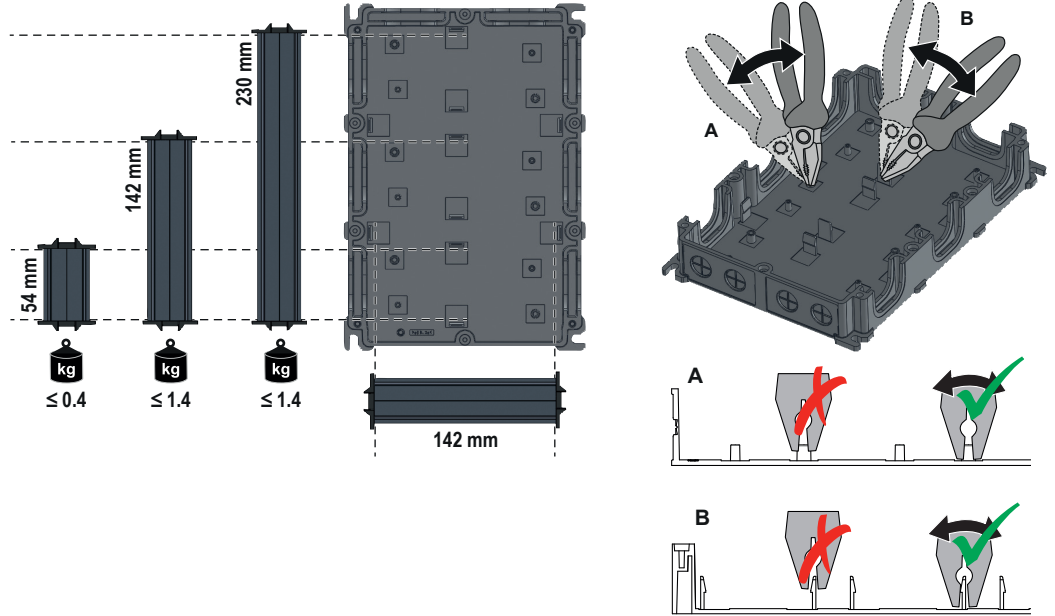
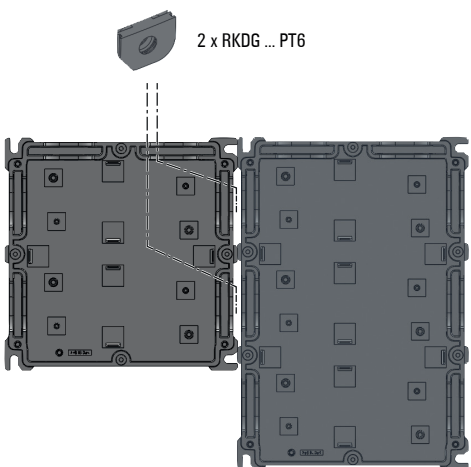
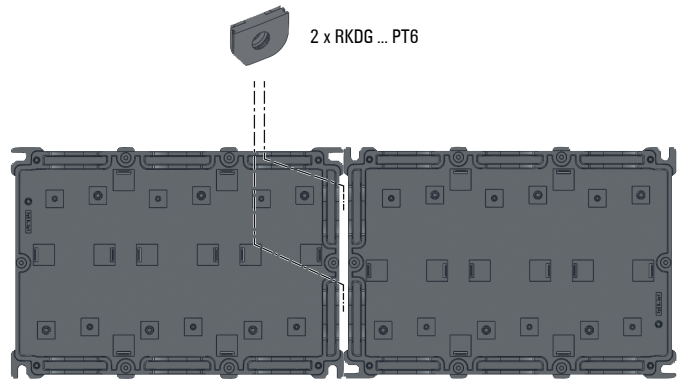
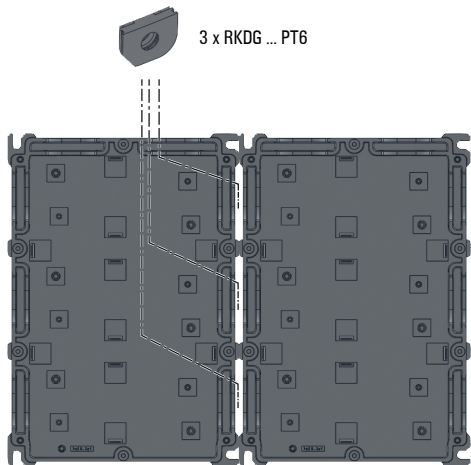
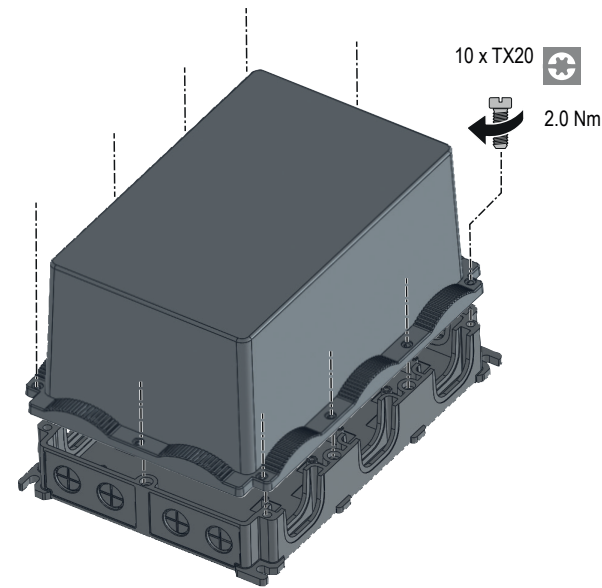
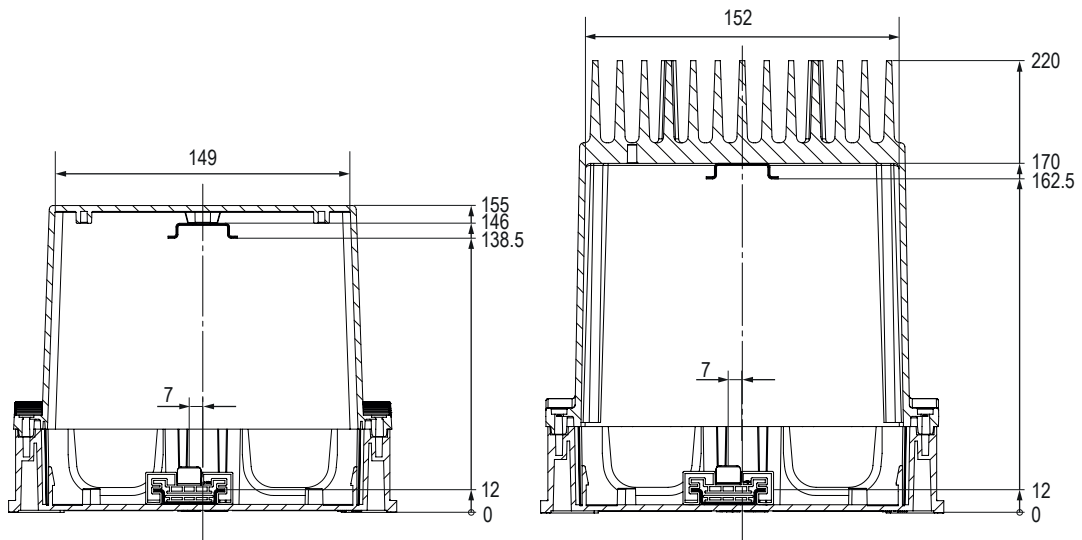


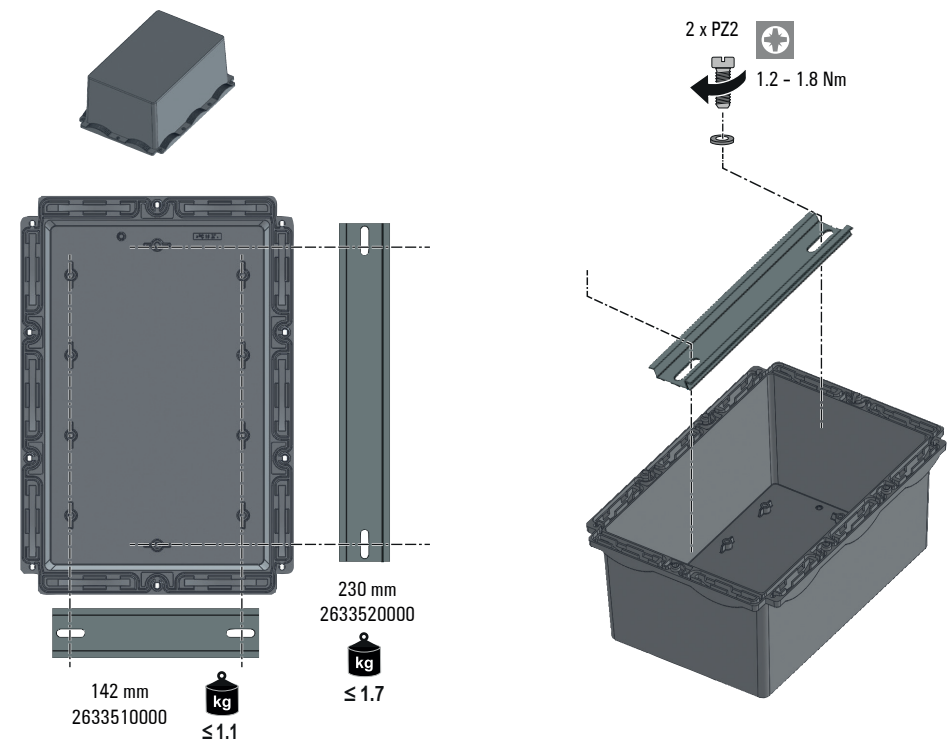

| Technische Daten / Technical data |                                      |                                                                                                             |
|-----------------------------------|--------------------------------------|-------------------------------------------------------------------------------------------------------------|
| Schutzart                         | Protection class                     | IP65                                                                                                        |
| Umgebungstemperatur               | Ambient temperature                  | -40 °C ... +85 °C                                                                                           |
| Material                          | Material                             | Polycarbonate / Aluminium                                                                                   |
| Dichtungsmaterial                 | Seal material                        | EPDM                                                                                                        |
| Rüttelsicher gemäß                | Resistant to vibrations according to | IEC 61373 category 1b  |
| Maße (L / B / H)                  | Dimensions (L / W / H)               | FP ENC BSBS 155 3M                                                                                          |
|                                   |                                      | 196 / 284 / 155 mm                                                                                          |
|                                   |                                      | FP ENC BSTS 155 3M                                                                                          |
|                                   |                                      | 196 / 284 / 155 mm                                                                                          |
|                                   |                                      | FP ENC BSAS 220 3M                                                                                          |
|                                   |                                      | 196 / 284 / 220 mm                                                                                          |
|                                   |                                      | FP ENC BS 042 3B                                                                                            |
|                                   |                                      | 196 / 284 / 42 mm                                                                                           |
|                                   |                                      | FP ENC TS 113 3C                                                                                            |
|                                   |                                      | 191 / 279 / 113 mm                                                                                          |
|                                   |                                      | FP ENC BS 113 3C                                                                                            |
|                                   |                                      | 191 / 279 / 113 mm                                                                                          |
|                                   |                                      | FP ENC AS 178 3C                                                                                            |
|                                   |                                      | 191 / 280 / 178 mm                                                                                          |

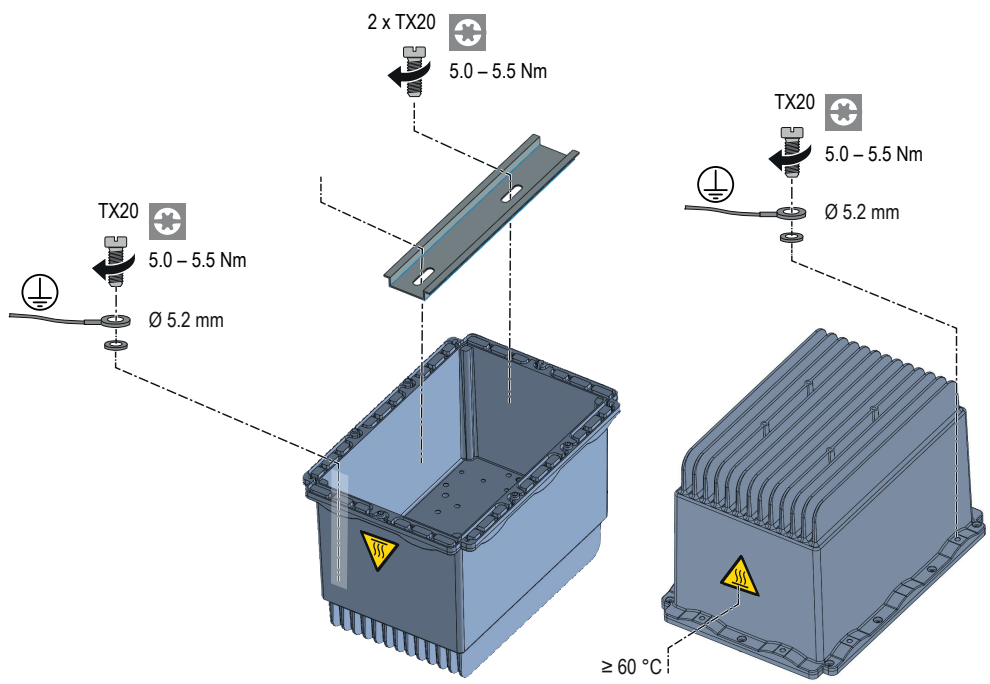

FieldPower® Enclosure Size 3

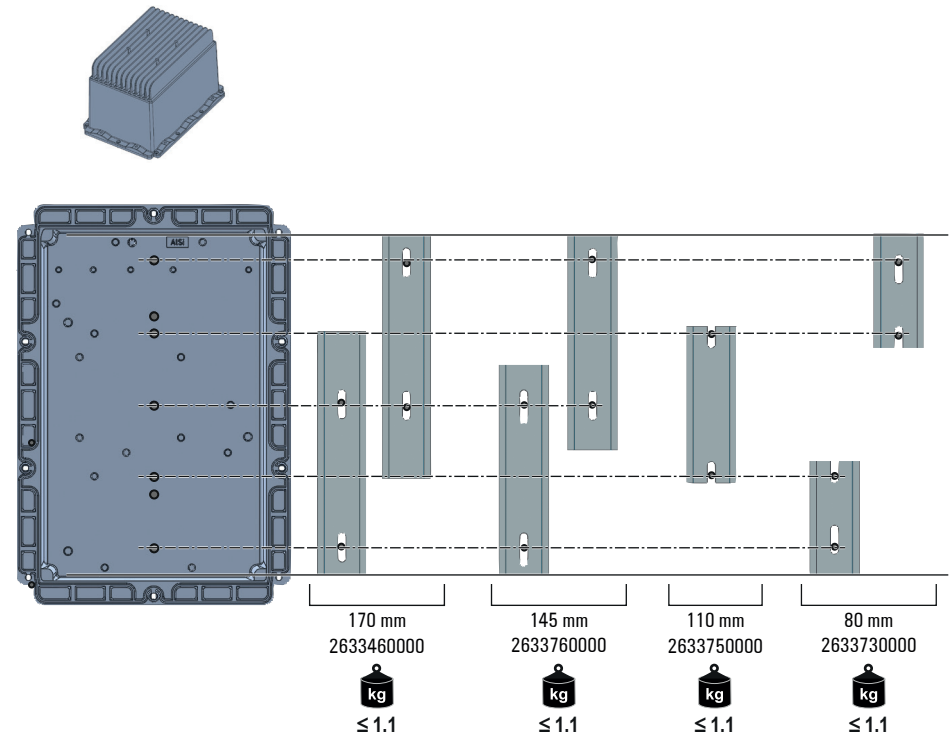

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
32758 Detmold, Germany  
T +49 5231 14-0  
F +49 5231 14-292083  
www.weidmueller.com

2638370000/06/11.2024