
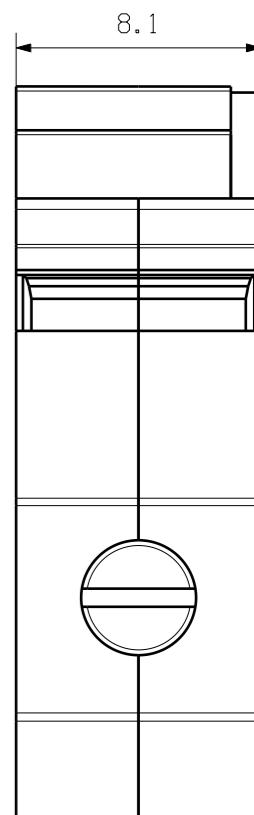
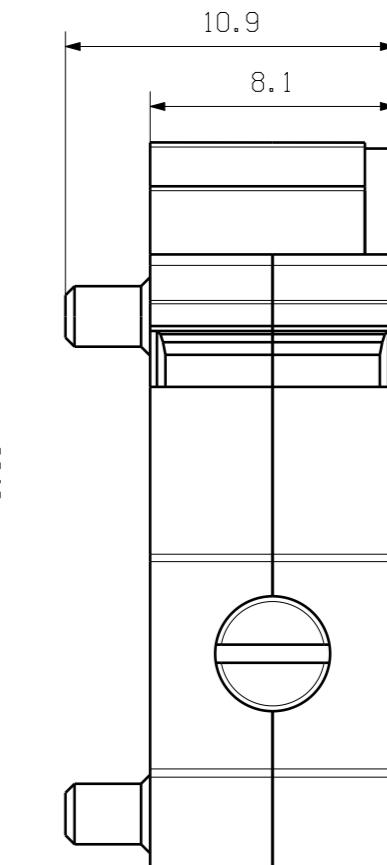
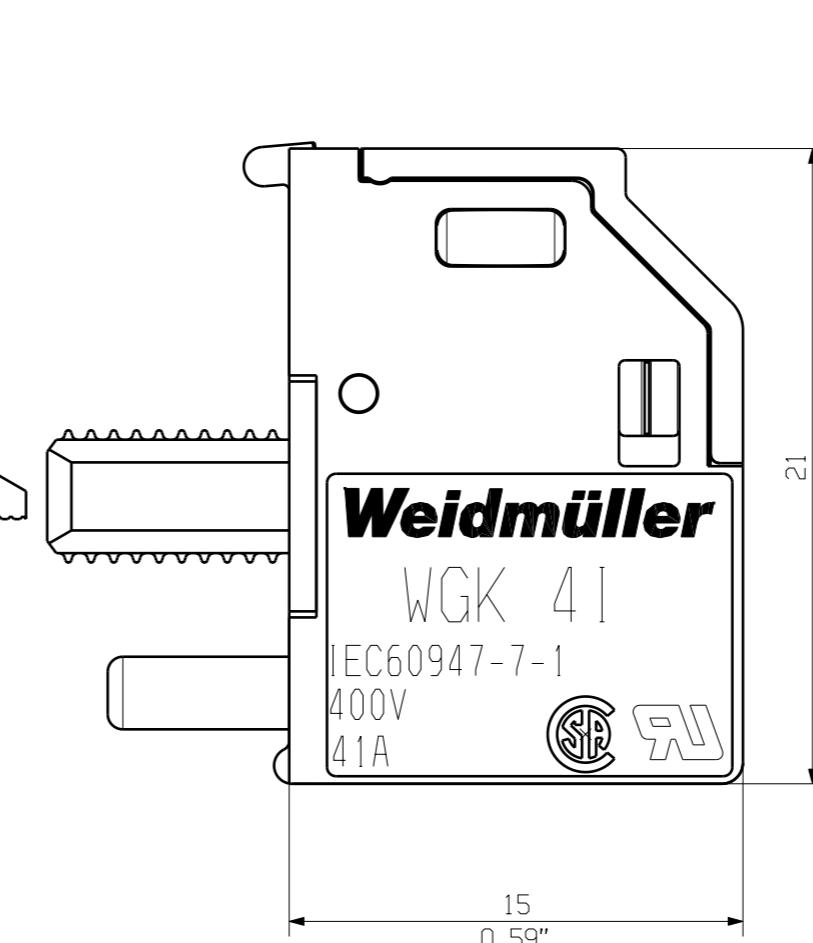


02

The reproduction, distribution and utilization of this document as well as the communication of its contents to others without explicit authorization is prohibited.
Offenders will be held liable for the payment of damages. Weidmüller exclusively reserves the right to file for patents, utility models or designs.

© Weidmüller Interface GmbH & Co. KG

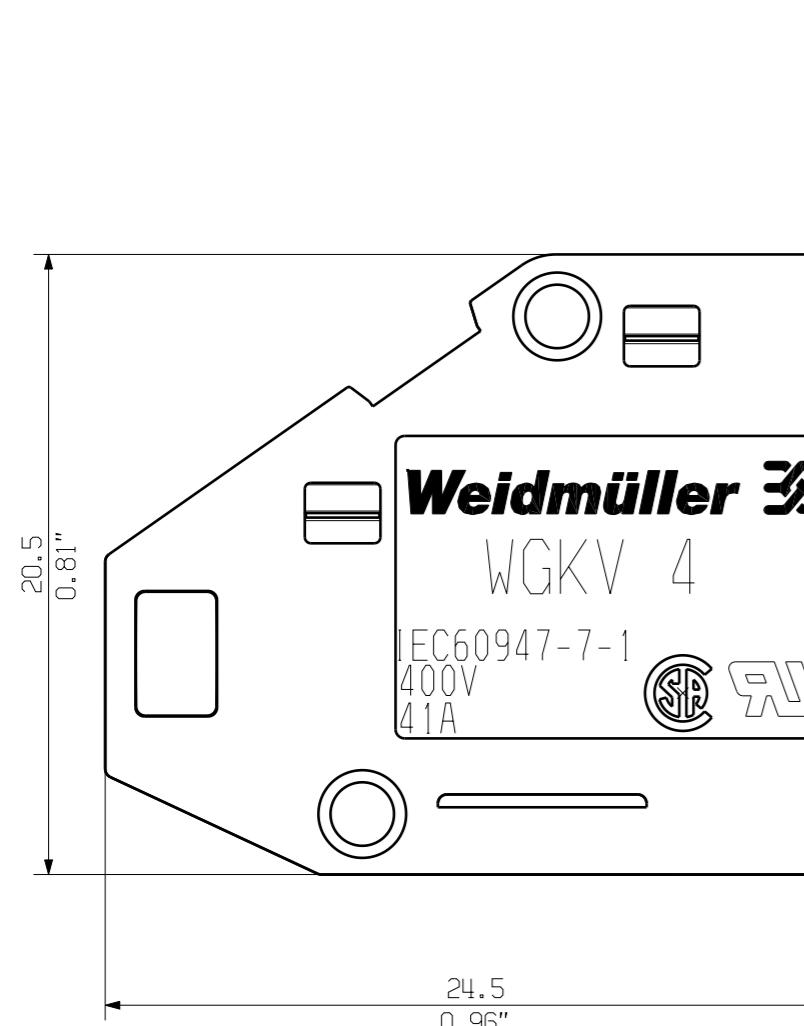


WGKV 4/Z...

WGKV 4...

KUNDENZEICHNUNG
CUSTOMER DRAWING

rated data
rated cross-section
rated current
rated voltage

4 mm²
41A
400V

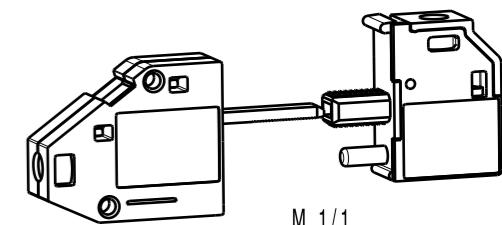

GENERAL TOLERANCE:
DIN ISO 2768-m



Max. nos.

91733/5
21.03.17 MA_J

01

Modification



Date

Name

Drawn

04.04.2006

ZHOU_B

Responsible

MA_J

Checked

22.03.2017

ZHOU_N

Approved

XU_S

Product file: WGKV 4

Weidmüller

3 42873

02

Drawing no. 01 of 01 sheets

WGKV 4...
DURCHGANGS-REIHENKLEMME
FEED-THROUGH TERMINAL