

RockStar® Housings IP65 / NEMA Type 12, 4X

RockStar® Housings IP65 / NEMA Type 12, 4X	Introduction	D.2
	RockStar® Housings IP65 / NEMA Type 12, 4X	D.4
	Size 1 - 12	

RockStar® Housings IP65 / NEMA Type 12, 4X

Where something extra comes as standard. The high quality workmanship of RockStar® IP65 housings begins with the material from which all interlock mechanisms are made: stainless steel. It guarantees a long lifespan with high resistance to corrosion and impact. For the die-cast aluminium variants, a high-quality, multi-stage surface sealing provides years of safety and reliability – even under the most extreme conditions. With just one housing series, Weidmüller delivers the proper protective solution for your heavy-duty connector – so your choice is simple.

Other standard extras:

- A patented spring system provides a secure interlock and easier handling.
- Integrated threads: your choice of cable glands
- Integrated insulation strips: for worry-free transmission of higher voltages

RockStar® IP65 housings are available in twelve sizes and can be combined with all fixed-pole and modular inserts.



Sturdy

Stainless steel interlock systems and multi-stage surface sealing results in high durability



Reliable

Guaranteed protection against jets of water, corrosion, ice and rain, according to IEC 60529 and UL.



D

**Practical**

Laser labelling for permanent identification and faster allocation



RockStar® IP65 Housings / NEMA Type 12, 4X

Plastic housing


Size 1

Hood

Plug housing, cable entry sideways




Colour	Version	b (mm)	Type	Order No.
beige	w. threading	49.2	HDC 07A TWLJ 1M20G	1788510000
beige	w. threading	49.2	HDC 07A TWLJ 1PG11G	1652400000

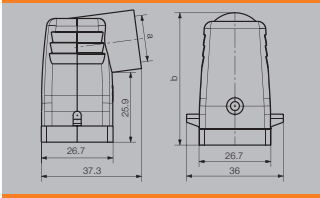

Plug housing, cable entry at top



Colour	Version	b (mm)	Type	Order No.
beige	w. threading	50	HDC 07A TOLJ 1M20G	1788520000
beige	w. threading	50	HDC 07A TOLJ 1PG11G	1652380000
black	w. threading	50	HDC 07A TOLJ 1M20G BLK	2089000000

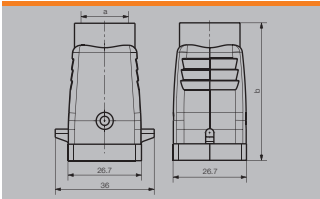

Plastic housing


Size 1

Base

Bulkhead housing




Colour	Version	b (mm)	Type	Order No.
beige		23	HDC 07A ALU	1652410000
black		23	HDC 07A ALU BLK	2088980000

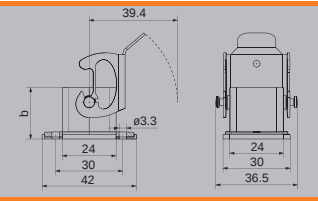

Bulkhead housing, angled




Colour	Version	b (mm)	Type	Order No.
beige	angled	26.7	HDC 07A AWLU	1652420000

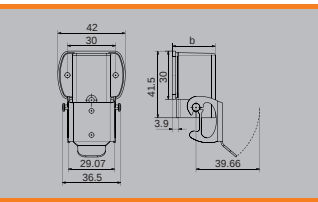

Base housing




Version	b (mm)	Type	Order No.
w. threading	41.5	HDC 07A SLU 1M20G	1788530000
w. Supports	41.5	HDC 07A SLU 1PG11S	1652440000

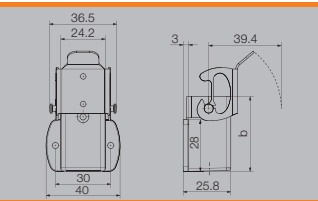

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	53.5	HDC 07A KOLU 1M20G	1788540000
w. threading	53.5	HDC 07A KOLU 1PG11G	1652460000

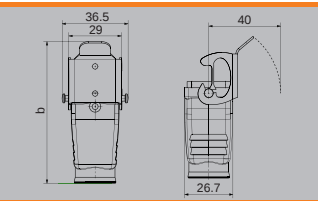

Screw mounting housing




Version	b (mm)	Type	Order No.
w. threading	54	HDC 07A ELU 1PG13G	1900990000

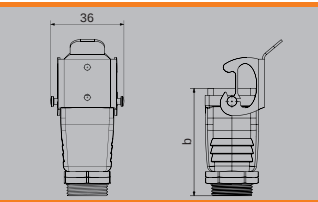

Cover



Version	Type	Order No.
with female	HDC 07A DMDL 2B0	1665770000
with male	HDC 07A DDDL 2B0	1665760000

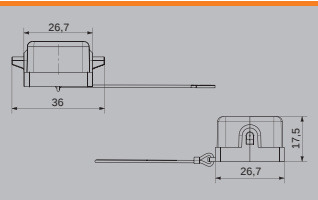

RockStar® IP65 Housings / NEMA Type 12, 4X

Metal housing


Size 1

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	49.2	HDC 04A TWLJ 1M20G	1788810000
w. threading	49.2	HDC 04A TWLJ 1PG11G	1652480000

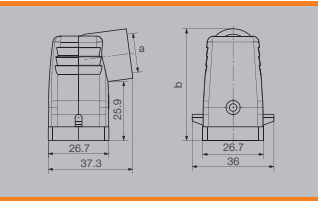

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	50	HDC 04A TOLJ 1M16G	1206090000
w. threading	50	HDC 04A TOLJ 1M20G	1788820000
w. threading	50	HDC 04A TOLJ 1PG11G	1652470000

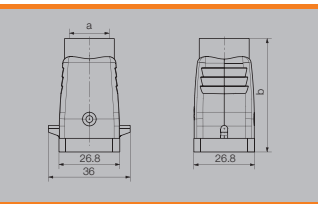

Cover



Version	Type	Order No.
with male	HDC 04A DDDL 1LB	1963690000

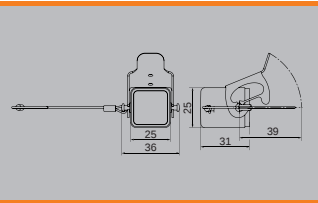

Metal housing


Size 1

Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	23	HDC 04A ALU	1497600000

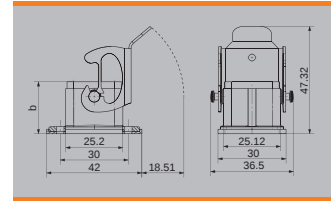

Bulkhead housing, angled




Version	b (mm)	Type	Order No.
angled	26.7	HDC 04A AWLU	1497700000

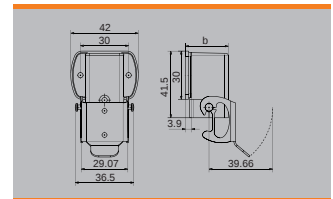

Base housing




Version	b (mm)	Type	Order No.
w. threading	41.5	HDC 04A SLU 1M20G	1788830000
w. threading	41.5	HDC 04A SLU 1PG11G	1652490000

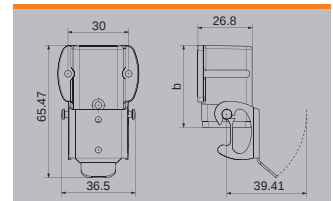

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	53.5	HDC 04A KOLU 1M20G	1788840000
w. threading	53.5	HDC 04A KOLU 1PG11G	1652500000

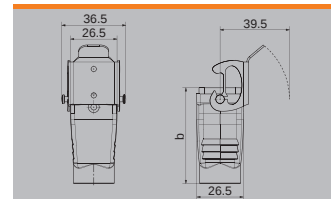

Screw mounting housing




Version	b (mm)	Type	Order No.
w. threading	54	HDC 04A ELU 1M20G	1900320000
w. threading	54	HDC 04A ELU 1PG13S	1900330000

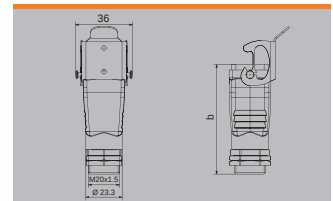

Cover



Version	Type	Order No.
with female	HDC 04A DMDL 2B0	1665750000
with male	HDC 04A DDDL 2B0	1665740000

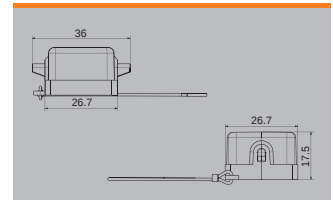

RockStar® IP65 Housings / NEMA Type 12, 4X

Plastic housing


Size HQ

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	54	HDC HQP TSLU 1PG16	1003090000

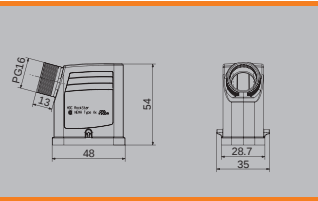

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	67	HDC HQP TOLU 1PG16	1003070000

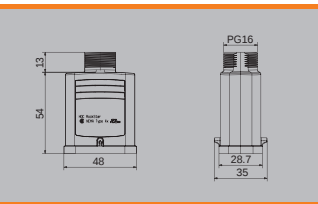


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	19.5	HDC HQP ALU	1003040000
	19.5	HDC HQP ALU CS	1354950000


Note CS: with locking bow

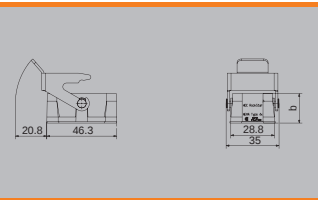

Bulkhead housing, angled




Version	b (mm)	Type	Order No.
angled	54.5	HDC HQP AWLU	1003060000

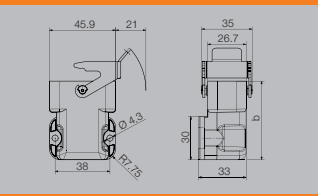

Base housing




Version	b (mm)	Type	Order No.
w. threading	54.5	HDC HQP SLU 1PG16	1003110000

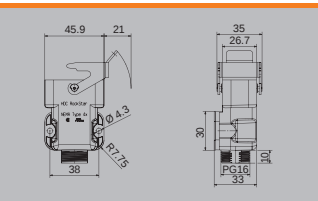

Coupling housing



Version	b (mm)	Type	Order No.
w. threading	63.5	HDC HQP KOLU 1PG16	1003120000

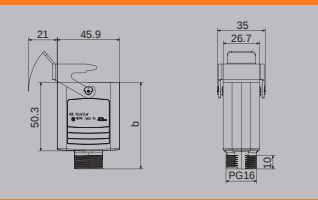


Cover



Version	Type	Order No.
with female	HDC HQP DMD 2B0	1003130000
with male	HDC HQP DOD 2B0	1003140000
with female	HDC HQP DMD 2B0 CS	1251660000
with male	HDC HQP DOD 2B0 CS	1251670000

Note for plastic and metal housings, for locking bow

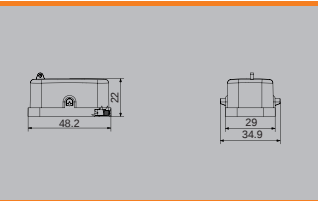

Die cast zinc housing (EMC)


Size HQ

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	60.5	HDC HQM TSLU 1PG21	1003100000

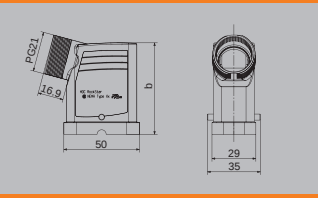

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	77.5	HDC HQM TOLU 1PG21	1003080000

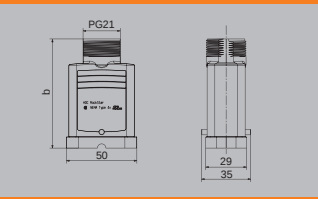


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	20.5	HDC HQM ALU	1003050000
	20.5	HDC HQM ALU CS	1251680000

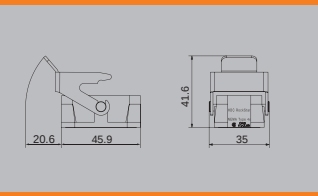

Cover



Material: Plastic			
Version		Type	Order No.
with female		HDC HQP DMD 2B0	1003130000
with male		HDC HQP DOD 2B0	1003140000
with female		HDC HQP DMD 2B0 CS	1251660000
with male		HDC HQP DOD 2B0 CS	1251670000

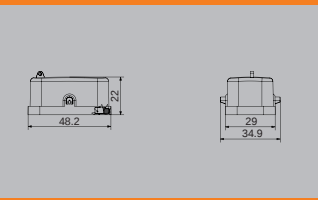

Note	for plastic and metal housings, for locking bow
------	---

RockStar® IP65 Housings / NEMA Type 12, 4X

End locking, lower side


Size 2

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	54	HDC 10A TSLU 1M20G	1967660000
w. threading	68	HDC 15A TSLU 1M20G	1788860000
w. threading	68	HDC 15A TSLU 1M25G	1788850000
w. threading	54	HDC 10A TSLU 1PG16G	1663810000
w. threading	68	HDC 15A TSLU 1PG16G	1663850000
w. threading	68	HDC 15A TSLU 1PG21G	1663870000

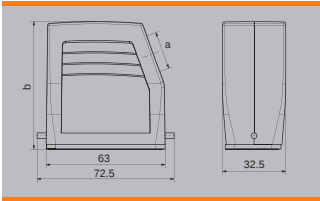

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	54	HDC 10A TOLU 1M20G	1788620000
w. threading	54	HDC 10A TOLU 1M25G	1788610000
w. threading	54	HDC 10A TOLU 2PG11G	1746170000
w. threading	54	HDC 10A TOLU 1PG16G	1663930000
w. threading	68	HDC 15A TOLU 1PG21G	1663990000

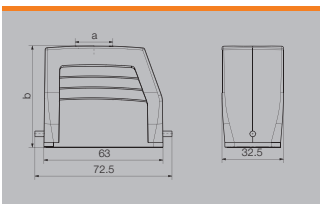

Cover



Version	Type	Order No.
For hoods	HDC 10A DODL 1LB	1665890000

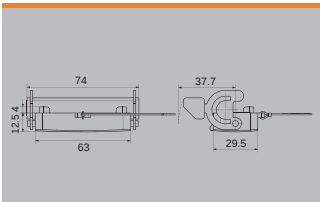

End locking, lower side


Size 2

Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	25	HDC 10A ALU	1664040000
	37.5	HDC 10A ADLU	1664060000

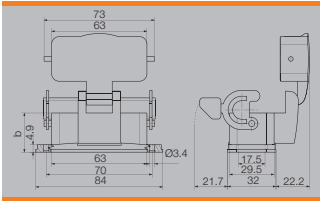

Bulkhead housing




Version	b (mm)	Type	Order No.
	26	HDC 10A ALU SL	1021450000

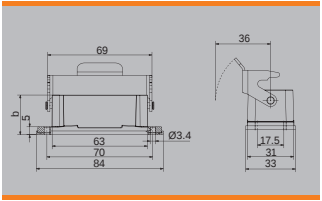

Base housing




Version	b (mm)	Type	Order No.
w. threading	57	HDC 10A SLU 1M20G	1901100000
w. threading	69.5	HDC 10A SDLU 1M20G	1901010000
w. threading	57	HDC 10A SLU 2M20G	1788640000
w. threading	69.5	HDC 10A SDLU 2M20G	1788660000
w. threading	57	HDC 10A SLU 1M25G	1901160000
w. threading	69.5	HDC 10A SDLU 1M25G	1901040000
w. threading	57	HDC 10A SLU 2M25G	1788630000
w. threading	69.5	HDC 10A SDLU 2M25G	1788650000
w. threading	57	HDC 10A SLU 1PG16G	1664170000
w. threading	69.5	HDC 10A SDLU 1PG16G	1664410000
w. threading	57	HDC 10A SLU 2PG16G	1664190000
w. threading	69.5	HDC 10A SDLU 2PG16G	1664420000
w. threading	57	HDC 10A SLU 1PG21G	1664210000

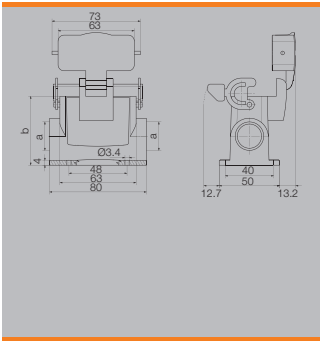

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	48	HDC 10A KLU 1M25G	1788670000
w. threading	48	HDC 10A KLU 2PG09G	1783250000
w. threading	48	HDC 10A KLU 1PG16G	1664560000

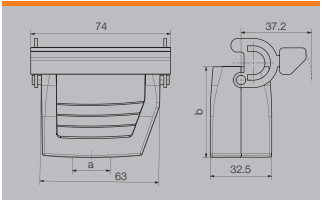

Cover



Version	Type	Order No.
For bases	HDC 10A DMDL 2B0	1665880000

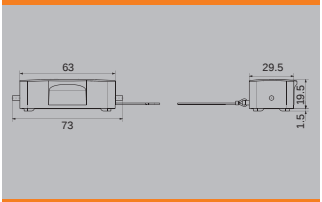

RockStar® IP65 Housings / NEMA Type 12, 4X

End locking, lower side


Size 3

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	52	HDC 06B TSLU 1M20G	1788100000
w. threading	52	HDC 06B TSLU 1M25G	1788090000
w. threading	72	HDC 16D TSLU 1M25G	1787480000
w. threading	72	HDC 16D TSLU 1M32G	1787470000
w. threading	52	HDC 06B TSLU 1PG13G	1670530000
w. threading	52	HDC 06B TSLU 1PG16G	1652520000
w. threading	72	HDC 16D TSLU 1PG21G	1652560000
w. threading	72	HDC 16D TSLU 1PG29G	1652580000

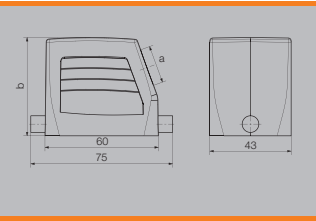

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	52	HDC 06B TOLU 1M20G	1788120000
w. threading	52	HDC 06B TOLU 1M25G	1788110000
w. threading	72	HDC 16D TOLU 1M25G	1787500000
w. threading	72	HDC 16D TOLU 1M32G	1787490000
w. threading	52	HDC 06B TOLU 1PG13G	1670500000
w. threading	52	HDC 06B TOLU 1PG16G	1652640000
w. threading	72	HDC 16D TOLU 1PG21G	1652680000
w. threading	72	HDC 16D TOLU 1PG29G	1652700000

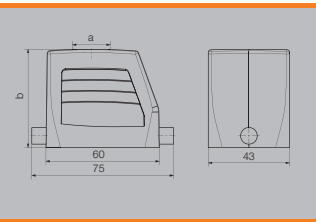


Cover



Version	Type	Order No.
For hoods	HDC 06B DMDL 1LB	1665210000
For hoods	HDC 06B DMDL 1LB N	2559730000

Note: N = Plastic locking lever with stainless steel inlay

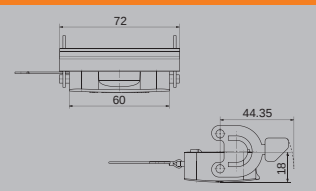

End locking, lower side

Size 3


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	29.3	HDC 06B ALU	1202100000
	29.3	HDC 06B ALU N	2488560000
	27.8	HDC 06B ALU O-RING	1019870000
	29.3	HDC 06B ADLU	1202500000
	29.3	HDC 06B ADLU N	2559320000

Note: N = Plastic locking lever with stainless steel inlay

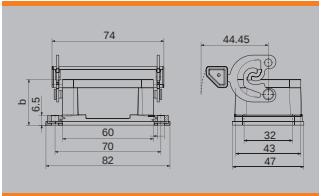


Base housing



Version	b (mm)	Type	Order No.
w. threading	54	HDC 06B SLU 1M20G	1900460000
w. threading		HDC 06B SLU 1M20G N	2637080000
w. threading	54	HDC 06B SDLU 1M20G N	2560720000
w. threading	54	HDC 06B SLU 2M20G	1788140000
w. threading	54	HDC 06B SDLU 1M20G	1900360000
w. threading	54	HDC 06B SDLU 2M20G	1788170000
w. threading	54	HDC 06B SLU 2M25G	1788130000
w. threading	54	HDC 06B SLU 2M20G N	2560850000
w. threading	54	HDC 06B SLU 2M25G N	2560860000
w. threading	54	HDC 06B SDLU 2M25G	1788160000
w. threading	54	HDC 06B SDLU 2M20G N	2560820000
w. threading	54	HDC 06B SDLU 2M25G N	2560830000
w. threading	54	HDC 06B SLU 1M25G	1900480000
w. threading	54	HDC 06B SLU 1M25G N	2560710000
w. threading	54	HDC 06B SDLU 1M25G	1900380000
w. threading	74	HDC 16D SLU 1M25G	1900880000
w. threading	74	HDC 16D SDLU 1M25G	1900820000
w. threading	74	HDC 16D SLU 2M25G	1787520000
w. threading	74	HDC 16D SDLU 2M25G	1787540000
w. threading	74	HDC 16D SLU 1M32G	1900900000
w. threading	74	HDC 16D SLU 2M32G	1787510000
w. threading	54	HDC 06B SLU 1PG16G	1652750000
w. threading	54	HDC 06B SLU 1PG16G N	2560840000
w. threading	54	HDC 06B SDLU 1PG16G	1652980000
w. threading	54	HDC 06B SDLU 1PG16G N	2560810000
w. threading	54	HDC 06B SLU 2PG16G	1652760000
w. threading	74	HDC 16D SLU 2PG21G	1652840000
w. threading	54	HDC 06B SDLU 2PG16G	1652990000


Note: N = Plastic locking lever with stainless steel inlay

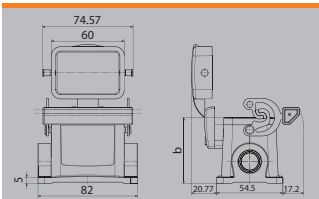

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	54.8	HDC 06B KLU 1M25G	1021330000
w. threading	74.6	HDC 16D KLU 1PG21G	1653230000
w. threading	54.8	HDC 06B KLU 1PG16G	1653200000

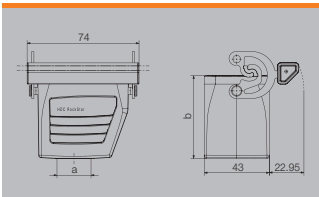

Cover




Version	Type	Order No.
For bases	HDC 06B DDDL 2B0	1665200000

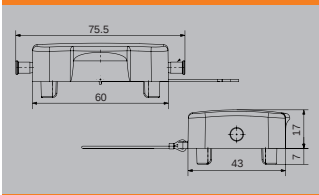

Counter-frame



Version	b (mm)	Type	Order No.
		HDC IP65 06B FRAME M4	1081550000

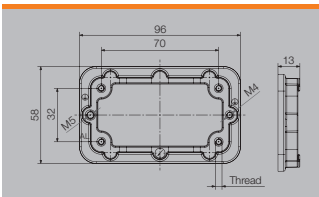

RockStar® IP65 Housings / NEMA Type 12, 4X

Side locking, lower side


Size 4

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	52	HDC 10B TSBU 1M20G	1787560000
w. threading	52	HDC 10B TSBU 1M25G	1787550000
w. threading	72	HDC 24D TSBU 1M25G	1787240000
w. threading	72	HDC 24D TSBU 1M32G	1787230000
w. threading	52	HDC 10B TSBU 1PG16G	1654070000
w. threading	52	HDC 10B TSBU 1PG21G	1654090000
w. threading	72	HDC 24D TSBU 1PG21G	1654150000
w. threading	72	HDC 24D TSBU 1PG29G	1654170000

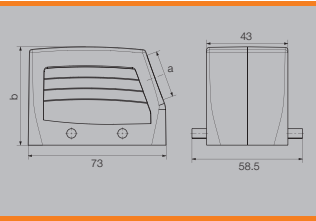

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	52	HDC 10B TOBU 1M20G	1787600000
w. threading	52	HDC 10B TOBU 1M25G	1787590000
w. threading	72	HDC 24D TOBU 2M20G	1336600000
w. threading	72	HDC 24D TOBU 1M25G	1787300000
w. threading	72	HDC 24D TOBU 1M32G	1787290000
w. threading	52	HDC 10B TOBU 1PG16G	1654220000
w. threading	52	HDC 10B TOBU 1PG21G	1654240000
w. threading	72	HDC 24D TOBU 1PG29G	1654320000

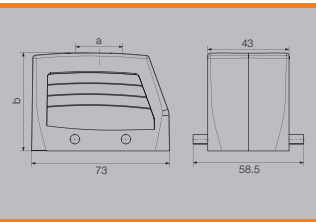

Cover



Version	Type	Order No.
For hoods	HDC 10B DMDQ 2QB	1665240000
For hoods	HDC 10B DMDQ 2QB N	2559740000

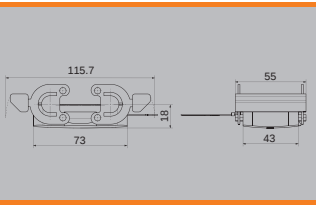

Note Note: N = Plastic locking lever with stainless steel inlay

Side locking, lower side

Size 4


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	29.5	HDC 10B ABU	120500000
	29.5	HDC 10B ABU N	248858000

Note: N = Plastic locking lever with stainless steel inlay

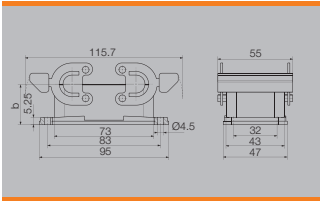


Base housing



Version	b (mm)	Type	Order No.
w. threading	57	HDC 10B SBU 1M20G	190136000
w. threading	57	HDC 10B SBU 1M20G N	256088000
w. threading	57	HDC 10B SBU 2M20G	178764000
w. threading	57	HDC 10B SBU 2M20G N	256089000
w. threading	57	HDC 10B SBU 1M25G N	256090000
w. threading	57	HDC 10B SBU 2M25G	178763000
w. threading	57	HDC 10B SBU 1M25G	190137000
w. threading	57	HDC 10B SBU 2M25G N	256091000
w. threading	74	HDC 24D SBU 1M25G	190321000
w. threading	74	HDC 24D SBU 2M25G	178735000
w. threading	74	HDC 24D SBU 2M25G N	256076000
w. threading	74	HDC 24D SBU 1M32G	190322000
w. threading	74	HDC 24D SBU 1M32G N	256099000
w. threading	74	HDC 24D SBU 2M32G	178736000
w. threading	74	HDC 24D SBU 2M32G N	256100000
w. threading	57	HDC 10B SBU 1PG16G	165437000
w. threading	57	HDC 10B SBU 1PG16G N	256073000
w. threading	57	HDC 10B SBU 2PG16G	165438000
w. threading	57	HDC 10B SBU 2PG16G N	256087000
w. threading	74	HDC 24D SBU 2PG21G	165445000
w. threading	74	HDC 24D SBU 1PG29G	165447000

Note: N = Plastic locking lever with stainless steel inlay

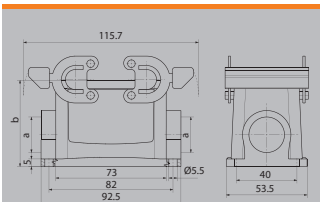


Coupling housing



Version	b (mm)	Type	Order No.
w. threading	54.65	HDC 10B KBU 1M20G	178772000
w. threading	54.65	HDC 10B KBU 1M20G N	255986000
w. threading	54.65	HDC 10B KBU 1M25G	102125000
w. threading	54.65	HDC 10B KBU 1PG16G	165458000


Note: N = Plastic locking lever with stainless steel inlay

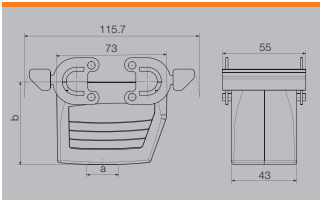

Cover




Version	Type	Order No.
For bases	HDC 10B DDDQ 4B0	166523000

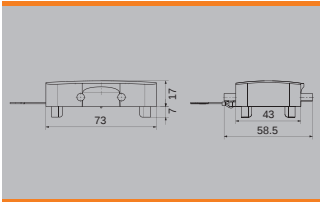

Counter-frame



Version	b (mm)	Type	Order No.
		HDC IP65 10B FRAME M4	108156000

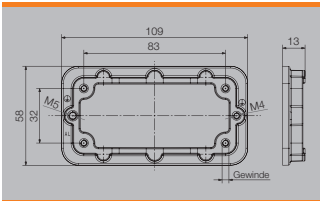

RockStar® IP65 Housings / NEMA Type 12, 4X

End locking, lower side


Size 4

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	52	HDC 10B TSLU 1M25G	1787580000
w. threading	72	HDC 24D TSLU 1M25G	1787280000
w. threading	72	HDC 24D TSLU 1M32G	1787270000
w. threading	52	HDC 10B TSLU 1PG16G	1655210000
w. threading	72	HDC 24D TSLU 1PG21G	1655250000
w. threading	72	HDC 24D TSLU 1PG29G	1655270000

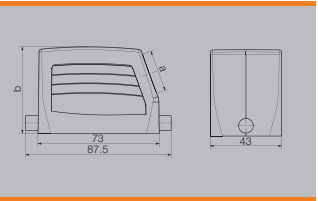

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	52	HDC 10B TOLU 1M25G	1787620000
w. threading	72	HDC 24D TOLU 1M25G	1787340000
w. threading	72	HDC 24D TOLU 1M32G	1787330000
w. threading	52	HDC 10B TOLU 1PG16G	1655320000
w. threading	72	HDC 24D TOLU 1PG21G	1655360000
w. threading	72	HDC 24D TOLU 1PG29G	1655380000

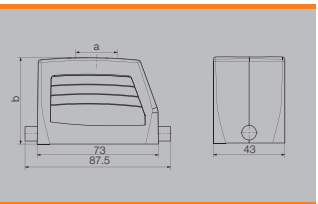


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	29	HDC 10B ALU	1206100000
	29	HDC 10B ADLU	1206500000

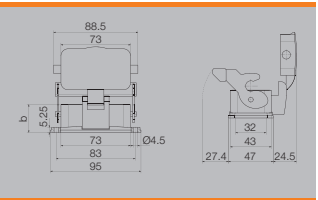

Base housing




Version	b (mm)	Type	Order No.
w. threading	57	HDC 10B SLU 1M20G	1901620000
w. threading	57	HDC 10B SDLU 1M20G	1901570000
w. threading	57	HDC 10B SLU 2M20G	1787660000
w. threading	57	HDC 10B SDLU 2M20G	1787700000
w. threading	57	HDC 10B SLU 1M25G	1901640000
w. threading	74	HDC 24D SDLU 1M25G	1903410000
w. threading	57	HDC 10B SLU 2M25G	1787650000
w. threading	74	HDC 24D SDLU 2M25G	1787420000
w. threading	74	HDC 24D SDLU 1M32G	1903560000
w. threading	74	HDC 24D SDLU 1M32G	1903510000
w. threading	74	HDC 24D SLU 2M32G	1787370000
w. threading	74	HDC 24D SDLU 2M32G	1787410000
w. threading	57	HDC 10B SLU 2PG16G	1655470000
w. threading	57	HDC 10B SDLU 2PG16G	1655680000

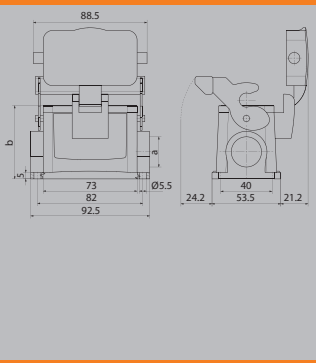

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	55	HDC 10B KLU 1M20G	1787740000
w. threading	55	HDC 10B KLU 1M25G	1787730000
w. threading	75	HDC 24D KLU 1M25G	1787460000
w. threading	75	HDC 24D KLU 1M32G	1787450000
w. threading	55	HDC 10B KLU 1PG16G	1655890000

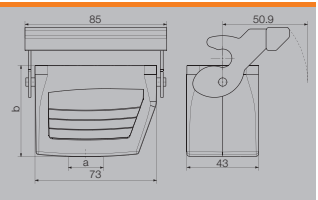

Counter-frame



Version	b (mm)	Type	Order No.
		HDC IP65 10B FRAME M4	1081560000

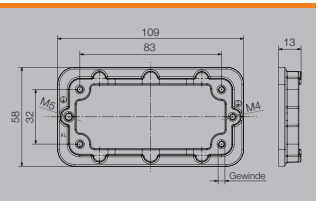

Side locking, upper side


Size 4

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	52	HDC 10B TSB0 1M25G	1787570000
w. threading	72	HDC 24D TSB0 1M25G	1787260000
w. threading	72	HDC 24D TSB0 1M32G	1787250000
w. threading	52	HDC 10B TSB0 1PG16G	1654750000
w. threading	72	HDC 24D TSB0 1PG16G	1654810000
w. threading	72	HDC 24D TSB0 1PG21G	1654790000

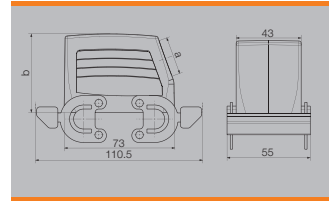

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	52	HDC 10B TOBO 1M25G	1787610000
w. threading	52	HDC 10B TOBO 1PG16G	1654860000
w. threading	72	HDC 24D TOBO 1PG29G	1654920000

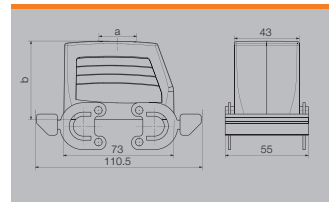

Cover



Version	Type	Order No.
For hoods	HDC 10B DMDQ 4B0	1665250000

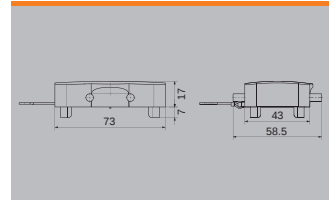


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	29	HDC 10B ABO	1052430000
	51.6	HDC 10B ADBO	1205600000

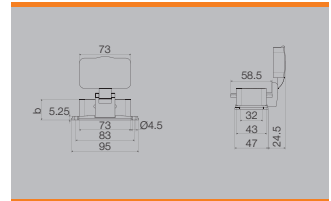

Base housing




Version	b (mm)	Type	Order No.
w. threading	57	HDC 10B SDB0 1M20G	1901490000
w. threading	57	HDC 10B SDB0 2M20G	1787680000
w. threading	57	HDC 10B SDB0 1M25G	1901510000
w. threading	74	HDC 24D SDB0 1M25G	1903370000
w. threading	57	HDC 10B SDB0 2M25G	1787670000
w. threading	74	HDC 24D SDB0 2M25G	1787400000
w. threading	57	HDC 10B SDB0 2PG16G	1655000000

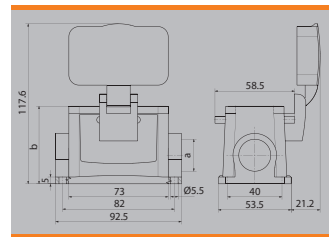

Cover




Version	Type	Order No.
For bases	HDC 10B D0DQ 2QB	1009080000

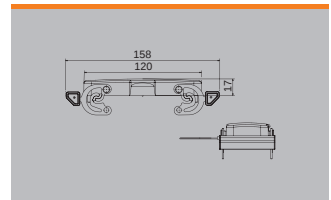

Counter-frame



Version	b (mm)	Type	Order No.
		HDC IP65 10B FRAME M4	1081560000

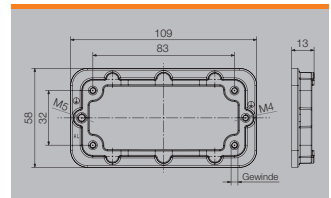

RockStar® IP65 Housings / NEMA Type 12, 4X

Central-locking clamp


Size 4

Hood

Plug housing, cable entry sideways



Version	b (mm)	Type	Order No.
w. threading	72	HDC 24D TSZO 1M25G	1903610000
w. threading	72	HDC 24D TSZO 1PG21G	1968360000

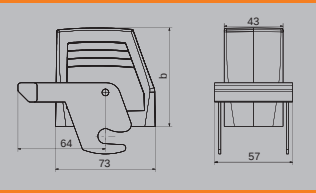


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	29.25	HDC 10B AZO	1901700000

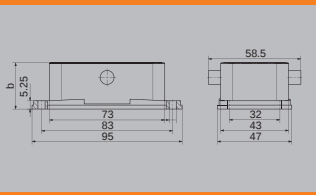

Base housing




Version	b (mm)	Type	Order No.
w. threading	74	HDC 24D SZO 2PG21G	1968350000

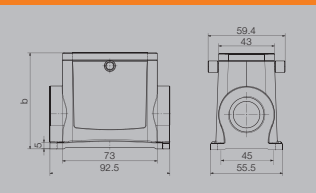

Counter-frame



Version	b (mm)	Type	Order No.
		HDC IP65 10B FRAME M4	1081560000

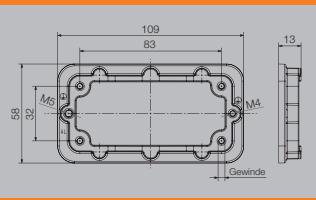

End locking, lower side


Size 5

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	58	HDC 16A TSLU 1M20G	1041760000
w. threading	72	HDC 25A TSLU 1M20G	1788680000
w. threading	58	HDC 16A TSLU 1M25G	1788740000
w. threading	72	HDC 25A TSLU 1M25G	1788690000
w. threading	58	HDC 16A TSLU 1PG16G	1664690000
w. threading	72	HDC 25A TSLU 1PG16G	1664730000
w. threading	72	HDC 25A TSLU 1PG21G	1664750000

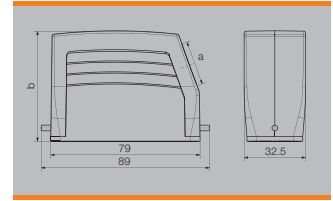

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	72	HDC 25A TOLU 1M20G	1788710000
w. threading	58	HDC 16A TOLU 1M25G	1788750000
w. threading	72	HDC 25A TOLU 1M25G	1788700000
w. threading	58	HDC 16A TOLU 1PG16G	1664810000
w. threading	72	HDC 25A TOLU 1PG21G	1664870000

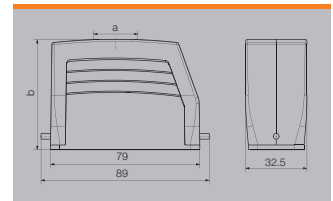

Cover



Version	Type	Order No.
For hoods	HDC 16A DDDL 1LB	1665900000

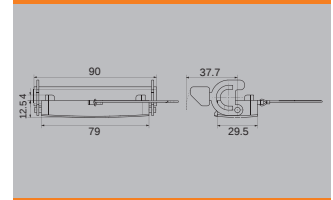


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	26.25	HDC 16A ALU	1664920000
	26.25	HDC 16A ADLU	1664940000

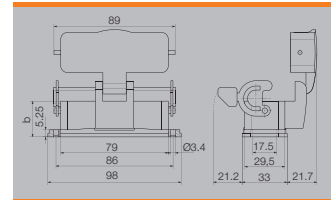

Base housing


Version	b (mm)	Type	Order No.
w. threading	57	HDC 16A SLU 1M20G	1934720000
w. threading	57	HDC 16A SDLU 1M20G	1934710000
w. threading	57	HDC 16A SLU 2M20G	1788770000
w. threading	57	HDC 16A SDLU 2M20G	1788790000
w. threading	57	HDC 16A SLU 1M25G	1902330000
w. threading	57	HDC 16A SLU 2M25G	1788760000
w. threading	57	HDC 16A SDLU 2M25G	1788780000
w. threading	57	HDC 16A SLU 2PG16G	1665070000
w. threading	57	HDC 16A SDLU 2PG16G	1665300000
w. threading	57	HDC 16A SLU 1PG21G	1665090000

 

Coupling housing



Version	b (mm)	Type	Order No.
w. threading	52.62	HDC 16A KLU 1M25G	1788800000
w. threading	52.62	HDC 16A KLU 1PG16G	1665450000

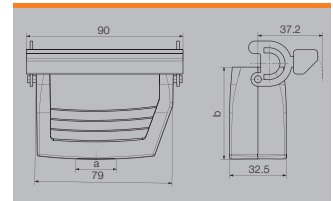

RockStar® IP65 Housings / NEMA Type 12, 4X

End locking, lower side


Size 5

Base

Cover



Version	Type	Order No.
For bases	HDC 16A DMDL 2B0	1665910000

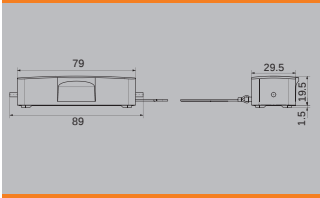

Side locking, lower side


Size 6

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	61	HDC 16B TSBU 1M25G	1788180000
w. threading	76	HDC 40D TSBU 1M25G	1787010000
w. threading	76	HDC 40D TSBU 1M32G	1787000000
w. threading	61	HDC 16B TSBU 1M40G	1809620000
w. threading	76	HDC 40D TSBU 1M40G	1904800000
w. threading	61	HDC 16B TSBU 1PG21G	1656480000
w. threading	76	HDC 40D TSBU 1PG21G	1656520000
w. threading	76	HDC 40D TSBU 1PG29G	1656540000

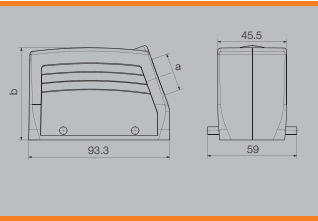

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	61	HDC 16B TOBU 1M25G	1788210000
w. threading	76	HDC 40D TOBU 1M25G	1787070000
w. threading	76	HDC 40D TOBU 2M25	1208380000
		HDC 40D TOBU 1M32G1M20G	1229120000
w. threading	76	HDC 40D TOBU 1M32G	1787060000
w. threading	61	HDC 16B TOBU 1PG21G	1656590000
w. threading	76	HDC 40D TOBU 1PG21G	1656630000
w. threading	76	HDC 40D TOBU 1PG29G	1656650000

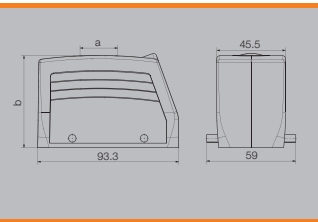

Cover



Version	Type	Order No.
For hoods	HDC 16B DMDQ 20B	1665270000

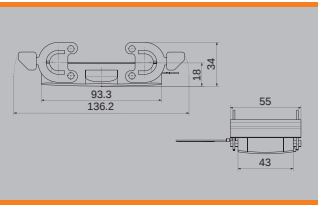

RockStar® IP65 Housings / NEMA Type 12, 4X

Side locking, lower side

Size 6


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	29	HDC 16B ABU	1208600000
	29	HDC 16B ABU N	2488590000

Note Note: N = Plastic locking lever with stainless steel inlay

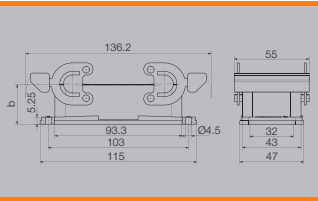


Base housing



Version	b (mm)	Type	Order No.
w. threading	64	HDC 16B SBU 1M25G	1899980000
w. threading	64	HDC 16B SBU 1M25G N	2560740000
w. threading	64	HDC 16B SBU 2M25G	1788240000
w. threading	84	HDC 40D SBU 1M25G	1902970000
w. threading	64	HDC 16B SBU 2M25G N	2560930000
w. threading	84	HDC 40D SBU 2M25G	1787120000
w. threading	84	HDC 40D SBU 1M32G N	2561030000
w. threading	84	HDC 40D SBU 2M32G	1787110000
w. threading	84	HDC 40D SBU 1M32G	1902990000
w. threading	64	HDC 16B SBU 1PG21G	1656720000
w. threading	64	HDC 16B SBU 2PG21G	1656730000
w. threading	84	HDC 40D SBU 2PG21G	1656810000
w. threading	84	HDC 40D SBU 1PG29G	1656830000
w. threading	64	HDC 16B SBU 1PG21G N	2560940000
w. threading	84	HDC 40D SBU 2PG29G	1656840000
w. threading	64	HDC 16B SBU 2PG21G N	2560950000
w. threading	84	HDC 40D SBU 2M25G N	2561020000
w. threading	84	HDC 40D SBU 2M32G N	2561040000

Note Note: N = Plastic locking lever with stainless steel inlay

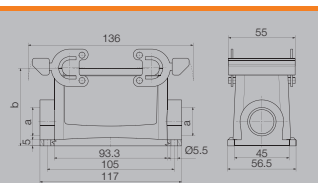


Coupling housing



Version	b (mm)	Type	Order No.
w. threading	78.6	HDC 40D KBU 1M25G	1787200000
w. threading	79	HDC 40D KBU 1M25G N	2559890000
w. threading	78.6	HDC 40D KBU 1M32G	1787190000
w. threading	79	HDC 40D KBU 1M32G N	2559900000
w. threading	79	HDC 40D KBU 2M32G N	2545510000
w. threading	64	HDC 16B KBU 1PG21G	1657270000
w. threading	78.6	HDC 40D KBU 1PG21G	1657310000


Note Note: N = Plastic locking lever with stainless steel inlay

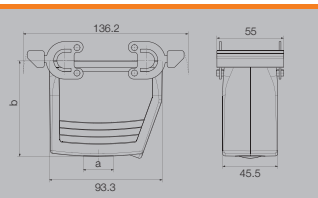

Cover




Version	Type	Order No.
For bases	HDC 16B DDDQ 480	1665260000

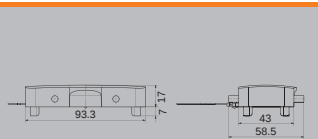

Counter-frame



Version	b (mm)	Type	Order No.
	14	HDC IP65 16B FRAME M4	1081570000

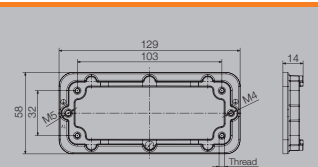

End locking, lower side


Size 6

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	61	HDC 16B TSLU 1M25G	1788200000
w. threading	76	HDC 40D TSLU 1M25G	1787050000
w. threading	61	HDC 16B TSLU 1M32G	1804640000
w. threading	76	HDC 40D TSLU 1M32G	1787040000
w. threading	76	HDC 40D TSLU 1M40G	1804650000
w. threading	61	HDC 16B TSLU 1PG21G	1657850000
w. threading	76	HDC 40D TSLU 1PG21G	1657890000
w. threading	76	HDC 40D TSLU 1PG29G	1657910000

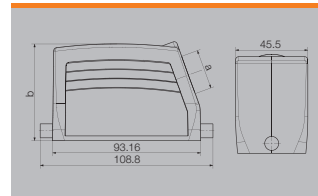

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	61	HDC 16B TOLU 1M25G	1788230000
w. threading	61	HDC 16B TOLU 1M32G	1804630000
w. threading	76	HDC 40D TOLU 1M32G	1787100000
w. threading	61	HDC 16B TOLU 1PG21G	1657960000
w. threading	76	HDC 40D TOLU 1PG29G	1658020000

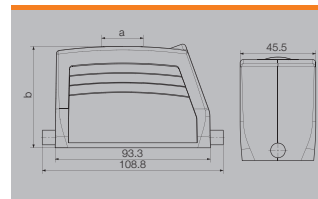


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	30.3	HDC 16B ALU	1209700000
	30.3	HDC 16B ADLU	1210100000

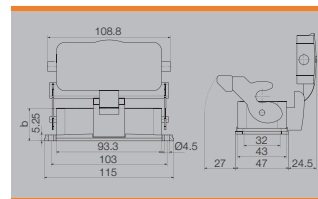

Base housing




Version	b (mm)	Type	Order No.
w. threading	64	HDC 16B SLU 1M25G	1900170000
w. threading	102	HDC 40D SDLU 1M25G	1903070000
w. threading	64	HDC 16B SLU 2M25G	1788250000
w. threading	82	HDC 16B SDLU 2M25G	1788270000
w. threading	102	HDC 40D SDLU 2M25G	1787180000
w. threading	84	HDC 40D SLU 1M32G	1903110000
w. threading	102	HDC 40D SDLU 1M32G	1903080000
w. threading	84	HDC 40D SLU 2M32G	1804660000
w. threading	102	HDC 40D SDLU 2M32G	1787170000
w. threading	64	HDC 16B SLU 1PG21G	1658110000
w. threading	82	HDC 16B SDLU 1PG21G	1658320000
w. threading	64	HDC 16B SLU 2PG21G	1658120000
w. threading	82	HDC 16B SDLU 2PG21G	1658330000
w. threading	102	HDC 40D SDLU 1PG29G	1658410000

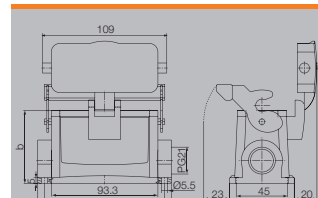

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	65.1	HDC 16B KLU 1M25G	1788290000
w. threading	78.6	HDC 40D KLU 1M25G	1787220000

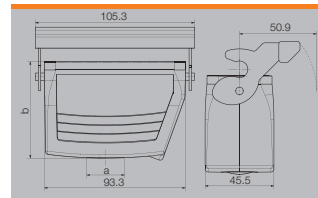

Counter-frame



Version	b (mm)	Type	Order No.
	14	HDC IP65 16B FRAME M4	1081570000

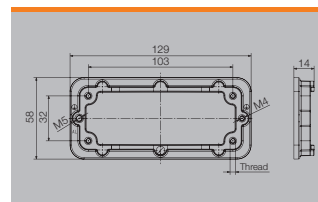

Side locking, lower side


Size 7

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	77	HDC 32A TSBU 1M25G	1787960000
w. threading	77	HDC 32A TSBU 1M32G	1787950000
w. threading	77	HDC 32A TSBU 1PG21G	1665670000
w. threading	77	HDC 32A TSBU 1PG29G	1665690000

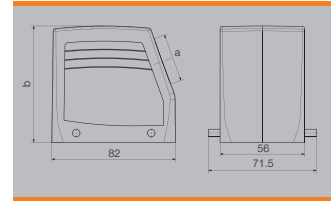

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	77	HDC 32A TOBU 1M32G	1787990000
w. threading	77	HDC 32A TOBU 1PG21G	1665790000
w. threading	77	HDC 32A TOBU 1PG29G	1665810000

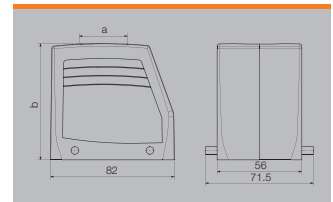

Cover



Version	Type	Order No.
For hoods	HDC 32A DMDQ 2QB	1665930000

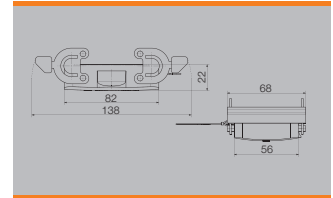


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	30	HDC 32A ABU	1665860000

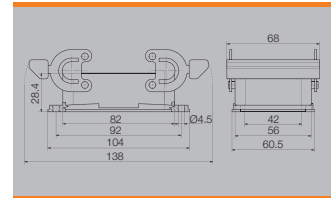

Base housing




Version	b (mm)	Type	Order No.
w. threading	75	HDC 32A SBU 1M25G	1903870000
w. threading	75	HDC 32A SBU 2M25G	1788040000
w. threading	75	HDC 32A SBU 2PG21G	1665980000
w. threading	75	HDC 32A SBU 1PG29G	1666010000

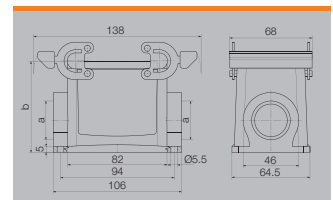

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	77	HDC 32A KBU 1M25G	1788080000
w. threading	77	HDC 32A KBU 1M32G	1788070000

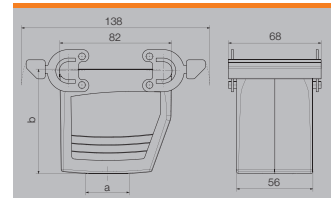

Cover



Version	Type	Order No.
For bases	HDC 32A DDDQ 4B0	1665920000

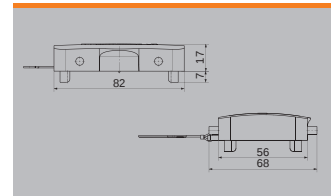

RockStar® IP65 Housings / NEMA Type 12, 4X

Side locking, upper side


Size 7

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	77	HDC 32A TSBO 1M25G	1787980000
w. threading	77	HDC 32A TSBO 1M32G	1787970000
w. threading	77	HDC 32A TSBO 1PG29G	1666270000

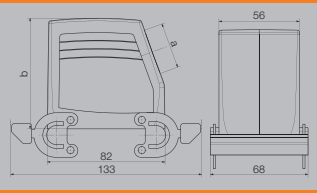

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	77	HDC 32A TOBO 1M32G	1788010000

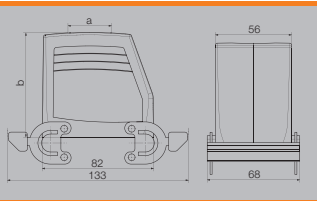


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	30	HDC 32A ADBO	1666440000

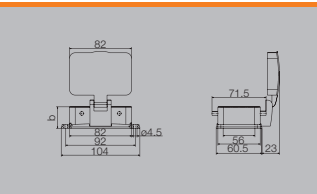

Base housing



Version	b (mm)	Type	Order No.
w. threading	75	HDC 32A SDBO 1M25G	1903900000
w. threading	75	HDC 32A SDBO 2M25G	1788060000
w. threading	75	HDC 32A SDBO 1M32G	1903910000
w. threading	75	HDC 32A SDBO 2M32G	1788050000
w. threading	75	HDC 32A SDBO 1PG21G	1666550000
w. threading	75	HDC 32A SDBO 1PG29G	1666590000

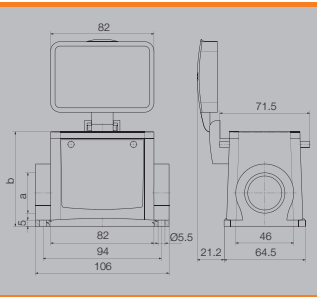

Side locking, lower side


Size 8

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	62.58	HDC 24B TSBU 1M25G	1787760000
w. threading	76	HDC 64D TSBU 1M25G	1786780000
w. threading	62.58	HDC 24B TSBU 1M32G	1787750000
w. threading	76	HDC 64D TSBU 1M32G	1786770000
w. threading	62.58	HDC 24B TSBU 1M40G	1902480000
w. threading	76	HDC 64D TSBU 1M40G	1809630000
w. threading	62.58	HDC 24B TSBU 1PG21G	1661230000
w. threading	76	HDC 64D TSBU 1PG21G	1661300000
w. threading	62.58	HDC 24B TSBU 1PG29G	1661240000
w. threading	76	HDC 64D TSBU 1PG29G	1661320000

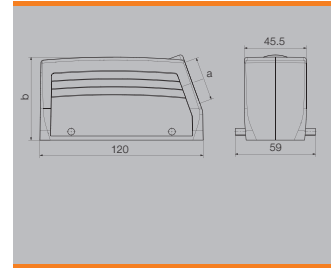

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	62.58	HDC 24B TOBU 1M25G	1787820000
w. threading	62.58	HDC 24B TOBU 1M32G	1787810000
w. threading	76	HDC 64D TOBU 1M32G	1786830000
w. threading	76	HDC 64D TOBU 2M32G	1009710000
w. threading	62.58	HDC 24B TOBU 1M40G	1902980000
w. threading	76	HDC 64D TOBU 1M40G	1045560000
w. threading	62.58	HDC 24B TOBU 1PG21G	1661370000
w. threading	76	HDC 64D TOBU 1PG21G	1661440000
w. threading	62.58	HDC 24B TOBU 1PG29G	1661380000
w. threading	76	HDC 64D TOBU 1PG29G	1661460000

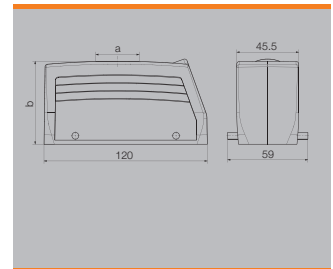


Cover



Version	Type	Order No.
For hoods	HDC 24B DMDQ 2QB	1665640000
For hoods	HDC 24B DMDQ 2QB N	2559760000

Note Note: N = Plastic locking lever with stainless steel inlay

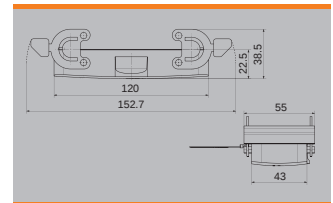


Hood

XXL plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	76	HDC 64D TSBu 1M50G	1111130000

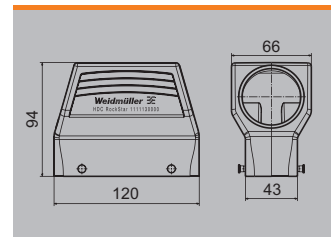

XXL plug housing, cable entry on top



Version	b (mm)	Type	Order No.
w. threading	76	HDC 64D TOBU 1M50G	1111140000

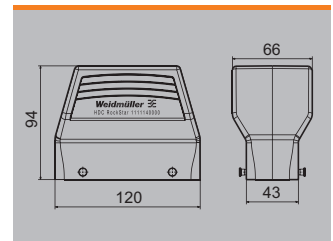

RockStar® IP65 Housings / NEMA Type 12, 4X

Side locking, lower side

Size 8


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	29.5	HDC 24B ABU	1212400000
	29.5	HDC 24B ABU N	2488600000

Note Note: N = Plastic locking lever with stainless steel inlay

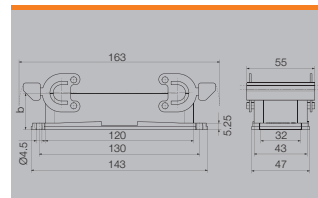


Base housing



Version	b (mm)	Type	Order No.
w. threading	64	HDC 24B SBU 2M25G	1787870000
w. threading	64	HDC 24B SBU 1M25G	1901150000
w. threading	84	HDC 64D SBU 1M25G	1904340000
w. threading	64	HDC 24B SBU 2M25G N	2560970000
w. threading	84	HDC 64D SBU 2M25G	1786890000
w. threading	64	HDC 24B SBU 1M25G N	2560960000
w. threading	84	HDC 64D SBU 2M25G N	2561060000
w. threading	84	HDC 64D SBU 1M32G N	2561050000
w. threading	84	HDC 64D SBU 2M32G	1786880000
w. threading	84	HDC 64D SBU 1M32G	1904350000
w. threading	64	HDC 24B SBU 1PG21G	1661510000
w. threading	64	HDC 24B SBU 1PG21G N	2560750000
w. threading	64	HDC 24B SBU 2PG21G	1661520000
w. threading	84	HDC 64D SBU 2PG21G	1661590000

Note Note: N = Plastic locking lever with stainless steel inlay

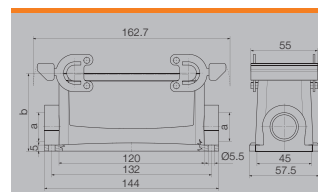


Coupling housing



Version	b (mm)	Type	Order No.
w. threading	65	HDC 24B KBU 1M25G	1787920000
w. threading	65	HDC 24B KBU 1M25G N	2559870000
w. threading	65	HDC 24B KBU 2M32G N	2559880000
w. threading	79	HDC 64D KBU 1M32G	1786960000
w. threading	79	HDC 64D KBU 1M32G N	2559910000
w. threading	65	HDC 24B KBU 1PG21G	1661720000
w. threading	65	HDC 24B KBU 1PG29G	1661730000


Note Note: N = Plastic locking lever with stainless steel inlay

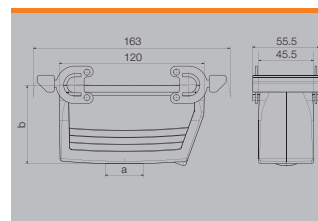

Cover




Version	Type	Order No.
For bases	HDC 24B D0DQ 4B0	1665630000

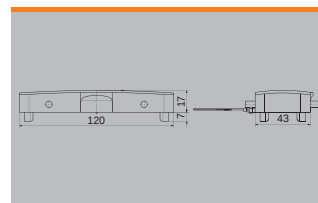

Counter-frame



Version	b (mm)	Type	Order No.
	17	HDC IP65 24B FRAME M4	1081580000

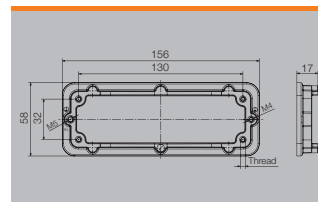

End locking, lower side


Size 8

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	62.58	HDC 24B TSLU 1M25G	1787800000
w. threading	62.58	HDC 24B TSLU 1M32G	1787790000
w. threading	76	HDC 64D TSLU 1M32G	1786810000
w. threading	76	HDC 64D TSLU 1M40G	1804610000
w. threading	62.58	HDC 24B TSLU 1P621G	1662390000
w. threading	76	HDC 64D TSLU 1P621G	1662470000
w. threading	62.58	HDC 24B TSLU 1P629G	1662410000
w. threading	76	HDC 64D TSLU 1P629G	1662490000

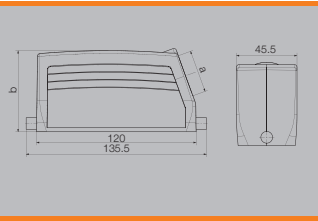

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	62.58	HDC 24B TOLU 1M25G	1787860000
w. threading	76	HDC 64D TOLU 1M25G	1786870000
w. threading	62.58	HDC 24B TOLU 1M32G	1787850000
w. threading	76	HDC 64D TOLU 1M32G	1786860000
w. threading	76	HDC 64D TOLU 1M40G	1983470000
w. threading	62.58	HDC 24B TOLU 1P621G	1662540000
w. threading	76	HDC 64D TOLU 1P621G	1662610000
w. threading	62.58	HDC 24B TOLU 1P629G	1662550000
w. threading	76	HDC 64D TOLU 1P629G	1662630000

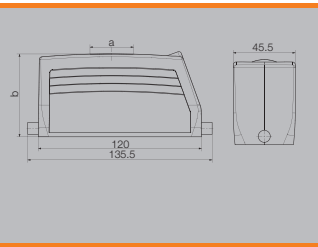


Hood

XXL plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	76	HDC 64D TSLU 1M50G	1111150000

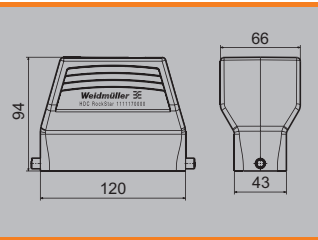

XXL plug housing, cable entry on top



Version	b (mm)	Type	Order No.
w. threading	76	HDC 64D TOLU 1M50G	1111170000

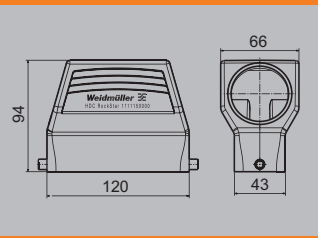

Side locking, upper side


Size 8

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	62.58	HDC 24B TSBO 1M25G	1787780000
w. threading	76	HDC 64D TSBO 1M25G	1786800000
w. threading	62.58	HDC 24B TSBO 1M32G	1787770000
w. threading	76	HDC 64D TSBO 1M32G	1786790000
w. threading	62.58	HDC 24B TSBO 1PG21G	1661860000
w. threading	76	HDC 64D TSBO 1PG21G	1661940000
w. threading	62.58	HDC 24B TSBO 1PG29G	1661880000
w. threading	76	HDC 64D TSBO 1PG29G	1661960000

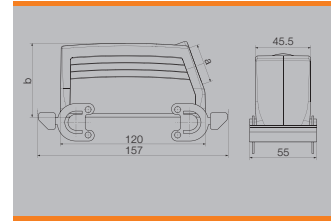

Plug housing, cable entry at top




Version	b (mm)	Type	Order No.
w. threading	62.58	HDC 24B TOBO 1M32G	1787830000
w. threading	76	HDC 64D TOBO 1PG21G	1662080000
w. threading	62.58	HDC 24B TOBO 1PG29G	1662020000
w. threading	76	HDC 64D TOBO 1PG29G	1662100000

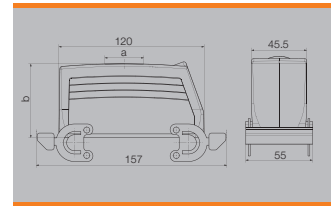

Cover



Version	Type	Order No.
For hoods	HDC 24B DMDQ 480	1665650000

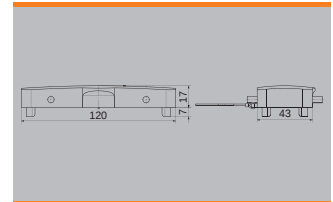


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	29	HDC 24B ABO	1967910000
	29	HDC 24B ADBO	1213300000

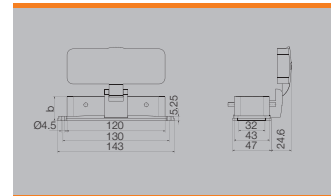

Base housing




Version	b (mm)	Type	Order No.
w. threading	84	HDC 64D SDBO 1M32G	1904400000
w. threading	84	HDC 64D SDBO 2M32G	1786920000
w. threading	64	HDC 24B SDBO 2PG21G	1662180000
w. threading	84	HDC 64D SDBO 1PG29G	1662280000

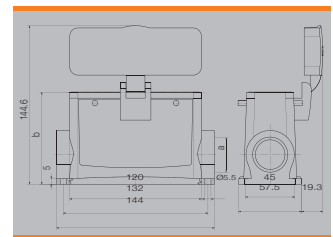

Cover



Version	Type	Order No.
For bases	HDC 24B DDDQ 20B	1009100000

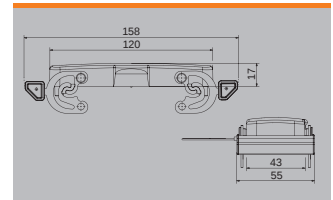

RockStar® IP65 Housings / NEMA Type 12, 4X

Central-locking clamp


Size 8

Hood

Plug housing, cable entry sideways



Version	b (mm)	Type	Order No.
w. threading	76	HDC 64D TSZO 1M40G	1904690000
w. threading	76	HDC 64D TSZO 1PG21G	1663370000
w. threading	76	HDC 64D TSZO 1PG29G	1663390000

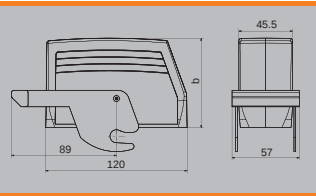


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	29	HDC 24B AZO	1611350000

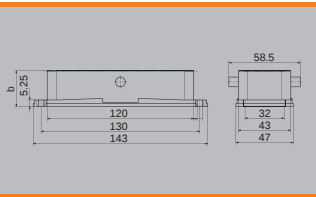

Base housing




Version	b (mm)	Type	Order No.
w. threading	79.7	HDC 64D SZO 2PG29G	1968370000

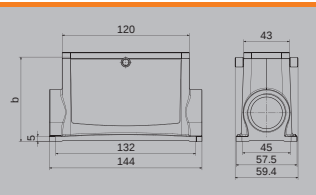

Counter-frame



Version	b (mm)	Type	Order No.
	17	HDC IP65 24B FRAME M4	1081580000

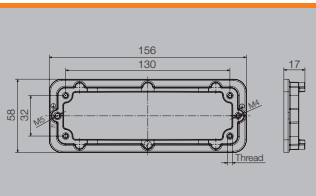

End locking, lower side


Size 9

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	78	HDC 48A TSLU 1M32G	1788550000
w. threading	78	HDC 48A TSLU 1PG29G	1666710000

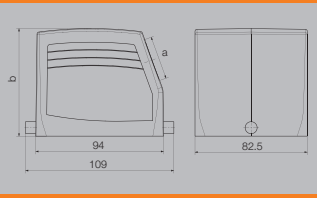

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	78	HDC 48A TOLU 1M32G	1788560000
w. threading	78	HDC 48A TOLU 1PG29G	1666730000

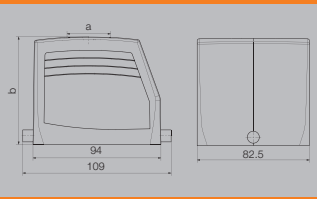


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	40	HDC 48A ALU	1666740000
	40	HDC 48A ADLU	1666750000

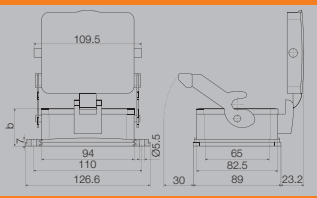

Base housing



Version	b (mm)	Type	Order No.
w. threading	79	HDC 48A SLU 2M32G	1788570000
w. threading	79	HDC 48A SLU 1PG29G	1666770000
w. threading	79	HDC 48A SDLU 1PG29G	1666810000

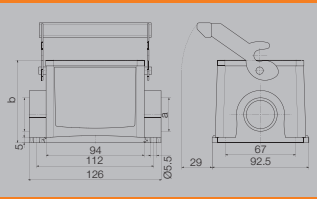

RockStar® IP65 Housings / NEMA Type 12, 4X

Side locking, lower side


Size 10

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B TSBU 1M32G	1788400000
w. threading	79	HDC 32B TSBU 1PG29G	1666840000

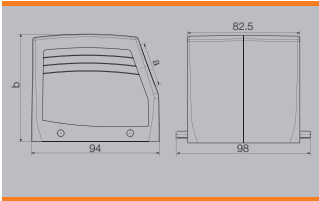

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B TOBU 1M32G	1788430000
w. threading	79	HDC 32B TOBU 1PG29G	1666870000

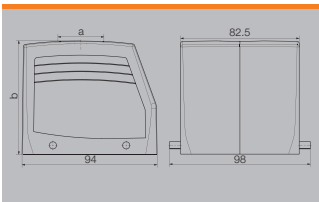


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	38	HDC 32B ABU	1217800000

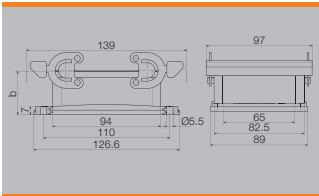

Base housing




Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B SBU 1M32G	1902600000
w. threading	79	HDC 32B SBU 2M32G	1788460000
		HDC 32B SBU 2M40G CS	1301990000
w. threading	79	HDC 32B SBU 2PG29G	1666920000
w. threading	79	HDC 32B SBU 1PG36G	1902610000
w. threading	79	HDC 32B SBU 2PG36G	1902640000

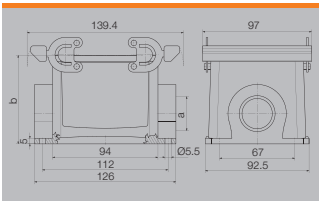

Coupling housing




Version	b (mm)	Type	Order No.
w. threading	83	HDC 32B KBU 1M40G	1902730000
w. threading	83	HDC 32B KBU 1PG29G	1902740000
w. threading	83	HDC 32B KBU 1PG36G	1902750000

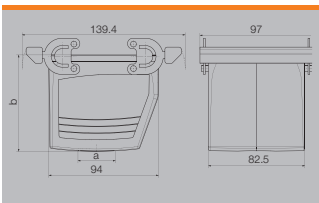

Cover



Version	Type	Order No.
For bases	HDC 32B D00Q 480	1165790000

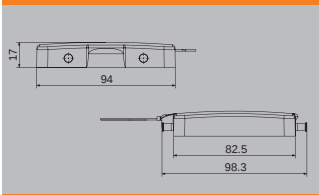

End locking, lower side


Size 10

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B TSLU 1M32G	1788420000
w. threading	79	HDC 32B TSLU 1PG29G	1667120000

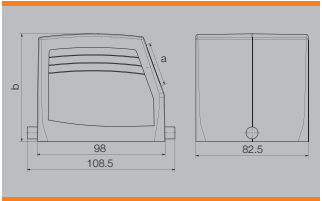

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B TOLU 1M32G	1788450000
w. threading	79	HDC 32B TOLU 1PG29G	1219300000

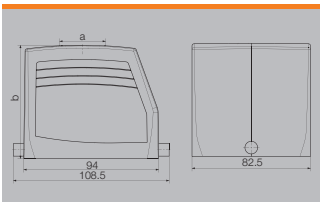


Base

Bulkhead housing




Version	b (mm)	Type	Order No.
	38	HDC 32B ALU	1219500000
	55	HDC 32B ADLU	1219800000

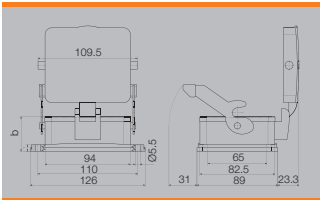

Base housing




Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B SLU 1M32G	1902670000
w. threading	96	HDC 32B SDLU 1M32G	1902650000
w. threading	79	HDC 32B SLU 2M32G	1788470000
w. threading	96	HDC 32B SDLU 2M32G	1788490000

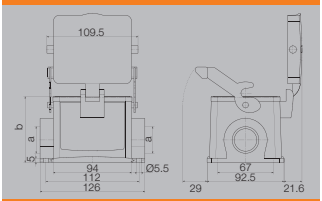

Coupling housing



Version	b (mm)	Type	Order No.
w. threading	83	HDC 32B KLU 1M32G	1788500000

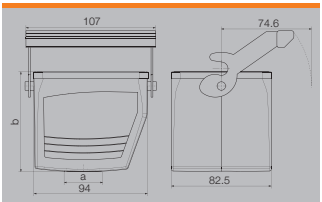

RockStar® IP65 Housings / NEMA Type 12, 4X

Side locking, upper side


Size 10

Hood

Plug housing, cable entry sideways



Version	b (mm)	Type	Order No.
w. threading	79	HDC 32B TSB0 1M32G	1788410000

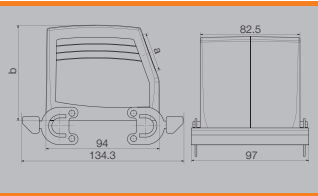


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	55	HDC 32B ADB0	1218800000

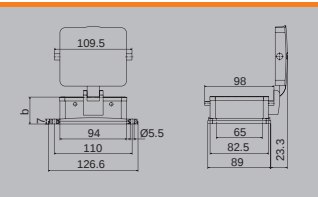

End locking, lower side


Size 12

Hood

Plug housing, cable entry sideways




Version	b (mm)	Type	Order No.
w. threading	94	HDC 48B TSLU 1M32G	1788320000
w. threading	94	HDC 48B TSLW 1M40G	1788310000
w. threading	94	HDC 48B TSLW 1M50G	1788300000
w. threading	94	HDC 48B TSLW 1P629G	1650850000
w. threading	94	HDC 48B TSLW 1P636G	1650860000
w. threading	94	HDC 48B TSLW 1P642G	1670470000

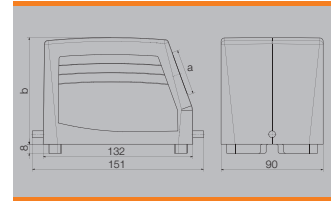

Plug housing, cable entry at top



Version	b (mm)	Type	Order No.
w. threading	94	HDC 48B TOLU 1M32G	1788350000
w. threading	94	HDC 48B TOLU 1M40G	1788340000
w. threading	94	HDC 48B TOLU 1M50G	1788330000
w. threading	94	HDC 48B TOLU 1PG29G	1650980000
w. threading	94	HDC 48B TOLU 1PG36G	1651000000

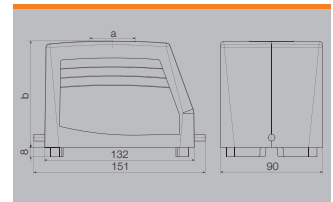


Base

Bulkhead housing



Version	b (mm)	Type	Order No.
	62	HDC 48B ADLW	12229000000
	41.5	HDC 48B ALW	12956000000

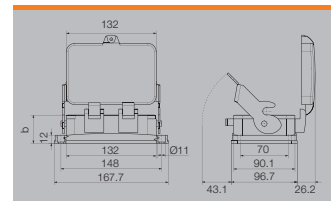

Base housing



Version	b (mm)	Type	Order No.
w. threading	100	HDC 48B SLU 1M32G	1904190000
w. threading	120	HDC 48B SDLW 1M32G	1904150000
w. threading	100	HDC 48B SLU 2M32G	1788370000
w. threading	120	HDC 48B SDLW 2M32G	1788390000
w. threading	100	HDC 48B SLU 2M40G	1788360000
w. threading	120	HDC 48B SDLW 2M40G	1983500000
w. threading	120	HDC 48B SDLW 2M50G	1983510000
w. threading	100	HDC 48B SLU 1PG29G	1651100000
w. threading	120	HDC 48B SDLW 1PG29G	1799810000
w. threading	120	HDC 48B SDLW 2PG29G	1667560000

