

Communication on FieldPower® power supply 24V/10A

Dear Madam or Sir,

The IP65 power supply 8000025427 FP BOX SNT10A 2XPT6 is discontinued and replaced by the new IP65 power supplies.

1. Initial situation

The high-performance power supply PROtop is now also available in FieldPower® IP65 enclosure.

2. Technical Information

Old version

Power Supply 24V / 10A



Input: 3x 320 ... 575 VAC

Output: 24 VDC / 10 A
150% for 4 Sek.,
100% permanent

No parallel connection

No status relay, no Input

No communication option

W 181 mm, H 196 mm, D 170 mm

New version

Power Supply 24V / 10A and 20 A



Input: 3x 400 ... 500 VAC



Output: 24 VDC / 10 A und 20A
150 % for 5 Sek.,
130% perm. with temperature derating

Parallel connection without diode module

Status relay and input via M12

Communication option available

W 196 mm, H 196 mm, D 220 mm

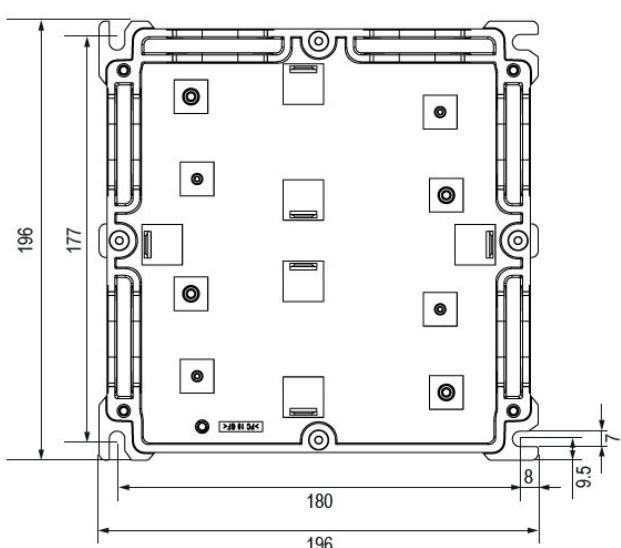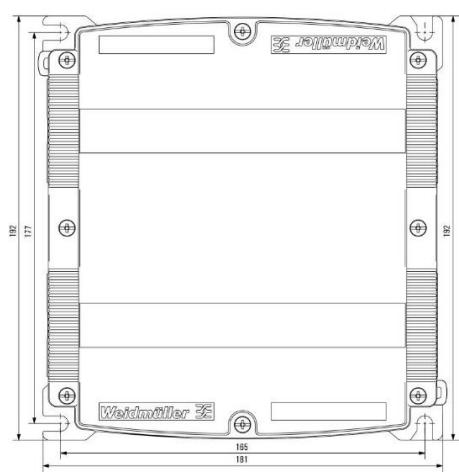

3. Reason for discontinuation

The high-performance power supply PROtop is now also available in FieldPower® IP65 enclosure

4. Availability

The new power supplies are available from stock from October 2020.

5. Affected parts

Discontinued:	8000025427 FP BOX SNT10A 2XPT6	power supply 24V / 10A
Replacement products	2743440000 FP PRO TOP3 24/10 2P	power supply 24V / 10A
	2743450000 FP PRO TOP3 24/20 2P	power supply 24V / 20A

6. Data

Detmold, 01.Sept. 2020

We are very sorry for all the inconveniences caused and doing everything to adjust this product change as smooth as possible without big influence on delivery times and general functions.

For further questions please contact your sales office directly. All contacts for sales representatives are available here: www.weidmueller.com/contact

Best regards

Product Management

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 16, 32758 Detmold, Germany

Weidmüller – Your partner in Industrial Connectivity
We look forward to sharing ideas with you – **Let's connect.**