

 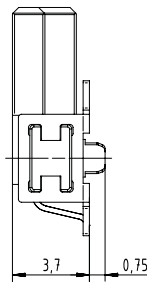
 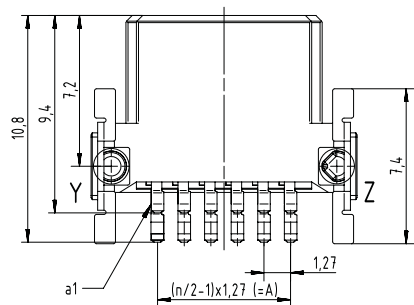


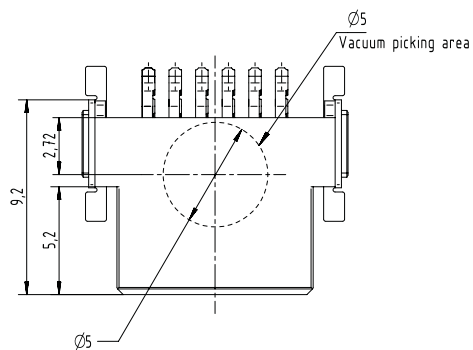


FFH S1/..H F1 B RL

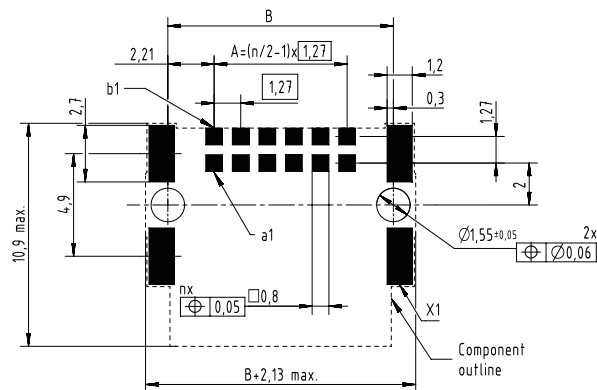

Type	Order no.	No. of poles	A	B	C	D	E
FFH S1/12H F1 B RL	2747430000	12	6,35	10,77	12,7	9,37	8,37
FFH S1/16H F1 B RL	2747440000	16	8,89	13,31	15,24	11,91	10,91
FFH S1/20H F1 B RL	2747450000	20	11,43	15,85	17,78	14,45	13,45
FFH S1/26H F1 B RL	2747460000	26	15,24	19,66	21,59	18,26	17,26
FFH S1/32H F1 B RL	2747470000	32	19,05	23,47	25,4	22,07	21,07
FFH S1/40H F1 B RL	2747480000	40	24,13	28,55	30,48	27,15	26,15
FFH S1/50H F1 B RL	2747490000	50	30,48	34,9	36,83	33,5	32,5
FFH S1/68H F1 B RL	2747500000	68	41,91	46,33	48,26	44,93	43,93
FFH S1/80H F1 B RL	2747510000	80	49,53	53,95	55,88	52,55	51,55

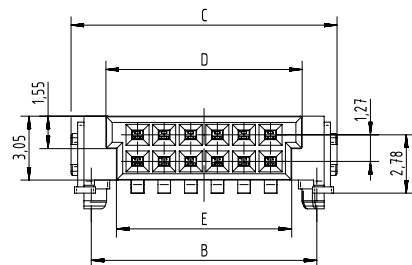

x= only mechanical
np= not plated thru hole
n= number of poles

