


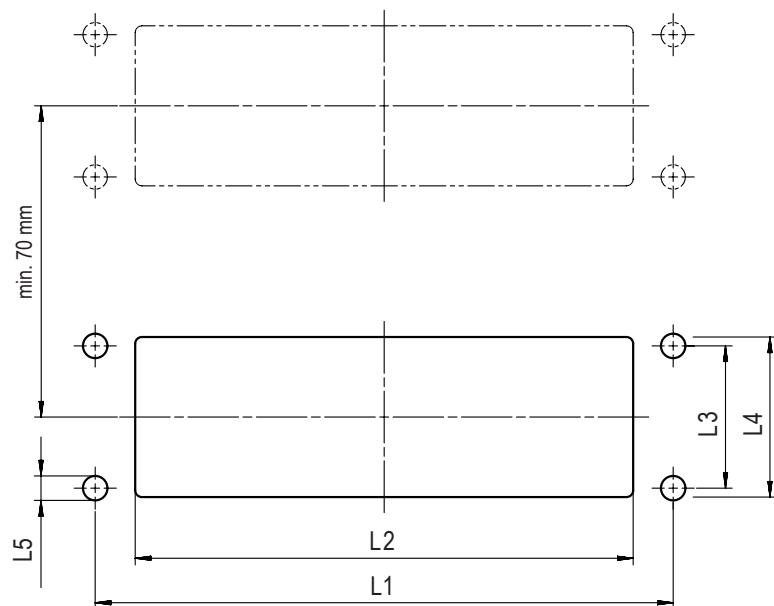

Abmessungen Montageausschnitte Cut-out dimensions

	L1	L2	L3	L4	L5
CABTITE FRFT 4-1 CABTITE FRFT 4-1 SET	58 mm	46 mm	32 mm	36 - 46 mm	5.5 mm
CABTITE FRFT 10/6 CABTITE FRFT 10/6 SET	83 mm	68.5 mm	32 mm	36 - 46 mm	5.5 mm
CABTITE FRFT 16/8 CABTITE FRFT 16/8 SET	103 mm	91 mm	32 mm	36 - 46 mm	5.5 mm
CABTITE FRFT 24/10 CABTITE FRFT 24/10 SET	130 mm	113.5 mm	32 mm	36 - 46 mm	5.5 mm

Montagetemperatur: min. +5 °C
Installation temperature: min. +5 °C

Max. Temperaturbereich: -40 °C bis +120 °C (statisch)
Max. temperature range: -40 °C to +120 °C (static)

Befestigung: Zylinderkopfschraube M5 ISO 4762 / DIN 912
Mounting: Cylinder head screw M5 ISO 4762 / DIN 912

Einzelrahmen (Deckel) Single frame (Cover)

CABTITE FRFT-AD 4-1	2891460000
CABTITE FRFT-AD 10/6	2891490000
CABTITE FRFT-AD 16/8	2891520000
CABTITE FRFT-AD 24/10	2891550000

Set mit Einzelrahmen und Inlays Set with single frame and inlays

CABTITE FRFT 4-1 SET	2891470000
CABTITE FRFT 10/6 SET	2891500000
CABTITE FRFT 16/8 SET	2891530000
CABTITE FRFT 24/10 SET	2891560000

Einzelrahmen (Rahmen und Deckel) Single frame (Frame and cover)


CABTITE FRFT 4-1	2891450000
CABTITE FRFT 10/6	2891480000
CABTITE FRFT 16/8	2891510000
CABTITE FRFT 24/10	2891540000

Inlay Informationen Inlay information









	—	⊥	+	++
	2584320000	2584300000	2584290000	2584270000
CABTITE FRFT 4-1 CABTITE FRFT 4-1 SET			x	
CABTITE FRFT 10/6 CABTITE FRFT 10/6 SET		x		x
CABTITE FRFT 16/8 CABTITE FRFT 16/8 SET	x		x	
CABTITE FRFT 24/10 CABTITE FRFT 24/10 SET		x	x	x

Cabtite

Montageanleitung Installation Instructions

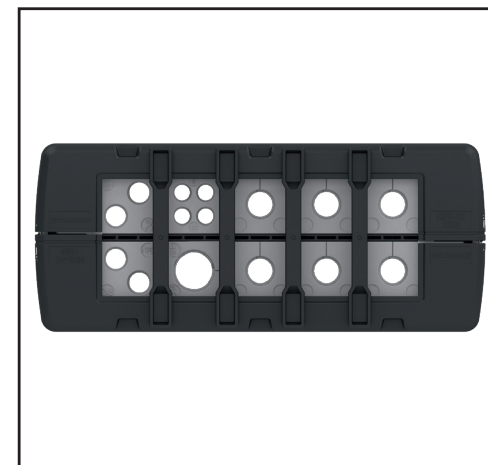

Weidmüller Interface GmbH & Co. KG
32758 Detmold, Germany
T +49 5231 1428-0
F +49 5231 1428-116
www.weidmueller.com

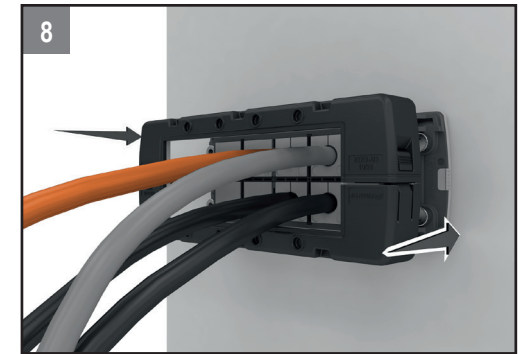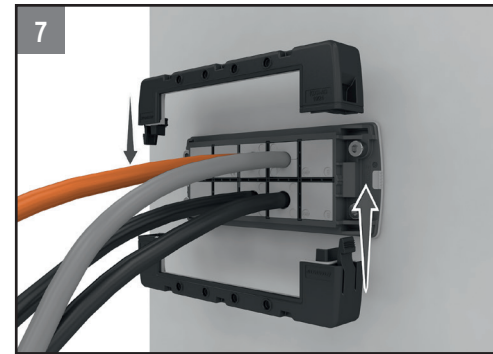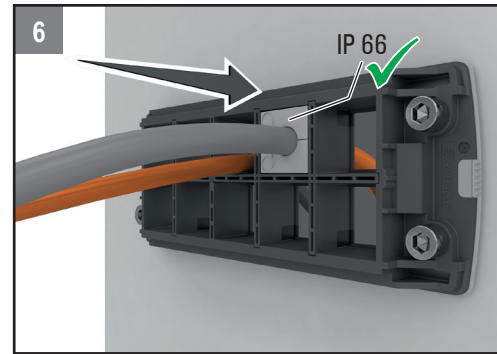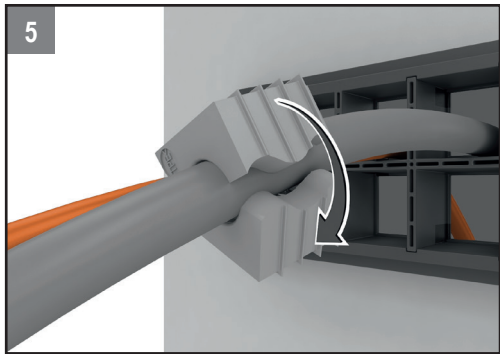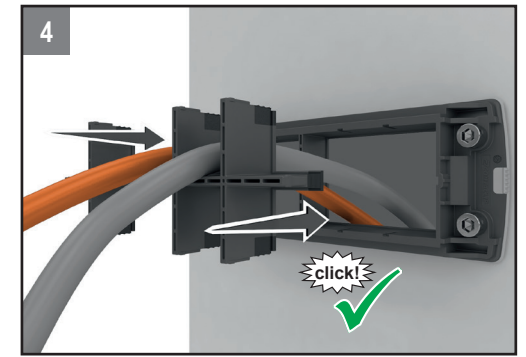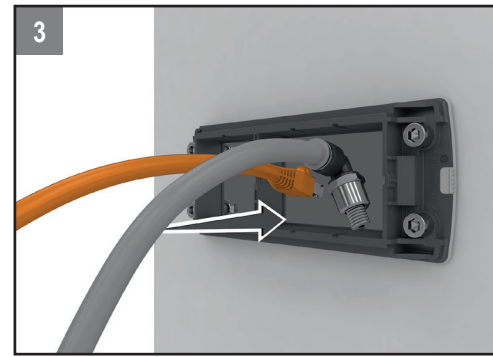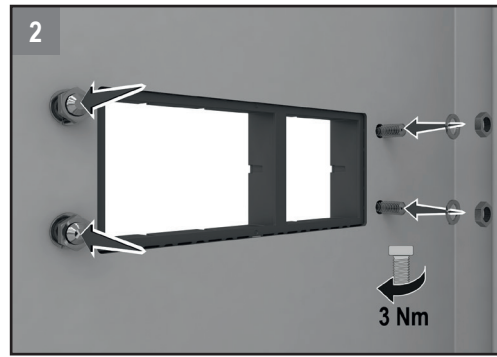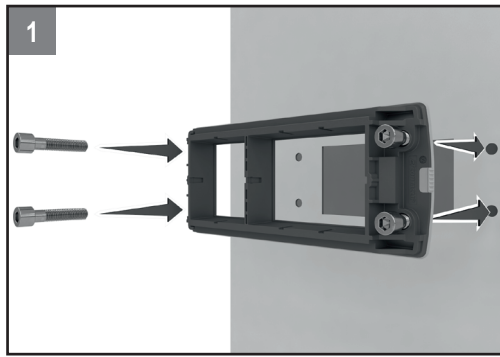

Optionale äußere Verriegelung
Optional frame lock on the outside

Deckel entfernen
Removing the cover

